


Ball bearings - plain ABEC 7



L1802

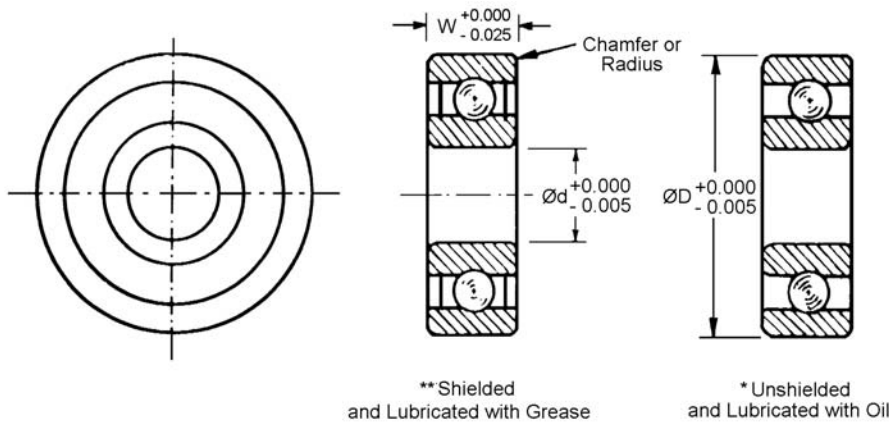

Material

Stainless steel DIN 1,4112.

Technical Notes

ABEC 7.

Unshielded - lubricated with oil.
Shielded - lubricated with grease.

Tips

Lower ranges ABEC bearings available on request.



Order no	Type	Ød	ØD	W	Dynamic Load (N)	Static Load (N)
B1-50	Unshielded	3,000	7,000	2,000	206	108
B1-50-S	Shielded	3,000	7,000	3,000	206	108
B1-51	Unshielded	3,000	8,000	3,000	333	196
B1-51-S	Shielded	3,000	8,000	4,000	333	196
B1-52	Unshielded	3,000	10,000	4,000	383	216
B1-52-S	Shielded	3,000	10,000	4,000	383	216
B1-104-7	Unshielded	4,000	9,000	2,500	353	196
B1-104-S-7	Shielded	4,000	9,000	4,000	353	196
B1-53	Unshielded	5,000	11,000	3,000	392	216
B1-53-S	Shielded	5,000	11,000	5,000	392	216
B1-54	Unshielded	5,000	13,000	4,000	451	284
B1-54-S	Shielded	5,000	13,000	4,000	451	284
B1-55	Unshielded	5,000	16,000	5,000	1480	746
B1-55-S	Shielded	5,000	16,000	5,000	1480	746
B1-106-7	Unshielded	6,000	13,000	3,500	579	353
B1-106-S-7	Shielded	6,000	13,000	5,000	579	353
B1-56	Unshielded	6,000	15,000	5,000	628	402
B1-56-S	Shielded	6,000	15,000	5,000	628	402
B1-57	Unshielded	6,000	19,000	6,000	1890	991
B1-57-S	Shielded	6,000	19,000	6,000	1890	991
B1-108-7	Unshielded	8,000	16,000	4,000	951	628
B1-108-S-7	Shielded	8,000	16,000	6,000	951	628
B1-110-7	Unshielded	10,000	19,000	5,000	1020	696
B1-110-S-7	Shielded	10,000	19,000	7,000	1020	696

