

Bearings - "Oil-less"

plain and flanged




L1808




Material
Sintered bronze.

Technical Notes
Long life.
Smooth operation.
No lubrication required.
Minimal breakaway torque resistance.

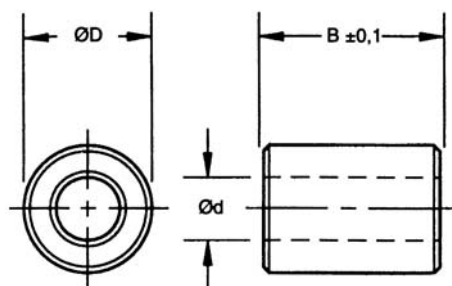

Plain Style

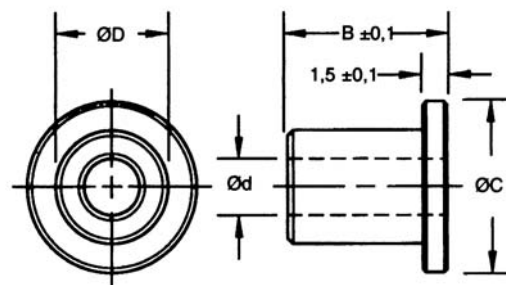

Flanged Style

Order No.	Type	Shaft Size	Ød +0,02	ØD -0,03	B	ØC
L1808.03-04	Plain	3	3,01	6,04	4	9
L1808.03-06	Plain	3	3,01	6,04	6	9
L1808.03-10	Plain	3	3,01	6,04	10	9
L1808.04-04	Plain	4	4,01	8,04	4	11
L1808.04-10	Plain	4	4,01	8,04	10	11
L1808.05-05	Plain	5	5,01	8,04	5	11
L1808.05-08	Plain	5	5,01	8,04	8	11
L1808.05-12	Plain	5	5,01	8,04	12	11
L1808.05-16	Plain	5	5,01	8,04	16	11
L1808.06-06	Plain	6	6,01	10,04	6	13
L1808.06-10	Plain	6	6,01	10,04	10	13
L1808.06-12	Plain	6	6,01	10,04	12	13
L1808.08-08	Plain	8	8,01	12,05	8	14
L1808.08-12	Plain	8	8,01	12,05	12	14
L1808.08-16	Plain	8	8,01	12,05	16	14
L1808.10-10	Plain	10	10,01	13,05	10	16
L1808.10-16	Plain	10	10,01	13,05	16	16
L1808.10-20	Plain	10	10,01	13,05	20	16
L1808.03-04	Flanged	3	3,01	6,04	4	9
L1808.03-06	Flanged	3	3,01	6,04	6	9
L1808.03-10	Flanged	3	3,01	6,04	10	9
L1808.04-04	Flanged	4	4,01	8,04	4	11
L1808.04-10	Flanged	4	4,01	8,04	10	11
L1808.05-05	Flanged	5	5,01	8,04	5	11
L1808.05-08	Flanged	5	5,01	8,04	8	11
L1808.05-12	Flanged	5	5,01	8,04	12	11
L1808.05-16	Flanged	5	5,01	8,04	16	11
L1808.06-06	Flanged	6	6,01	10,04	6	13
L1808.06-10	Flanged	6	6,01	10,04	10	13
L1808.06-12	Flanged	6	6,01	10,04	12	13
L1808.08-08	Flanged	8	8,01	12,05	8	14
L1808.08-12	Flanged	8	8,01	12,05	12	14
L1808.08-16	Flanged	8	8,01	12,05	16	14
L1808.10-10	Flanged	10	10,01	13,05	10	16
L1808.10-16	Flanged	10	10,01	13,05	16	16
L1808.10-20	Flanged	10	10,01	13,05	20	16



Other bearings versions and imperial sizes readily available.