

Bearings - Teflon




L1812




Material
Teflon.

Technical Notes

Long life.
Smooth operation.
No lubrication required.
Minimal breakaway torque resistance.

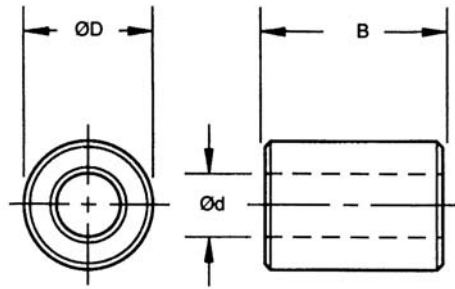

Plain Style

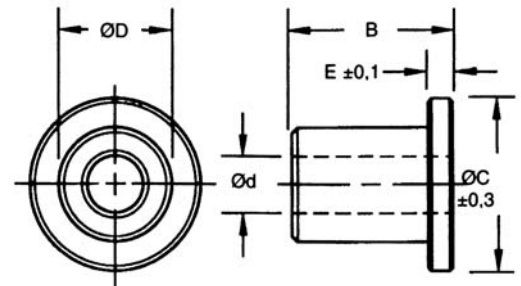

Flanged Style

Order No. Plain Style	Order No. Flanged Style	Shaft Size nominal	Ød +0,13	ØD +0,08	B ± 0,13	ØC	E
B8M-1	B9M-1	3	3,02	6,04	4,00	8,00	1,2
B8M-2	B9M-2	3	3,02	6,04	6,00	8,0	1,2
B8M-3	B9M-3	3	3,02	6,04	10,00	8,0	1,2
B8M-4	B9M-4	5	5,02	8,04	4,00	10,0	1,2
B8M-5	B9M-5	5	5,02	8,04	8,00	10,0	1,2
B8M-6	B9M-6	5	5,02	8,04	12,00	10,0	1,2
B8M-7	B9M-7	6	6,02	10,04	6,00	12,0	1,2
B8M-8	B9M-8	6	6,02	10,04	10,00	12,0	1,2
B8M-9	B9M-9	6	6,02	10,04	12,00	12,0	1,2
B8M-10	B9M-10	6	6,02	10,04	16,00	12,0	1,2
B8M-11	B9M-11	8	8,02	12,05	8,00	16,0	1,5
B8M-12	B9M-12	8	8,02	12,05	12,00	16,0	1,5
B8M-13	B9M-13	8	8,02	12,05	16,00	16,0	1,5
B8M-14	B9M-14	10	10,02	13,05	8,00	16,0	1,5
B8M-15	B9M-15	10	10,02	13,05	10,00	16,0	1,5
B8M-16	B9M-16	10	10,02	13,05	16,00	16,0	1,5
B8M-17	B9M-17	10	10,02	13,05	20,00	16,0	1,5
B8M-18	B9M-18	12	12,02	13,05	10,00	19,0	1,5
B8M-19	B9M-19	12	12,02	16,05	12,00	19,0	1,5
B8M-20	B9M-20	12	12,02	16,05	20,00	19,0	1,5
B8M-21	B9M-21	12	12,02	16,05	25,00	19,0	1,5



Other bearings versions and imperial sizes readily available.

