



Bearings - Thrust, ball



carbon steel

L1820



Material

Thrust washer carbon steel M5.0 series.
 Balls - hardened carbon steel DIN 1,4021.
 Nylon ball retainer.

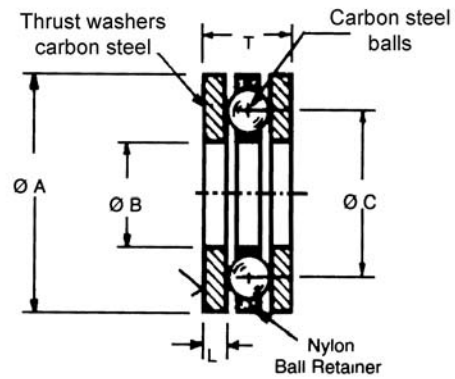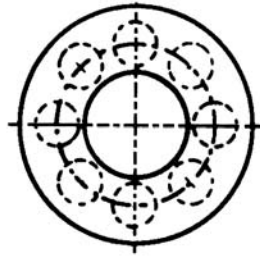

BEARINGS & SHAFTING



Other bearings versions and imperial sizes readily available.

Order No	ØB +0,13 -0,00	ØA +0,00 -0,13	ØC	L + 0,05	T	No. of Balls	Load Rating at 15rpm (N)
L1820.005	5,00	12,00	8,7	1,30	4,98	7	461
L1820.006	6,00	14,00	10,3	1,30	4,98	8	530
L1820.007	7,00	17,00	11,9	1,30	4,98	9	598
L1820.008	8,00	16,00	11,9	1,30	4,98	6	598
L1820.010	10,00	21,00	15,1	1,60	6,38	6	667
L1820.012	12,00	24,00	18,3	1,60	6,38	8	883
L1820.016	16,00	28,00	22,2	2,40	8,80	6	1079
L1820.019	19,00	32,00	25,4	2,40	8,80	8	1432
L1820.025	25,00	41,00	33,3	3,18	11,12	10	2207

