


Knurled Thumb Screws-Imperial sizes

stainless steel A2



P1070

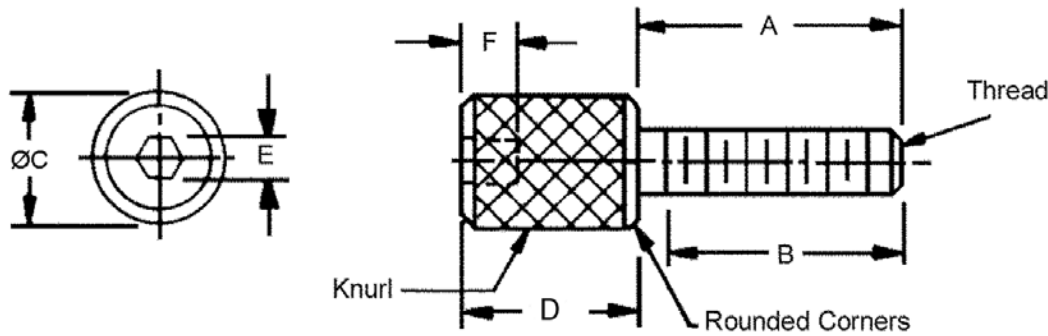

Material

303 (A2) stainless steel.
A2(AISI303) stainless steel is typically used in food, pharmaceutical and similar applications requiring a degree of corrosion protection.
Threads UNC-2A or UNF-2A as indicated.

Technical Notes

Stainless steel A2 is a hard stainless steel which may (in harsh conditions) exhibit slight signs of rusting.
Typically used in food and pharmaceutical applications.

Order No	Thread	Thread type	A	ØC	D	B	E	F
P1070.I041	#4-40	UNC-2A	1/2	1/4	1/2	7/16	5/64	1/16
P1070.I042	#4-40	UNC-2A	3/4	1/4	1/2	5/8	5/64	1/16
P1070.I045	#4-40	UNC-2A	1/2	5/16	1/2	7/16	3/32	5/64
P1070.I046	#4-40	UNC-2A	3/4	5/16	1/2	5/8	3/32	5/64
P1070.I048	#4-40	UNC-2A	3/8	3/8	1/2	5/16	1/8	3/32
P1070.I049	#4-40	UNC-2A	1/2	3/8	1/2	7/16	1/8	3/32
P1070.I061	#6-32	UNC-2A	1/2	1/4	1/2	7/16	5/64	1/16
P1070.I062	#6-32	UNC-2A	3/4	1/4	1/2	5/8	5/64	1/16
P1070.I063	#6-32	UNC-2A	1	1/4	1/2	13/16	5/64	1/16
P1070.I065	#6-32	UNC-2A	1/2	5/16	1/2	7/16	3/32	5/64
P1070.I066	#6-32	UNC-2A	3/4	5/16	1/2	5/8	3/32	5/64
P1070.I067	#6-32	UNC-2A	1	5/16	1/2	13/16	3/32	5/64
P1070.I068	#6-32	UNC-2A	3/8	3/8	1/2	5/16	1/8	3/32
P1070.I069	#6-32	UNC-2A	1/2	3/8	1/2	3/8	1/8	3/32
P1070.I081	#8-32	UNC-2A	1/2	1/4	1/2	7/16	5/64	1/16
P1070.I082	#8-32	UNC-2A	3/4	1/4	1/2	5/8	5/64	1/16
P1070.I083	#8-32	UNC-2A	1	1/4	1/2	13/16	5/64	1/16
P1070.I085	#8-32	UNC-2A	1/2	5/16	1/2	7/16	3/32	5/64
P1070.I086	#8-32	UNC-2A	3/4	5/16	1/2	5/8	3/32	5/64
P1070.I087	#8-32	UNC-2A	1	5/16	1/2	13/16	3/32	5/64
P1070.I088	#8-32	UNC-2A	3/8	3/8	1/2	5/16	1/8	3/32
P1070.I089	#8-32	UNC-2A	1/2	3/8	1/2	3/8	1/8	3/32
P1070.I101	#10-24	UNC-2A	1/2	5/16	3/16	7/16	3/32	5/64
P1070.I102	#10-24	UNC-2A	3/4	5/16	3/16	5/8	3/32	5/64
P1070.I103	#10-24	UNC-2A	1	5/16	3/16	13/16	3/32	5/64
P1070.I104	#10-24	UNC-2A	1 1/4	5/16	3/16	1	3/32	5/64
P1070.I105	#10-24	UNC-2A	1/2	3/8	1/2	7/16	1/8	3/32
P1070.I106	#10-24	UNC-2A	3/4	3/8	1/2	5/8	1/8	3/32
P1070.I107	#10-24	UNC-2A	1	3/8	1/2	13/16	1/8	3/32
P1070.I108	#10-24	UNC-2A	1 1/4	3/8	1/2	1	1/8	3/32
P1070.I111	#10-32	UNF-2A	1/2	5/16	3/16	7/16	3/32	5/64
P1070.I112	#10-32	UNF-2A	3/4	5/16	3/16	5/8	3/32	5/64
P1070.I113	#10-32	UNF-2A	1	5/16	3/16	13/16	3/32	5/64
P1070.I114	#10-32	UNF-2A	1 1/4	5/16	3/16	1	3/32	5/64
P1070.I115	#10-32	UNF-2A	1/2	3/8	1/2	7/16	1/8	3/32
P1070.I116	#10-32	UNF-2A	3/4	3/8	1/2	5/8	1/8	3/32
P1070.I117	#10-32	UNF-2A	1	3/8	1/2	13/16	1/8	3/32
P1070.I118	#10-32	UNF-2A	1 1/4	3/8	1/2	1	1/8	3/32

THREADED FASTENERS

