


# Thumb Screws

stainless steel A4

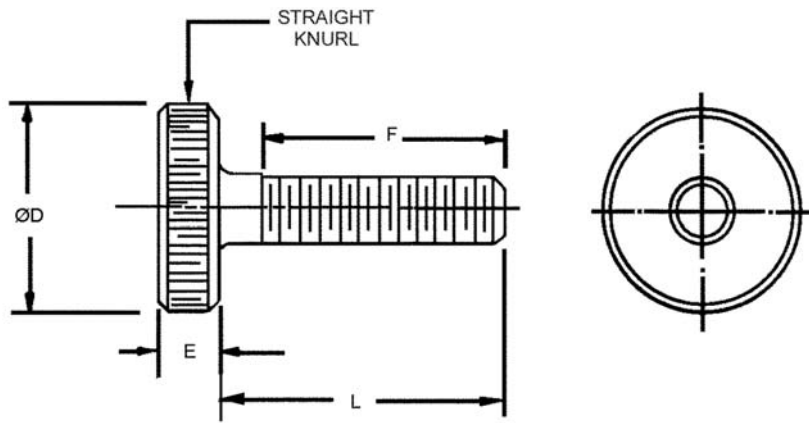

## P1083



### Material

Stainless steel A4 (DIN 1,4005, AISI316).

### Technical Notes

Stainless steel thumb screws A4 are considerably more expensive than A2 stainless steel thumb screws. They are highly resistant to corrosion.



Order No.	Thread	ØD	L	F	E
P1083.031	M3x0,5	7	12	8	3
P1083.032	M3x0,5	7	25	11	12
P1083.033	M3x0,5	7	32	16	12
P1083.034	M3x0,5	10	16	8	3
P1083.035	M3x0,5	10	16	11	3
P1083.041	M4x0,7	7	25	11	12
P1083.042	M4x0,7	7	32	16	12
P1083.043	M4x0,7	7	38	24	12
P1083.044	M4x0,7	10	12	8	3
P1083.045	M4x0,7	10	16	10	3
P1083.050	M5x0,8	10	18	11	5
P1083.051	M5x0,8	10	25	16	5
P1083.052	M5x0,8	10	30	20	5
P1083.053	M5x0,8	10	36	25	5
P1083.054	M5x0,8	10	25	16	5
P1083.055	M5x0,8	12	36	20	5
P1083.056	M5x0,8	12	25	25	5
P1083.057	M5x0,8	19	25	16	5
P1083.058	M5x0,8	19	30	20	5
P1083.059	M5x0,8	19	36	25	5
P1083.061	M6x1,0	19	25	16	5
P1083.062	M6x1,0	19	30	20	5
P1083.063	M6x1,0	19	36,5	25	5
P1083.064	M6x1,0	25,5	25	16	5
P1083.065	M6x1,0	25,5	30	20	5
P1083.066	M6x1,0	25,5	36,5	25	5
P1083.067	M6x1,0	25,5	42	32	5

