


Sprockets - nylatron, pin hub

for 9,53mm nom. circular pitch

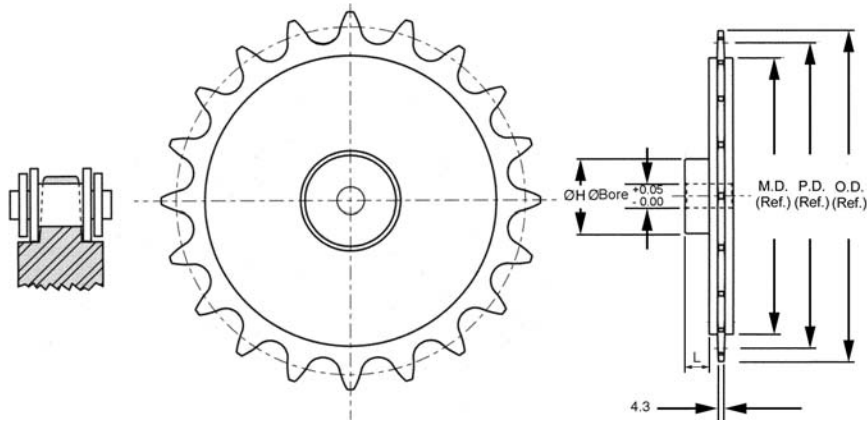

R1375



Material

Filled Nylatron.

Important Notes

Operates with R1375 chain.

Order No.	No. of Teeth	Bore Ø	Outside Ø	Pitch Ø	Minor Ø	L	Hub ØH	Max. Bore
R1375.009	9	Ø10	31,90	27,84	22,76	19,0	16,0	10
R1375.010	10	Ø10	35,05	30,84	25,76	19,0	20,6	12
R1375.011	11	Ø10	38,15	33,81	28,73	19,0	22,2	12
R1375.012	12	Ø16	41,28	36,80	31,72	19,0	25,5	19
R1375.014	14	Ø16	47,45	42,80	37,72	19,0	27,0	19
R1375.015	15	Ø16	50,55	45,82	40,74	19,0	35,0	20
R1375.016	16	Ø16	53,62	48,82	43,74	19,0	38,0	24
R1375.018	18	Ø16	59,84	54,84	49,56	19,0	31,8	27
R1375.020	20	Ø16	65,86	60,88	55,80	22,2	38,0	30
R1375.024	24	Ø16	78,08	72,97	67,89	22,2	50,8	30
R1375.026	26	Ø16	84,18	79,02	73,94	22,2	57,0	36,5
R1375.030	30	Ø16	96,34	91,14	86,06	22,2	57,0	36,5
R1375.035	35	Ø16	111,56	105,11	101,17	22,2	57,0	36,5
R1375.036	36	Ø16	114,58	109,30	104,22	22,2	57,0	36,5
R1375.040	40	Ø16	126,75	121,41	116,33	22,2	63,5	45
R1375.045	45	Ø16	141,94	136,55	131,47	25,5	70,0	45

linear and rotary motion components

Automation