

# R1475



**Material**  
Neoprene (black). Fibreglass reinforced.

**Technical Notes**


- High Ratios.
- Allows use of small diameter pulleys.
- High speeds.
- High power transmission.
- Long life.
- Wear resistant nylon facing.
- Low profile.
- Quiet operation.
- Max speed up to 10,000 rpm.
- Max operating tension 105N.
- Minimum pulley diameter 17,5 (11 grooves).
- Temperature range +85°C to -34°C.

**Important Notes**

Operates with TP5 (R1480-R1495) pulleys.

## Timing Belts - 5mm circular pitch (HTD)

belt width 6mm

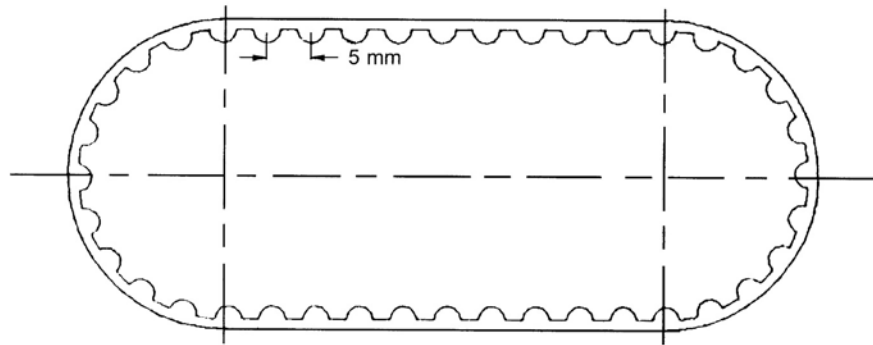



Order No.	No. of Grooves	Pitch Length
TB5EF6M-64	64	320
TB5EF6M-70	70	350
TB5EF6M-75	75	375
TB5EF6M-80	80	400
TB5EF6M-85	85	425
TB5EF6M-90	90	450
TB5EF6M-100	100	500
TB5EF6M-104	104	520
TB5EF6M-107	107	535
TB5EF6M-113	113	565
TB5EF6M-120	120	600
TB5EF6M-127	127	635
TB5EF6M-133	133	665
TB5EF6M-142	142	710
TB5EF6M-148	148	740
TB5EF6M-160	160	800
TB5EF6M-166	166	830
TB5EF6M-178	178	890
TB5EF6M-185	185	925
TB5EF6M-190	190	950
TB5EF6M-200	200	1000
TB5EF6M-210	210	1050
TB5EF6M-225	225	1125
TB5EF6M-254	254	1270
TB5EF6M-284	284	1420
TB5EF6M-319	319	1595
TB5EF6M-358	358	1790
TB5EF6M-360	360	1800
TB5EF6M-379	379	1895
TB5EF6M-400	400	2000
TB5EF6M-505	505	2525

BELTS & PULLEYS



## Timing Belts - 5mm circular pitch (HTD)

belt with 9mm

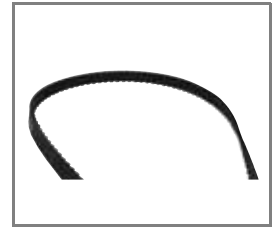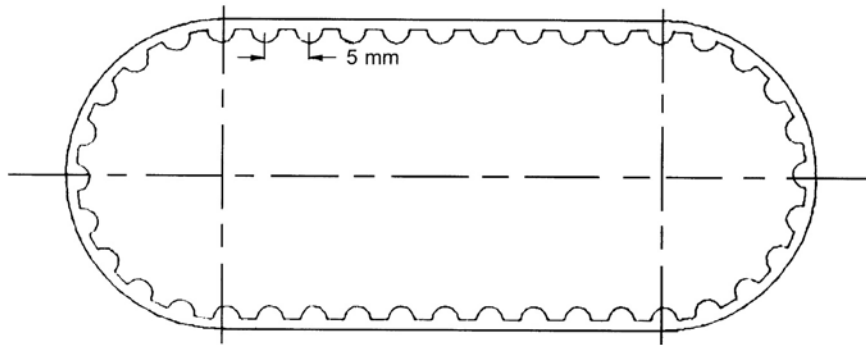

# R1475



**Material**  
Neoprene (black). Fibreglass reinforced.

**Technical Notes**

High Ratios.  
Allows use of small diameter pulleys.  
High speeds.  
High power transmission.  
Long life.  
Wear resistant nylon facing.  
Low profile.  
Quiet operation.  
Max speed up to 10,000 rpm.  
Max operating tension 155N.  
Minimum pulley diameter 17,5 (11 grooves).  
Temperature range +85°C to -34°C.

**Important Notes**

Operates with TP5 (R1480-R1495) pulleys.

Order No.	No. of Grooves	Pitch Length
TB5EF9M-33	33	165
TB5EF9M-37	37	185
TB5EF9M-40	40	200
TB5EF9M-45	45	225
TB5EF9M-52	52	260
TB5EF9M-54	54	270
TB5EF9M-55	55	275
TB5EF9M-56	56	280
TB5EF9M-60	60	300
TB5EF9M-64	64	320
TB5EF9M-70	70	350
TB5EF9M-75	75	375
TB5EF9M-80	80	400
TB5EF9M-85	85	425
TB5EF9M-90	90	450
TB5EF9M-100	100	500
TB5EF9M-104	104	520
TB5EF9M-107	107	535
TB5EF9M-113	113	565
TB5EF9M-120	120	600
TB5EF9M-127	127	635
TB5EF9M-133	133	665
TB5EF9M-142	142	710
TB5EF9M-148	148	740
TB5EF9M-160	160	800
TB5EF9M-166	166	830
TB5EF9M-178	178	890
TB5EF9M-185	185	925
TB5EF9M-190	190	950
TB5EF9M-200	200	1000
TB5EF9M-210	210	1050
TB5EF9M-225	225	1125
TB5EF9M-254	254	1270
TB5EF9M-284	284	1420
TB5EF9M-319	319	1595
TB5EF9M-358	358	1790
TB5EF9M-360	360	1800
TB5EF9M-379	379	1895
TB5EF9M-400	400	2000
TB5EF9M-505	505	2525

BELTS & PULLEYS

