


Single Flange Timing Pulleys - circ. pitch 5mm HTD for belts width 6-9mm



R1490

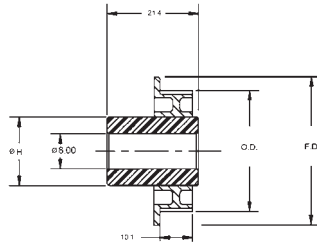


Material
Polycarbonate Lexan, fibreglass reinforced.

Important Notes

Operates with TB5 (R1475) timing belts.

Order No.	Bore +0,036 -0,000	No. of teeth	O.D. Ø	P.D. Ø	F.D. Ø	H
TP5L4U9M-11	4	11	16,4	17,5	22	17
TP5L4U9M-12	4	12	18,0	19,1	24	17
TP5L4U9M-13	4	13	19,6	20,7	25	17
TP5L4U9M-14	4	14	21,1	22,2	27	17
TP5L6U9M-15	6	15	22,7	23,8	30	19
TP5L6U9M-16	6	16	24,3	25,4	30	19
TP5L6U9M-17	6	17	25,9	27,0	32	19
TP5L6U9M-18	6	18	27,5	28,6	33	19
TP5L6U9M-19	6	19	29,1	30,2	35	19
TP5L6U9M-20	6	20	30,7	31,8	37	19
TP5L6U9M-22	6	22	33,9	35,0	40	22
TP5L6U9M-25	6	27	38,7	39,8	45	22
TP5L6U9M-28	6	28	43,4	44,5	50	22
TP5L6U9M-29	6	29	45,0	46,1	51	22
TP5L6U9M-30	6	30	46,6	47,7	53	22
TP5L8U9M-40	8	40	62,5	63,6	69	22
TP5L8U9M-50	8	50	78,4	79,5	84	22

Double Flange Timing Pulleys - circ. pitch 5mm HTD for belts width 6-9mm

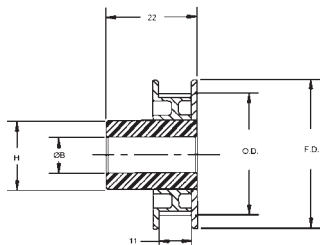

R1495



Material
Polycarbonate Lexan, fibreglass reinforced.

Important Notes

Operates with TB5 (R1475) timing belts.

Order No.	Bore +0,036 -0,000	No. of teeth	O.D. Ø	P.D. Ø	F.D. Ø	H
TP5L4W9M-11	4	11	16,4	17,5	22	17
TP5L4W9M-12	4	12	18,0	19,1	24	17
TP5L4W9M-13	4	13	19,6	20,7	25	17
TP5L4W9M-14	4	14	21,1	22,2	27	17
TP5L6W9M-15	6	15	22,7	23,8	30	19
TP5L6W9M-16	6	16	24,3	25,4	30	19
TP5L6W9M-17	6	17	25,9	27,0	32	19
TP5L6W9M-18	6	18	27,5	28,6	33	19
TP5L6W9M-19	6	19	29,1	30,2	35	19
TP5L6W9M-20	6	20	30,7	31,8	37	19
TP5L6W9M-22	6	22	33,9	35,0	40	22
TP5L6W9M-25	6	27	38,7	39,8	45	22
TP5L6W9M-28	6	28	43,4	44,5	50	22
TP5L6W9M-29	6	29	45,0	46,1	51	22
TP5L6W9M-30	6	30	46,6	47,7	53	22
TP5L8W9M-40	8	40	62,5	63,6	69	22
TP5L8W9M-50	8	50	78,4	79,5	84	22

BELTS & PULLEYS

