


15mm Linear Guide Rail

standard, blackened

Linear Guideways

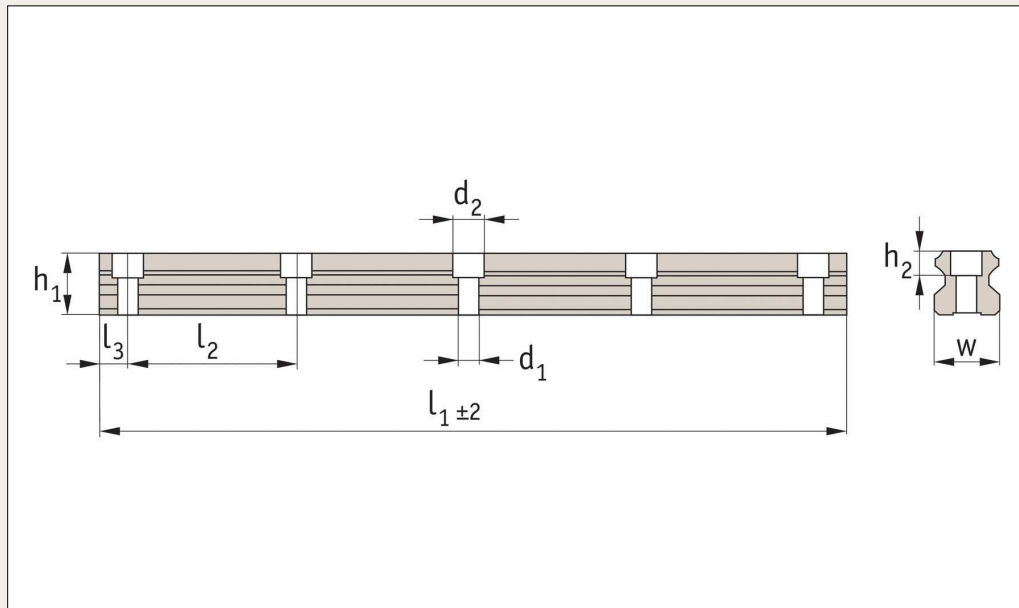

L1016.BL15

Material

Hardened and ground steel (typically 60 HRC). Black oxide.

For carriages to suit the required load see part nos. L1016.F (flanged) and L1016.U (unflanged).
Other rail lengths on request.
Weight: 1,4 Kg/m.

Tips

Plastic screw covers issued with the rails to protect screw holes from debris.

Technical notes

Order No.	Rail size	l_1	l_2	l_3	h_1	h_2	w	d_1	d_2	For screws
L1016.BL15-0160	15	160	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0220	15	220	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0280	15	280	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0340	15	340	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0400	15	400	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0460	15	460	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0520	15	520	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0580	15	580	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0640	15	640	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0700	15	700	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0760	15	760	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0820	15	820	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0880	15	880	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-0940	15	940	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1000	15	1000	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1060	15	1060	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1120	15	1120	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1180	15	1180	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1240	15	1240	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1300	15	1300	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1360	15	1360	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1420	15	1420	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1480	15	1480	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1540	15	1540	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1600	15	1600	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1660	15	1660	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1720	15	1720	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1780	15	1780	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1840	15	1840	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1900	15	1900	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-1960	15	1960	60	20	13,0	6,0	15	4,5	7,5	M4

15mm Linear Guide Rail

standard, blackened

Linear Guideways

Order No.	Rail size	l_1	l_2	l_3	h_1	h_2	w	d_1	d_2	For screws
L1016.BL15-2020	15	2020	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2080	15	2080	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2140	15	2140	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2200	15	2220	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2260	15	2260	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2320	15	2320	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2380	15	2380	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2440	15	2440	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2500	15	2500	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2560	15	2560	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2620	15	2620	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2680	15	2680	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2740	15	2740	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2800	15	2800	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2860	15	2860	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2920	15	2920	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-2980	15	2980	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3040	15	3040	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3100	15	3100	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3160	15	3160	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3220	15	3220	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3280	15	3280	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3340	15	3340	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3400	15	3400	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3460	15	3460	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3520	15	3520	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3580	15	3580	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3640	15	3640	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3700	15	3700	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3760	15	3760	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3820	15	3820	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3880	15	3880	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-3940	15	3940	60	20	13,0	6,0	15	4,5	7,5	M4
L1016.BL15-4000	15	4000	60	20	13,0	6,0	15	4,5	7,5	M4