


# 30mm Linear Guide Rail

rear fixing

Linear Guideways

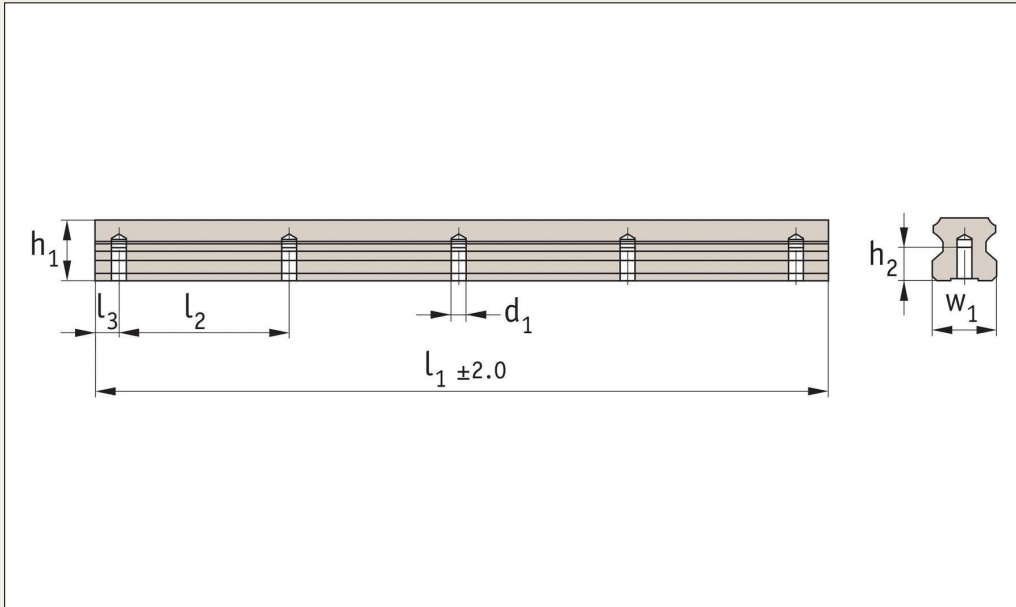

## L1016.RF30

### 0

#### Material

Hardened and ground steel (typically 60 HRC).

#### Technical notes

For carriages to suit the required load see part nos. L1016.F (flanged) and

L1016.U (unflanged).

Other rail lengths on request.  
Weight: 5,2 Kg/m.

Order No.	Rail size	$l_1$	$l_2$	$l_3$	$h_1$	$h_2$	w	d
L1016.RF30-0200	30	200	80	20	22,8	15	28	M8
L1016.RF30-0280	30	280	80	20	22,8	15	28	M8
L1016.RF30-0360	30	360	80	20	22,8	15	28	M8
L1016.RF30-0440	30	440	80	20	22,8	15	28	M8
L1016.RF30-0520	30	520	80	20	22,8	15	28	M8
L1016.RF30-0600	30	600	80	20	22,8	15	28	M8
L1016.RF30-0680	30	680	80	20	22,8	15	28	M8
L1016.RF30-0760	30	760	80	20	22,8	15	28	M8
L1016.RF30-0840	30	840	80	20	22,8	15	28	M8
L1016.RF30-0920	30	920	80	20	22,8	15	28	M8
L1016.RF30-1000	30	1000	80	20	22,8	15	28	M8
L1016.RF30-1080	30	1080	80	20	22,8	15	28	M8
L1016.RF30-1160	30	1160	80	20	22,8	15	28	M8
L1016.RF30-1240	30	1240	80	20	22,8	15	28	M8
L1016.RF30-1320	30	1320	80	20	22,8	15	28	M8
L1016.RF30-1400	30	1400	80	20	22,8	15	28	M8
L1016.RF30-1480	30	1480	80	20	22,8	15	28	M8
L1016.RF30-1560	30	1560	80	20	22,8	15	28	M8
L1016.RF30-1640	30	1640	80	20	22,8	15	28	M8
L1016.RF30-1720	30	1720	80	20	22,8	15	28	M8
L1016.RF30-1800	30	1800	80	20	22,8	15	28	M8
L1016.RF30-1880	30	1880	80	20	22,8	15	28	M8
L1016.RF30-1960	30	1960	80	20	22,8	15	28	M8
L1016.RF30-2040	30	2040	80	20	22,8	15	28	M8
L1016.RF30-2120	30	2120	80	20	22,8	15	28	M8
L1016.RF30-2200	30	2200	80	20	22,8	15	28	M8
L1016.RF30-2280	30	2280	80	20	22,8	15	28	M8
L1016.RF30-2360	30	2360	80	20	22,8	15	28	M8
L1016.RF30-2440	30	2440	80	20	22,8	15	28	M8
L1016.RF30-2520	30	2520	80	20	22,8	15	28	M8
L1016.RF30-2600	30	2600	80	20	22,8	15	28	M8
L1016.RF30-2680	30	2680	80	20	22,8	15	28	M8
L1016.RF30-2760	30	2760	80	20	22,8	15	28	M8
L1016.RF30-2840	30	2840	80	20	22,8	15	28	M8

# 30mm Linear Guide Rail

rear fixing

Linear Guideways

Order No.	Rail size	$l_1$	$l_2$	$l_3$	$h_1$	$h_2$	w	d
L1016.RF30-2920	30	2920	80	20	22,8	15	28	M8
L1016.RF30-3000	30	3000	80	20	22,8	15	28	M8
L1016.RF30-3080	30	3080	80	20	22,8	15	28	M8
L1016.RF30-3160	30	3160	80	20	22,8	15	28	M8
L1016.RF30-3240	30	3240	80	20	22,8	15	28	M8
L1016.RF30-3320	30	3320	80	20	22,8	15	28	M8
L1016.RF30-3400	30	3400	80	20	22,8	15	28	M8
L1016.RF30-3480	30	3480	80	20	22,8	15	28	M8
L1016.RF30-3560	30	3560	80	20	22,8	15	28	M8
L1016.RF30-3640	30	3640	80	20	22,8	15	28	M8
L1016.RF30-3720	30	3720	80	20	22,8	15	28	M8
L1016.RF30-3800	30	3800	80	20	22,8	15	28	M8
L1016.RF30-3880	30	3880	80	20	22,8	15	28	M8
L1016.RF30-3960	30	3960	80	20	22,8	15	28	M8
L1016.RF30-4000	30	4000	80	20	22,8	15	28	M8