


Fully Telescopic Slides

ultra heavy-duty

Telescopic Slides

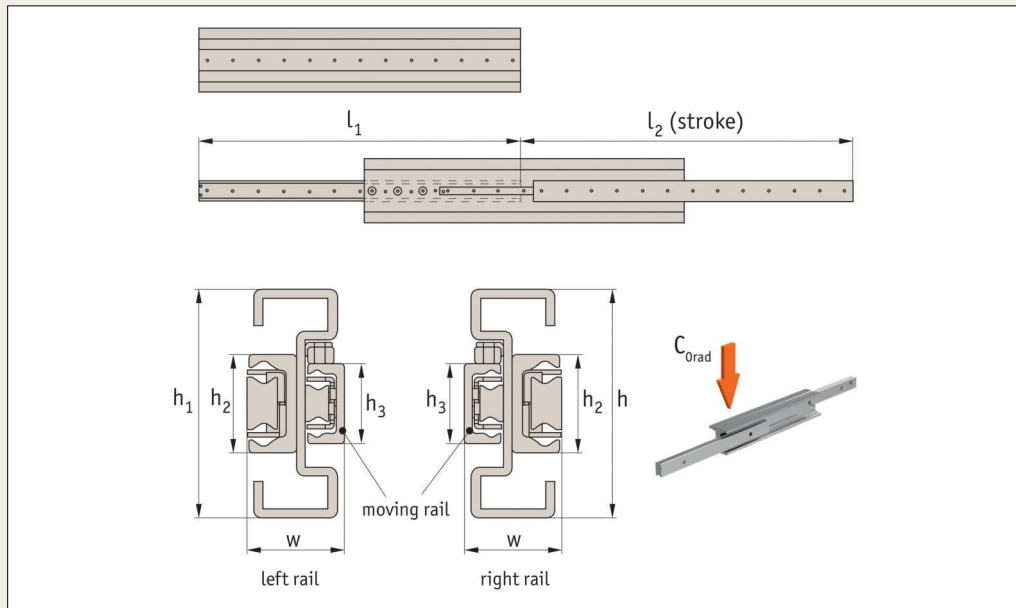

L1995

Material

Cold drawn bearing steel, raceways hardened to 60 HRC. Balls - hardened steel.
Zinc coating to ISO 2081 (excluding raceways). Corrosion resistant coatings available on request.

Technical notes

These are ultra heavy load capacity. They can support heavy loads with continuous movements 24 hours per day, 7 days a week - even with vibration and high stroke frequency. Optimal balance between high performance and light-weight.
 C_{0rad} is the load rating for a single

telescopic slide.

Moving rail must be lower rail (unless technical department consulted).

Tips

Moving element smaller than the fixed one.

These are handed rails - ie left and right hands to be specified.

Order No.	Type	l_1	l_2 Stroke	h_1	w	h_2	h_3	Max. load (per rail) C_{0rad} N
L1995.43-0530R	Right	530	552	100	43	43	35	2389
L1995.43-0610R	Right	610	620	100	43	43	35	2960
L1995.43-0690R	Right	690	726	100	43	43	35	3091
L1995.43-0770R	Right	770	793	100	43	43	35	3662
L1995.43-0850R	Right	850	860	100	43	43	35	4242
L1995.43-0930R	Right	930	966	100	43	43	35	4365
L1995.43-1010R	Right	1010	1033	100	43	43	35	4942
L1995.43-1090R	Right	1090	1100	100	43	43	35	5524
L1995.43-1170R	Right	1170	1206	100	43	43	35	5144
L1995.43-1250R	Right	1250	1273	100	43	43	35	4930
L1995.43-1330R	Right	1330	1379	100	43	43	35	4474
L1995.43-1440R	Right	1446	1446	100	43	43	35	4311
L1995.43-1490R	Right	1490	1513	100	43	43	35	4159
L1995.43-1570R	Right	1570	1607	100	43	43	35	4886
L1995.43-1650R	Right	1650	1686	100	43	43	35	3710
L1995.43-1730R	Right	1730	1753	100	43	43	35	3597
L1995.43-1810R	Right	1810	1847	100	43	43	35	3391
L1995.43-1890R	Right	1890	1926	100	43	43	35	3256
L1995.43-1970R	Right	1790	2020	100	43	43	35	3086
L1995.43-0530L	Left	530	552	100	43	43	35	2389
L1995.43-0610L	Left	610	620	100	43	43	35	2960
L1995.43-0690L	Left	690	726	100	43	43	35	3091
L1995.43-0770L	Left	770	793	100	43	43	35	3662
L1995.43-0850L	Left	850	860	100	43	43	35	4242
L1995.43-0930L	Left	930	966	100	43	43	35	4365

Fully Telescopic Slides

ultra heavy-duty

Telescopic Slides

Order No.	Type	l_1	l_2 Stroke	h_1	w	h_2	h_3	Max. load (per rail) C_{0rad} N
L1995.43-1010L	Left	1010	1033	100	43	43	35	4942
L1995.43-1090L	Left	1090	1100	100	43	43	35	5524
L1995.43-1170L	Left	1170	1206	100	43	43	35	5144
L1995.43-1250L	Left	1250	1273	100	43	43	35	4930
L1995.43-1330L	Left	1330	1379	100	43	43	35	4474
L1995.43-1440L	Left	1446	1446	100	43	43	35	4311
L1995.43-1490L	Left	1490	1513	100	43	43	35	4159
L1995.43-1570L	Left	1570	1607	100	43	43	35	4886
L1995.43-1650L	Left	1650	1686	100	43	43	35	3710
L1995.43-1730L	Left	1730	1753	100	43	43	35	3597
L1995.43-1810L	Left	1810	1847	100	43	43	35	3391
L1995.43-1890L	Left	1890	1926	100	43	43	35	3256
L1995.43-1970L	Left	1790	2020	100	43	43	35	3086