




Threaded Plastic Inserts for Hollow no bush



Other Mechanical Parts

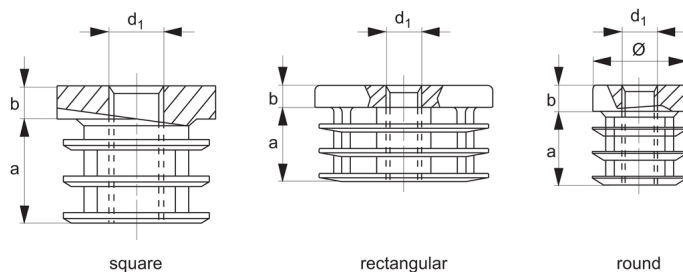

P1970

OTHER MECHANICAL PARTS

Material

Thermoplastic, black. Moulded thread.


Technical Notes

For use with fixed feet.


Tips

M 8 available on request, subject to minimum order quantity.

Order No.	Type	Tube size mm	d_1	a	b
P1970.40-40	Square	40x40	M10	22	6

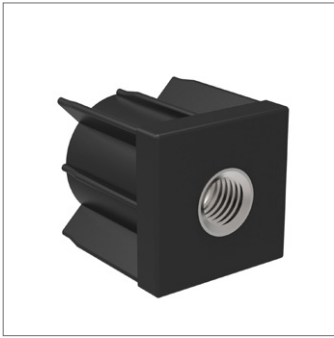

P1974

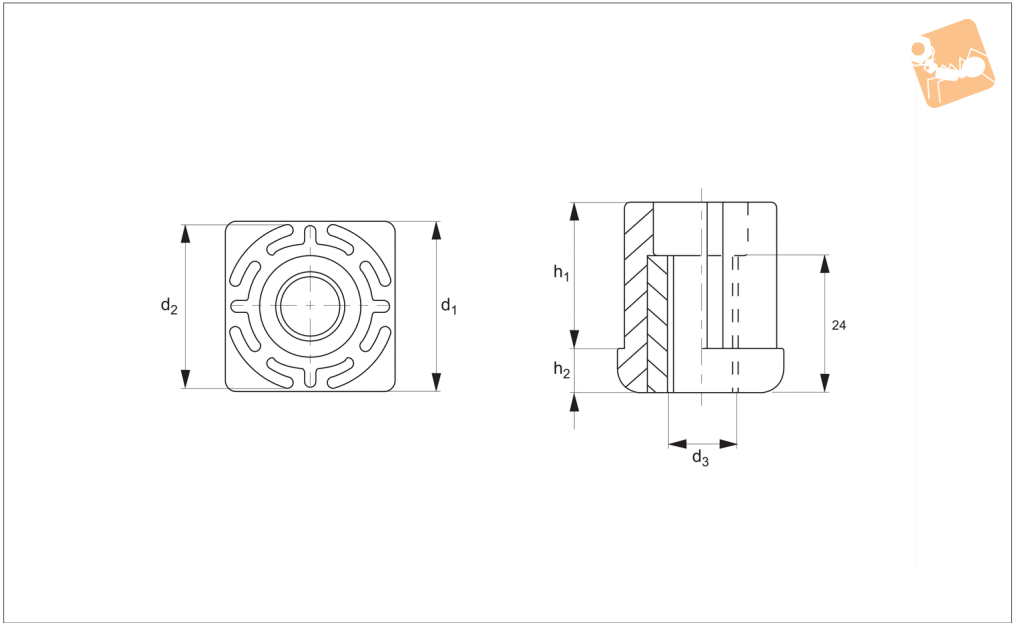

Material

Body: polyamide reinforced nylon.
Bush: brass, nickel plated.

Technical Notes



For use with levelling feet parts.

Order No.	Outerbox d_1	Innerbox d_2	d_3	h_1	h_2	Rec. load kg max.
P1974.212	40x40x1,5	37	M12	35	8	1000





Threaded Plastic Insert for Hollow with stainless steel bush

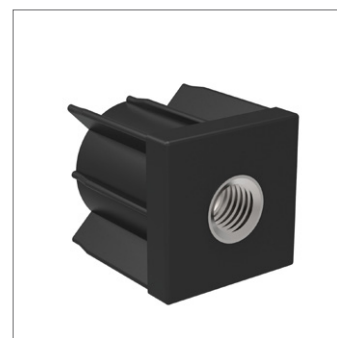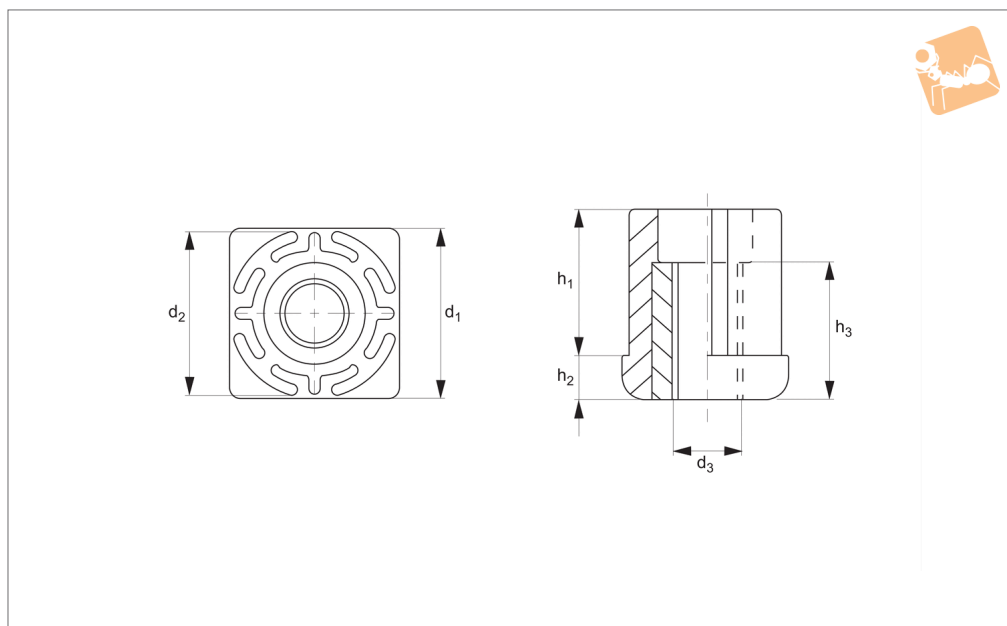

P1975

OTHER MECHANICAL PARTS

Material

Bush: stainless steel, type AISI 303.

Moulding: polyamide reinforced nylon.

Order No.	Outerbox d_1	Innerbox d_2	d_3	h_1	h_2	h_3	Load capacity for static load kg max.
P1975.112	30x30x1,5	27	M12	35	8	24	500
P1975.210	40x40x1,5	37	M10	35	8	24	1000