




Pan Head Pozi AB Tappers

Pozi AB - steel, zinc-plated



Self Tappers

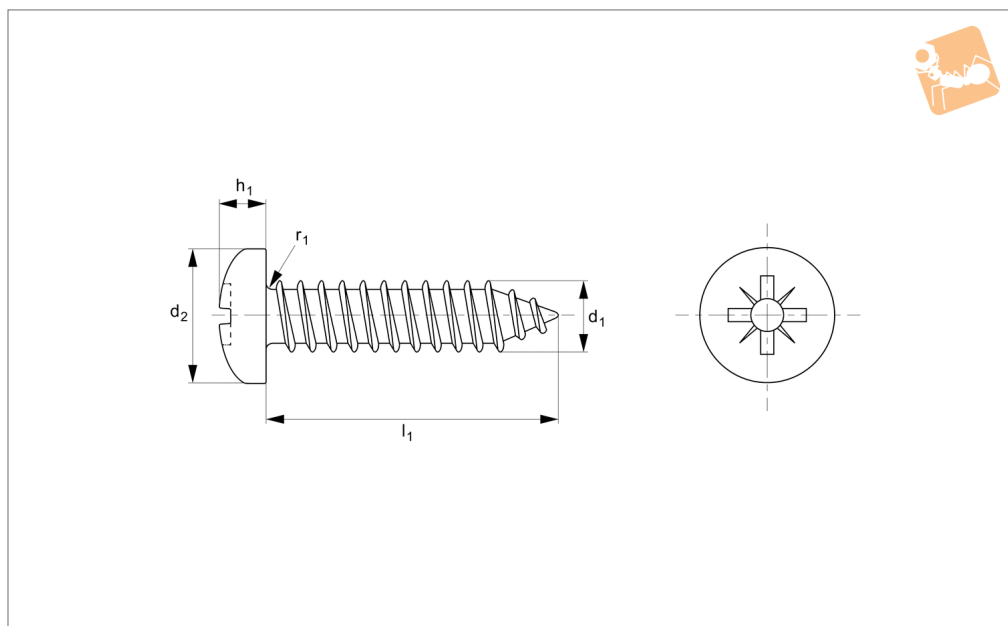

P0620.ZP

SELF TAPPERS


Material

Steel, zinc-plated (also available zinc-plated black passivated).

Technical Notes

To DIN 7981C-Z, ISO 7049 type C.

Order No.	d ₁	l ₁	d ₂	h ₁ max.	Size
P0620.022-006-ZP	2.2	6.5	4.2	1.8	PZ-1
P0620.022-009-ZP	2.2	9.5	4.2	1.8	PZ-1
P0620.022-013-ZP	2.2	13.0	4.2	1.8	PZ-1
P0620.022-016-ZP	2.2	16.0	4.2	1.8	PZ-1
P0620.022-019-ZP	2.2	19.0	4.2	1.8	PZ-1
P0620.022-022-ZP	2.2	22.0	4.2	1.8	PZ-1
P0620.022-025-ZP	2.2	25.0	4.2	1.8	PZ-1
P0620.022-032-ZP	2.2	32.0	4.2	1.8	PZ-1
P0620.029-006-ZP	2.9	6.5	5.6	2.2	PZ-1
P0620.029-009-ZP	2.9	9.5	5.6	2.2	PZ-1
P0620.029-013-ZP	2.9	13.0	5.6	2.2	PZ-1
P0620.029-016-ZP	2.9	16.0	5.6	2.2	PZ-1
P0620.029-019-ZP	2.9	19.0	5.6	2.2	PZ-1
P0620.029-022-ZP	2.9	22.0	5.6	2.2	PZ-1
P0620.029-025-ZP	2.9	25.0	5.6	2.2	PZ-1
P0620.029-032-ZP	2.9	32.0	5.6	2.2	PZ-1
P0620.029-038-ZP	2.9	38.0	5.6	2.2	PZ-1
P0620.035-006-ZP	3.5	6.5	6.9	2.6	PZ-2
P0620.035-009-ZP	3.5	9.5	6.9	2.6	PZ-2
P0620.035-013-ZP	3.5	13.0	6.9	2.6	PZ-2
P0620.035-016-ZP	3.5	16.0	6.9	2.6	PZ-2
P0620.035-019-ZP	3.5	19.0	6.9	2.6	PZ-2
P0620.035-022-ZP	3.5	22.0	6.9	2.6	PZ-2
P0620.035-025-ZP	3.5	25.0	6.9	2.6	PZ-2
P0620.035-032-ZP	3.5	32.0	6.9	2.6	PZ-2
P0620.035-038-ZP	3.5	38.0	6.9	2.6	PZ-2
P0620.035-045-ZP	3.5	45.0	6.9	2.6	PZ-2
P0620.035-050-ZP	3.5	50.0	6.9	2.6	PZ-2
P0620.035-060-ZP	3.5	60.0	6.9	2.6	PZ-2
P0620.039-006-ZP	3.9	6.5	7.5	2.8	PZ-2
P0620.039-009-ZP	3.9	9.5	7.5	2.8	PZ-2
P0620.039-013-ZP	3.9	13.0	7.5	2.8	PZ-2
P0620.039-016-ZP	3.9	16.0	7.5	2.8	PZ-2
P0620.039-019-ZP	3.9	19.0	7.5	2.8	PZ-2

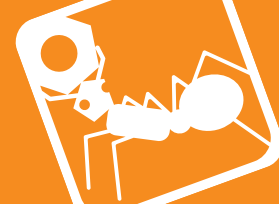

Order No.	d ₁	l ₁	d ₂	h ₁ max.	Size
P0620.039-022-ZP	3.9	22.0	7.5	2.8	PZ-2
P0620.039-025-ZP	3.9	25.0	7.5	2.8	PZ-2
P0620.039-032-ZP	3.9	32.0	7.5	2.8	PZ-2
P0620.039-038-ZP	3.9	38.0	7.5	2.8	PZ-2
P0620.039-045-ZP	3.9	45.0	7.5	2.8	PZ-2
P0620.039-050-ZP	3.9	50.0	7.5	2.8	PZ-2
P0620.039-060-ZP	3.9	60.0	7.5	2.8	PZ-2
P0620.039-070-ZP	3.9	70.0	7.5	2.8	PZ-2
P0620.039-080-ZP	3.9	80.0	7.5	2.8	PZ-2
P0620.042-006-ZP	4.2	6.5	8.2	3.05	PZ-2
P0620.042-009-ZP	4.2	9.5	8.2	3.05	PZ-2
P0620.042-013-ZP	4.2	13.0	8.2	3.05	PZ-2
P0620.042-016-ZP	4.2	16.0	8.2	3.05	PZ-2
P0620.042-019-ZP	4.2	19.0	8.2	3.05	PZ-2
P0620.042-022-ZP	4.2	22.0	8.2	3.05	PZ-2
P0620.042-025-ZP	4.2	25.0	8.2	3.05	PZ-2
P0620.042-032-ZP	4.2	32.0	8.2	3.05	PZ-2
P0620.042-038-ZP	4.2	38.0	8.2	3.05	PZ-2
P0620.042-045-ZP	4.2	45.0	8.2	3.05	PZ-2
P0620.042-050-ZP	4.2	50.0	8.2	3.05	PZ-2
P0620.042-060-ZP	4.2	60.0	8.2	3.05	PZ-2
P0620.042-070-ZP	4.2	70.0	8.2	3.05	PZ-2
P0620.042-080-ZP	4.2	80.0	8.2	3.05	PZ-2
P0620.048-006-ZP	4.8	6.5	9.5	3.55	PZ-2
P0620.048-009-ZP	4.8	9.5	9.5	3.55	PZ-2
P0620.048-013-ZP	4.8	13.0	9.5	3.55	PZ-2
P0620.048-016-ZP	4.8	16.0	9.5	3.55	PZ-2
P0620.048-019-ZP	4.8	19.0	9.5	3.55	PZ-2
P0620.048-022-ZP	4.8	22.0	9.5	3.55	PZ-2
P0620.048-025-ZP	4.8	25.0	9.5	3.55	PZ-2
P0620.048-032-ZP	4.8	32.0	9.5	3.55	PZ-2
P0620.048-038-ZP	4.8	38.0	9.5	3.55	PZ-2
P0620.048-045-ZP	4.8	45.0	9.5	3.55	PZ-2
P0620.048-050-ZP	4.8	50.0	9.5	3.55	PZ-2
P0620.048-060-ZP	4.8	60.0	9.5	3.55	PZ-2
P0620.048-070-ZP	4.8	70.0	9.5	3.55	PZ-2
P0620.048-080-ZP	4.8	80.0	9.5	3.55	PZ-2
P0620.048-090-ZP	4.8	90.0	9.5	3.55	PZ-2
P0620.048-100-ZP	4.8	100.0	9.5	3.55	PZ-2
P0620.055-006-ZP	5.5	6.5	10.8	3.95	PZ-3
P0620.055-009-ZP	5.5	9.5	10.8	3.95	PZ-3
P0620.055-013-ZP	5.5	13.0	10.8	3.95	PZ-3
P0620.055-016-ZP	5.5	16.0	10.8	3.95	PZ-3
P0620.055-019-ZP	5.5	19.0	10.8	3.95	PZ-3
P0620.055-022-ZP	5.5	22.0	10.8	3.95	PZ-3
P0620.055-025-ZP	5.5	25.0	10.8	3.95	PZ-3
P0620.055-032-ZP	5.5	32.0	10.8	3.95	PZ-3
P0620.055-038-ZP	5.5	38.0	10.8	3.95	PZ-3
P0620.055-045-ZP	5.5	45.0	10.8	3.95	PZ-3
P0620.055-050-ZP	5.5	50.0	10.8	3.95	PZ-3
P0620.055-060-ZP	5.5	60.0	10.8	3.95	PZ-3
P0620.055-070-ZP	5.5	70.0	10.8	3.95	PZ-3
P0620.055-080-ZP	5.5	80.0	10.8	3.95	PZ-3
P0620.055-090-ZP	5.5	90.0	10.8	3.95	PZ-3
P0620.055-100-ZP	5.5	100.0	10.8	3.95	PZ-3
P0620.063-013-ZP	6.3	13.0	12.5	4.55	PZ-3
P0620.063-016-ZP	6.3	16.0	12.5	4.55	PZ-3
P0620.063-019-ZP	6.3	19.0	12.5	4.55	PZ-3
P0620.063-022-ZP	6.3	22.0	12.5	4.55	PZ-3
P0620.063-025-ZP	6.3	25.0	12.5	4.55	PZ-3
P0620.063-032-ZP	6.3	32.0	12.5	4.55	PZ-3
P0620.063-038-ZP	6.3	38.0	12.5	4.55	PZ-3
P0620.063-045-ZP	6.3	45.0	12.5	4.55	PZ-3
P0620.063-050-ZP	6.3	50.0	12.5	4.55	PZ-3
P0620.063-060-ZP	6.3	60.0	12.5	4.55	PZ-3
P0620.063-070-ZP	6.3	70.0	12.5	4.55	PZ-3
P0620.063-080-ZP	6.3	80.0	12.5	4.55	PZ-3
P0620.063-090-ZP	6.3	90.0	12.5	4.55	PZ-3



Pan Head Pozi AB Tappers


Pozi AB - steel, zinc-plated




Self Tappers

Order No.	d_1	l_1	d_2	h_1 max.	Size
P0620.063-100-ZP	6.3	100.0	12.5	4.55	PZ-3

SELF TAPPERS

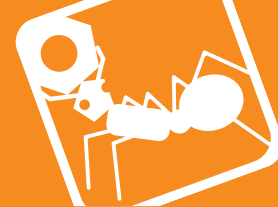

P0620.A4

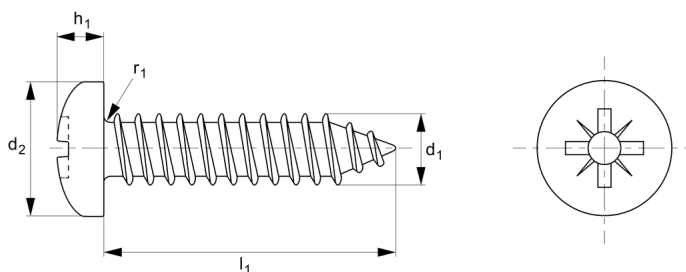

Material

Stainless steel (A4, AISI 316).

Technical Notes

To DIN 7981C-Z, ISO 7049 type C.

Order No.	d ₁	l ₁	d ₂	h ₁ max.	Size
P0620.022-006-A4	2.2	6.5	4.2	1.8	PZ-1
P0620.022-009-A4	2.2	9.5	4.2	1.8	PZ-1
P0620.022-013-A4	2.2	13.0	4.2	1.8	PZ-1
P0620.022-016-A4	2.2	16.0	4.2	1.8	PZ-1
P0620.022-019-A4	2.2	19.0	4.2	1.8	PZ-1
P0620.022-022-A4	2.2	22.0	4.2	1.8	PZ-1
P0620.022-025-A4	2.2	25.0	4.2	1.8	PZ-1
P0620.022-032-A4	2.2	32.0	4.2	1.8	PZ-1
P0620.029-006-A4	2.9	6.5	5.6	2.2	PZ-1
P0620.029-009-A4	2.9	9.5	5.6	2.2	PZ-1
P0620.029-013-A4	2.9	13.0	5.6	2.2	PZ-1
P0620.029-016-A4	2.9	16.0	5.6	2.2	PZ-1
P0620.029-019-A4	2.9	19.0	5.6	2.2	PZ-1
P0620.029-022-A4	2.9	22.0	5.6	2.2	PZ-1
P0620.029-025-A4	2.9	25.0	5.6	2.2	PZ-1
P0620.029-032-A4	2.9	32.0	5.6	2.2	PZ-1
P0620.029-038-A4	2.9	38.0	5.6	2.2	PZ-1
P0620.035-006-A4	3.5	6.5	6.9	2.6	PZ-2
P0620.035-009-A4	3.5	9.5	6.9	2.6	PZ-2
P0620.035-013-A4	3.5	13.0	6.9	2.6	PZ-2
P0620.035-016-A4	3.5	16.0	6.9	2.6	PZ-2
P0620.035-019-A4	3.5	19.0	6.9	2.6	PZ-2
P0620.035-022-A4	3.5	22.0	6.9	2.6	PZ-2
P0620.035-025-A4	3.5	25.0	6.9	2.6	PZ-2
P0620.035-032-A4	3.5	32.0	6.9	2.6	PZ-2
P0620.035-038-A4	3.5	38.0	6.9	2.6	PZ-2
P0620.035-045-A4	3.5	45.0	6.9	2.6	PZ-2
P0620.035-050-A4	3.5	50.0	6.9	2.6	PZ-2
P0620.035-060-A4	3.5	60.0	6.9	2.6	PZ-2
P0620.039-006-A4	3.9	6.5	7.5	2.8	PZ-2
P0620.039-009-A4	3.9	9.5	7.5	2.8	PZ-2
P0620.039-013-A4	3.9	13.0	7.5	2.8	PZ-2
P0620.039-016-A4	3.9	16.0	7.5	2.8	PZ-2
P0620.039-019-A4	3.9	19.0	7.5	2.8	PZ-2



Stainless Pan Head Pozi AB Tappers


Pozi AB - A4 stainless



Self Tappers

SELF TAPPERS

Order No.	d ₁	l ₁	d ₂	h ₁ max.	Size
P0620.039-022-A4	3.9	22.0	7.5	2.8	PZ-2
P0620.039-025-A4	3.9	25.0	7.5	2.8	PZ-2
P0620.039-032-A4	3.9	32.0	7.5	2.8	PZ-2
P0620.039-038-A4	3.9	38.0	7.5	2.8	PZ-2
P0620.039-045-A4	3.9	45.0	7.5	2.8	PZ-2
P0620.039-050-A4	3.9	50.0	7.5	2.8	PZ-2
P0620.039-060-A4	3.9	60.0	7.5	2.8	PZ-2
P0620.039-070-A4	3.9	70.0	7.5	2.8	PZ-2
P0620.039-080-A4	3.9	80.0	7.5	2.8	PZ-2
P0620.042-006-A4	4.2	6.5	8.2	3.05	PZ-2
P0620.042-009-A4	4.2	9.5	8.2	3.05	PZ-2
P0620.042-013-A4	4.2	13.0	8.2	3.05	PZ-2
P0620.042-016-A4	4.2	16.0	8.2	3.05	PZ-2
P0620.042-019-A4	4.2	19.0	8.2	3.05	PZ-2
P0620.042-022-A4	4.2	22.0	8.2	3.05	PZ-2
P0620.042-025-A4	4.2	25.0	8.2	3.05	PZ-2
P0620.042-032-A4	4.2	32.0	8.2	3.05	PZ-2
P0620.042-038-A4	4.2	38.0	8.2	3.05	PZ-2
P0620.042-045-A4	4.2	45.0	8.2	3.05	PZ-2
P0620.042-050-A4	4.2	50.0	8.2	3.05	PZ-2
P0620.042-060-A4	4.2	60.0	8.2	3.05	PZ-2
P0620.042-070-A4	4.2	70.0	8.2	3.05	PZ-2
P0620.042-080-A4	4.2	80.0	8.2	3.05	PZ-2
P0620.048-006-A4	4.8	6.5	9.5	3.55	PZ-2
P0620.048-009-A4	4.8	9.5	9.5	3.55	PZ-2
P0620.048-013-A4	4.8	13.0	9.5	3.55	PZ-2
P0620.048-016-A4	4.8	16.0	9.5	3.55	PZ-2
P0620.048-019-A4	4.8	19.0	9.5	3.55	PZ-2
P0620.048-022-A4	4.8	22.0	9.5	3.55	PZ-2
P0620.048-025-A4	4.8	25.0	9.5	3.55	PZ-2
P0620.048-032-A4	4.8	32.0	9.5	3.55	PZ-2
P0620.048-038-A4	4.8	38.0	9.5	3.55	PZ-2
P0620.048-045-A4	4.8	45.0	9.5	3.55	PZ-2
P0620.048-050-A4	4.8	50.0	9.5	3.55	PZ-2
P0620.048-060-A4	4.8	60.0	9.5	3.55	PZ-2
P0620.048-070-A4	4.8	70.0	9.5	3.55	PZ-2
P0620.048-080-A4	4.8	80.0	9.5	3.55	PZ-2
P0620.048-090-A4	4.8	90.0	9.5	3.55	PZ-2
P0620.048-100-A4	4.8	100.0	9.5	3.55	PZ-2
P0620.055-006-A4	5.5	6.5	10.8	3.95	PZ-3
P0620.055-009-A4	5.5	9.5	10.8	3.95	PZ-3
P0620.055-013-A4	5.5	13.0	10.8	3.95	PZ-3
P0620.055-016-A4	5.5	16.0	10.8	3.95	PZ-3
P0620.055-019-A4	5.5	19.0	10.8	3.95	PZ-3
P0620.055-022-A4	5.5	22.0	10.8	3.95	PZ-3
P0620.055-025-A4	5.5	25.0	10.8	3.95	PZ-3
P0620.055-032-A4	5.5	32.0	10.8	3.95	PZ-3
P0620.055-038-A4	5.5	38.0	10.8	3.95	PZ-3
P0620.055-045-A4	5.5	45.0	10.8	3.95	PZ-3
P0620.055-050-A4	5.5	50.0	10.8	3.95	PZ-3
P0620.055-060-A4	5.5	60.0	10.8	3.95	PZ-3
P0620.055-070-A4	5.5	70.0	10.8	3.95	PZ-3
P0620.055-080-A4	5.5	80.0	10.8	3.95	PZ-3
P0620.055-090-A4	5.5	90.0	10.8	3.95	PZ-3
P0620.055-100-A4	5.5	100.0	10.8	3.95	PZ-3
P0620.063-013-A4	6.3	13.0	12.5	4.55	PZ-3
P0620.063-016-A4	6.3	16.0	12.5	4.55	PZ-3
P0620.063-019-A4	6.3	19.0	12.5	4.55	PZ-3
P0620.063-022-A4	6.3	22.0	12.5	4.55	PZ-3
P0620.063-025-A4	6.3	25.0	12.5	4.55	PZ-3
P0620.063-032-A4	6.3	32.0	12.5	4.55	PZ-3
P0620.063-038-A4	6.3	38.0	12.5	4.55	PZ-3
P0620.063-045-A4	6.3	45.0	12.5	4.55	PZ-3
P0620.063-050-A4	6.3	50.0	12.5	4.55	PZ-3
P0620.063-060-A4	6.3	60.0	12.5	4.55	PZ-3
P0620.063-070-A4	6.3	70.0	12.5	4.55	PZ-3
P0620.063-080-A4	6.3	80.0	12.5	4.55	PZ-3
P0620.063-090-A4	6.3	90.0	12.5	4.55	PZ-3

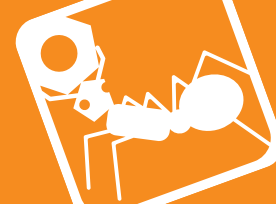

Order No.	d_1	l_1	d_2	h_1 max.	Size
P0620.063-100-A4	6.3	100.0	12.5	4.55	PZ-3





Pan Head Phillips AB Tappers

Phillips AB - steel, zinc-plated



Self Tappers

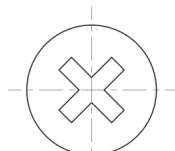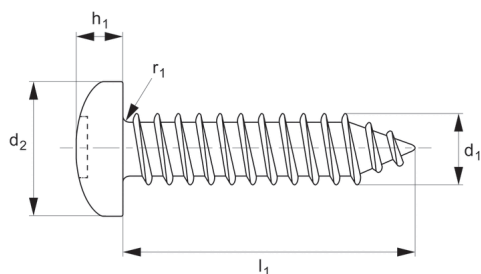

P0621.ZP

SELF TAPPERS


Material

Steel, zinc-plated (also available zinc-plated black passivated).

Technical Notes

To DIN 7981C-H, ISO 7049 type C.

Order No.	d ₁	l ₁	d ₂	h ₁ max.	Size
P0621.022-004-ZP	2.2	4.5	4.2	1.8	PH-1
P0621.022-006-ZP	2.2	6.5	4.2	1.8	PH-1
P0621.022-009-ZP	2.2	9.5	4.2	1.8	PH-1
P0621.022-013-ZP	2.2	13.0	4.2	1.8	PH-1
P0621.022-016-ZP	2.2	16.0	4.2	1.8	PH-1
P0621.022-019-ZP	2.2	19.0	4.2	1.8	PH-1
P0621.022-022-ZP	2.2	22.0	4.2	1.8	PH-1
P0621.022-025-ZP	2.2	25.0	4.2	1.8	PH-1
P0621.022-032-ZP	2.2	32.0	4.2	1.8	PH-1
P0621.029-006-ZP	2.9	6.5	5.6	2.2	PH-1
P0621.029-009-ZP	2.9	9.5	5.6	2.2	PH-1
P0621.029-013-ZP	2.9	13.0	5.6	2.2	PH-1
P0621.029-016-ZP	2.9	16.0	5.6	2.2	PH-1
P0621.029-019-ZP	2.9	19.0	5.6	2.2	PH-1
P0621.029-022-ZP	2.9	22.0	5.6	2.2	PH-1
P0621.029-025-ZP	2.9	25.0	5.6	2.2	PH-1
P0621.029-032-ZP	2.9	32.0	5.6	2.2	PH-1
P0621.029-038-ZP	2.9	38.0	5.6	2.2	PH-1
P0621.035-006-ZP	3.5	6.5	6.9	2.6	PH-2
P0621.035-009-ZP	3.5	9.5	6.9	2.6	PH-2
P0621.035-013-ZP	3.5	13.0	6.9	2.6	PH-2
P0621.035-016-ZP	3.5	16.0	6.9	2.6	PH-2
P0621.035-019-ZP	3.5	19.0	6.9	2.6	PH-2
P0621.035-022-ZP	3.5	22.0	6.9	2.6	PH-2
P0621.035-025-ZP	3.5	25.0	6.9	2.6	PH-2
P0621.035-032-ZP	3.5	32.0	6.9	2.6	PH-2
P0621.035-038-ZP	3.5	38.0	6.9	2.6	PH-2
P0621.035-045-ZP	3.5	45.0	6.9	2.6	PH-2
P0621.035-050-ZP	3.5	50.0	6.9	2.6	PH-2
P0621.035-060-ZP	3.5	60.0	6.9	2.6	PH-2
P0621.035-070-ZP	3.5	70.0	6.9	2.6	PH-2
P0621.039-006-ZP	3.9	6.5	7.5	2.8	PH-2
P0621.039-009-ZP	3.9	9.5	7.5	2.8	PH-2
P0621.039-013-ZP	3.9	13.0	7.5	2.8	PH-2

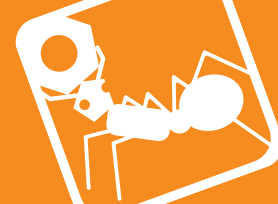

Order No.	d ₁	l ₁	d ₂	h ₁ max.	Size
P0621.039-016-ZP	3.9	16.0	7.5	2.8	PH-2
P0621.039-019-ZP	3.9	19.0	7.5	2.8	PH-2
P0621.039-022-ZP	3.9	22.0	7.5	2.8	PH-2
P0621.039-025-ZP	3.9	25.0	7.5	2.8	PH-2
P0621.039-032-ZP	3.9	32.0	7.5	2.8	PH-2
P0621.039-038-ZP	3.9	38.0	7.5	2.8	PH-2
P0621.039-045-ZP	3.9	45.0	7.5	2.8	PH-2
P0621.039-050-ZP	3.9	50.0	7.5	2.8	PH-2
P0621.039-060-ZP	3.9	60.0	7.5	2.8	PH-2
P0621.039-070-ZP	3.9	70.0	7.5	2.8	PH-2
P0621.039-080-ZP	3.9	80.0	7.5	2.8	PH-2
P0621.042-006-ZP	4.2	6.5	8.2	3.05	PH-2
P0621.042-009-ZP	4.2	9.5	8.2	3.05	PH-2
P0621.042-013-ZP	4.2	13.0	8.2	3.05	PH-2
P0621.042-016-ZP	4.2	16.0	8.2	3.05	PH-2
P0621.042-019-ZP	4.2	19.0	8.2	3.05	PH-2
P0621.042-022-ZP	4.2	22.0	8.2	3.05	PH-2
P0621.042-025-ZP	4.2	25.0	8.2	3.05	PH-2
P0621.042-032-ZP	4.2	32.0	8.2	3.05	PH-2
P0621.042-038-ZP	4.2	38.0	8.2	3.05	PH-2
P0621.042-045-ZP	4.2	45.0	8.2	3.05	PH-2
P0621.042-050-ZP	4.2	50.0	8.2	3.05	PH-2
P0621.042-060-ZP	4.2	60.0	8.2	3.05	PH-2
P0621.042-070-ZP	4.2	70.0	8.2	3.05	PH-2
P0621.042-080-ZP	4.2	80.0	8.2	3.05	PH-2
P0621.042-090-ZP	4.2	90.0	8.2	3.05	PH-2
P0621.042-100-ZP	4.2	100.0	8.2	3.05	PH-2
P0621.048-009-ZP	4.8	9.5	9.5	3.55	PH-2
P0621.048-013-ZP	4.8	13.0	9.5	3.55	PH-2
P0621.048-016-ZP	4.8	16.0	9.5	3.55	PH-2
P0621.048-019-ZP	4.8	19.0	9.5	3.55	PH-2
P0621.048-022-ZP	4.8	22.0	9.5	3.55	PH-2
P0621.048-025-ZP	4.8	25.0	9.5	3.55	PH-2
P0621.048-032-ZP	4.8	32.0	9.5	3.55	PH-2
P0621.048-038-ZP	4.8	38.0	9.5	3.55	PH-2
P0621.048-045-ZP	4.8	45.0	9.5	3.55	PH-2
P0621.048-050-ZP	4.8	50.0	9.5	3.55	PH-2
P0621.048-060-ZP	4.8	60.0	9.5	3.55	PH-2
P0621.048-070-ZP	4.8	70.0	9.5	3.55	PH-2
P0621.048-080-ZP	4.8	80.0	9.5	3.55	PH-2
P0621.048-090-ZP	4.8	90.0	9.5	3.55	PH-2
P0621.048-100-ZP	4.8	100.0	9.5	3.55	PH-2
P0621.048-120-ZP	4.8	120.0	9.5	3.55	PH-2
P0621.055-009-ZP	5.5	9.5	10.8	3.95	PH-3
P0621.055-013-ZP	5.5	13.0	10.8	3.95	PH-3
P0621.055-016-ZP	5.5	16.0	10.8	3.95	PH-3
P0621.055-019-ZP	5.5	19.0	10.8	3.95	PH-3
P0621.055-022-ZP	5.5	22.0	10.8	3.95	PH-3
P0621.055-025-ZP	5.5	25.0	10.8	3.95	PH-3
P0621.055-032-ZP	5.5	32.0	10.8	3.95	PH-3
P0621.055-038-ZP	5.5	38.0	10.8	3.95	PH-3
P0621.055-045-ZP	5.5	45.0	10.8	3.95	PH-3
P0621.055-050-ZP	5.5	50.0	10.8	3.95	PH-3
P0621.055-060-ZP	5.5	60.0	10.8	3.95	PH-3
P0621.055-070-ZP	5.5	70.0	10.8	3.95	PH-3
P0621.055-080-ZP	5.5	80.0	10.8	3.95	PH-3
P0621.055-090-ZP	5.5	90.0	10.8	3.95	PH-3
P0621.055-100-ZP	5.5	100.0	10.8	3.95	PH-3
P0621.055-120-ZP	5.5	120.0	10.8	3.95	PH-3
P0621.063-013-ZP	6.3	13.0	12.5	4.55	PH-3
P0621.063-016-ZP	6.3	16.0	12.5	4.55	PH-3
P0621.063-019-ZP	6.3	19.0	12.5	4.55	PH-3
P0621.063-022-ZP	6.3	22.0	12.5	4.55	PH-3
P0621.063-025-ZP	6.3	25.0	12.5	4.55	PH-3
P0621.063-032-ZP	6.3	32.0	12.5	4.55	PH-3
P0621.063-038-ZP	6.3	38.0	12.5	4.55	PH-3
P0621.063-045-ZP	6.3	45.0	12.5	4.55	PH-3
P0621.063-050-ZP	6.3	50.0	12.5	4.55	PH-3



Pan Head Phillips AB Tappers


Phillips AB - steel, zinc-plated

Self Tappers




Order No.	d ₁	l ₁	d ₂	h ₁ max.	Size
P0621.063-060-ZP	6.3	60.0	12.5	4.55	PH-3
P0621.063-070-ZP	6.3	70.0	12.5	4.55	PH-3
P0621.063-080-ZP	6.3	80.0	12.5	4.55	PH-3
P0621.063-090-ZP	6.3	90.0	12.5	4.55	PH-3
P0621.063-100-ZP	6.3	100.0	12.5	4.55	PH-3
P0621.063-120-ZP	6.3	120.0	12.5	4.55	PH-3

SELF TAPPERS

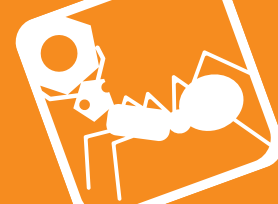

P0623.ZP

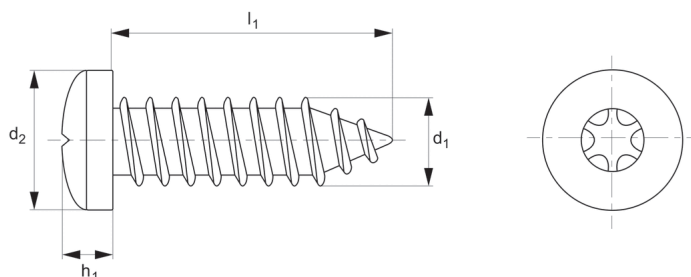

Material

Steel, zinc-plated.

Technical Notes

To DIN 7981C-TX, ISO 7049 type C.

Order No.	d ₁	l ₁	d ₂	h ₁ max.	Size
P0623.029-006-ZP	2.9	6.5	5.6	2.2	TX-10
P0623.029-009-ZP	2.9	9.5	5.6	2.2	TX-10
P0623.029-013-ZP	2.9	13.0	5.6	2.2	TX-10
P0623.029-016-ZP	2.9	16.0	5.6	2.2	TX-10
P0623.029-019-ZP	2.9	19.0	5.6	2.2	TX-10
P0623.029-022-ZP	2.9	22.0	5.6	2.2	TX-10
P0623.029-025-ZP	2.9	25.0	5.6	2.2	TX-10
P0623.029-032-ZP	2.9	32.0	5.6	2.2	TX-10
P0623.029-038-ZP	2.9	38.0	5.6	2.2	TX-10
P0623.035-009-ZP	3.5	9.5	6.9	2.6	TX-15
P0623.035-013-ZP	3.5	13.0	6.9	2.6	TX-15
P0623.035-016-ZP	3.5	16.0	6.9	2.6	TX-15
P0623.035-019-ZP	3.5	19.0	6.9	2.6	TX-15
P0623.035-022-ZP	3.5	22.0	6.9	2.6	TX-15
P0623.035-025-ZP	3.5	25.0	6.9	2.6	TX-15
P0623.035-032-ZP	3.5	32.0	6.9	2.6	TX-15
P0623.035-038-ZP	3.5	38.0	6.9	2.6	TX-15
P0623.035-045-ZP	3.5	45.0	6.9	2.6	TX-15
P0623.035-050-ZP	3.5	50.0	6.9	2.6	TX-15
P0623.039-009-ZP	3.9	9.5	7.5	2.8	TX-15
P0623.039-013-ZP	3.9	13.0	7.5	2.8	TX-15
P0623.039-016-ZP	3.9	16.0	7.5	2.8	TX-15
P0623.039-019-ZP	3.9	19.0	7.5	2.8	TX-15
P0623.039-022-ZP	3.9	22.0	7.5	2.8	TX-15
P0623.039-025-ZP	3.9	25.0	7.5	2.8	TX-15
P0623.039-032-ZP	3.9	32.0	7.5	2.8	TX-15
P0623.039-038-ZP	3.9	38.0	7.5	2.8	TX-15
P0623.039-045-ZP	3.9	45.0	7.5	2.8	TX-15
P0623.039-050-ZP	3.9	50.0	7.5	2.8	TX-15
P0623.039-060-ZP	3.9	60.0	7.5	2.8	TX-15
P0623.042-009-ZP	4.2	9.5	8.2	3.05	TX-20
P0623.042-013-ZP	4.2	13.0	8.2	3.05	TX-20
P0623.042-016-ZP	4.2	16.0	8.2	3.05	TX-20
P0623.042-019-ZP	4.2	19.0	8.2	3.05	TX-20



Pan Head TX AB Tappers


TX AB - steel, zinc-plated



Self Tappers


Order No.	d ₁	l ₁	d ₂	h ₁ max.	Size
P0623.042-022-ZP	4.2	22.0	8.2	3.05	TX-20
P0623.042-025-ZP	4.2	25.0	8.2	3.05	TX-20
P0623.042-032-ZP	4.2	32.0	8.2	3.05	TX-20
P0623.042-038-ZP	4.2	38.0	8.2	3.05	TX-20
P0623.042-045-ZP	4.2	45.0	8.2	3.05	TX-20
P0623.042-050-ZP	4.2	50.0	8.2	3.05	TX-20
P0623.042-060-ZP	4.2	60.0	8.2	3.05	TX-20
P0623.048-013-ZP	4.8	13.0	9.5	3.55	TX-25
P0623.048-016-ZP	4.8	16.0	9.5	3.55	TX-25
P0623.048-019-ZP	4.8	19.0	9.5	3.55	TX-25
P0623.048-022-ZP	4.8	22.0	9.5	3.55	TX-25
P0623.048-025-ZP	4.8	25.0	9.5	3.55	TX-25
P0623.048-032-ZP	4.8	32.0	9.5	3.55	TX-25
P0623.048-038-ZP	4.8	38.0	9.5	3.55	TX-25
P0623.048-045-ZP	4.8	45.0	9.5	3.55	TX-25
P0623.048-050-ZP	4.8	50.0	9.5	3.55	TX-25
P0623.048-060-ZP	4.8	60.0	9.5	3.55	TX-25
P0623.055-013-ZP	5.5	13.0	10.8	3.95	TX-25
P0623.055-016-ZP	5.5	16.0	10.8	3.95	TX-25
P0623.055-019-ZP	5.5	19.0	10.8	3.95	TX-25
P0623.055-022-ZP	5.5	22.0	10.8	3.95	TX-25
P0623.055-025-ZP	5.5	25.0	10.8	3.95	TX-25
P0623.055-032-ZP	5.5	32.0	10.8	3.95	TX-25
P0623.055-038-ZP	5.5	38.0	10.8	3.95	TX-25
P0623.055-045-ZP	5.5	45.0	10.8	3.95	TX-25
P0623.055-050-ZP	5.5	50.0	10.8	3.95	TX-25
P0623.055-060-ZP	5.5	60.0	10.8	3.95	TX-25
P0623.063-013-ZP	6.3	13.0	12.5	4.55	TX-30
P0623.063-016-ZP	6.3	16.0	12.5	4.55	TX-30
P0623.063-019-ZP	6.3	19.0	12.5	4.55	TX-30
P0623.063-022-ZP	6.3	22.0	12.5	4.55	TX-30
P0623.063-025-ZP	6.3	25.0	12.5	4.55	TX-30
P0623.063-032-ZP	6.3	32.0	12.5	4.55	TX-30
P0623.063-038-ZP	6.3	38.0	12.5	4.55	TX-30
P0623.063-045-ZP	6.3	45.0	12.5	4.55	TX-30
P0623.063-050-ZP	6.3	50.0	12.5	4.55	TX-30
P0623.063-060-ZP	6.3	60.0	12.5	4.55	TX-30

SELF TAPPERS

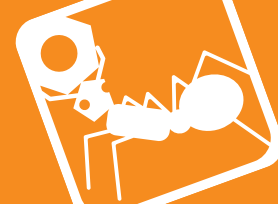

P0624.ZP

SELF TAPPERS

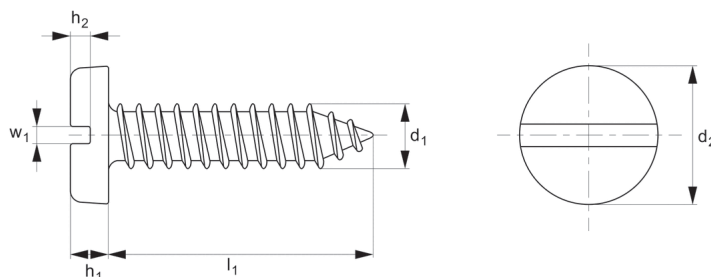

Material

Steel, zinc-plated.

Technical Notes

To DIN 7971C, ISO 1481 type C.

Order No.	d_1	l_1	d_2	h_1 max.	h_2 max.	w_1
P0624.022-004-ZP	2.2	4.5	4.2	1.35	0.8	0.6
P0624.022-006-ZP	2.2	6.5	4.2	1.35	0.8	0.6
P0624.022-009-ZP	2.2	9.5	4.2	1.35	0.8	0.6
P0624.022-013-ZP	2.2	13.0	4.2	1.35	0.8	0.6
P0624.022-016-ZP	2.2	16.0	4.2	1.35	0.8	0.6
P0624.022-019-ZP	2.2	19.0	4.2	1.35	0.8	0.6
P0624.022-022-ZP	2.2	22.0	4.2	1.35	0.8	0.6
P0624.022-025-ZP	2.2	25.0	4.2	1.35	0.8	0.6
P0624.029-006-ZP	2.9	6.5	5.6	1.75	1.0	0.8
P0624.029-009-ZP	2.9	9.5	5.6	1.75	1.0	0.8
P0624.029-013-ZP	2.9	13.0	5.6	1.75	1.0	0.8
P0624.029-016-ZP	2.9	16.0	5.6	1.75	1.0	0.8
P0624.029-019-ZP	2.9	19.0	5.6	1.75	1.0	0.8
P0624.029-022-ZP	2.9	22.0	5.6	1.75	1.0	0.8
P0624.029-025-ZP	2.9	25.0	5.6	1.75	1.0	0.8
P0624.029-032-ZP	2.9	32.0	5.6	1.75	1.0	0.8
P0624.035-006-ZP	3.5	6.5	6.9	2.1	1.25	1.0
P0624.035-009-ZP	3.5	9.5	6.9	2.1	1.25	1.0
P0624.035-013-ZP	3.5	13.0	6.9	2.1	1.25	1.0
P0624.035-016-ZP	3.5	16.0	6.9	2.1	1.25	1.0
P0624.035-019-ZP	3.5	19.0	6.9	2.1	1.25	1.0
P0624.035-022-ZP	3.5	22.0	6.9	2.1	1.25	1.0
P0624.035-025-ZP	3.5	25.0	6.9	2.1	1.25	1.0
P0624.035-032-ZP	3.5	32.0	6.9	2.1	1.25	1.0
P0624.035-038-ZP	3.5	38.0	6.9	2.1	1.25	1.0
P0624.042-006-ZP	4.2	6.5	8.2	2.45	1.5	1.2
P0624.042-009-ZP	4.2	9.5	8.2	2.45	1.5	1.2
P0624.042-013-ZP	4.2	13.0	8.2	2.45	1.5	1.2
P0624.042-016-ZP	4.2	16.0	8.2	2.45	1.5	1.2
P0624.042-019-ZP	4.2	19.0	8.2	2.45	1.5	1.2
P0624.042-022-ZP	4.2	22.0	8.2	2.45	1.5	1.2
P0624.042-025-ZP	4.2	25.0	8.2	2.45	1.5	1.2
P0624.042-032-ZP	4.2	32.0	8.2	2.45	1.5	1.2
P0624.042-038-ZP	4.2	38.0	8.2	2.45	1.5	1.2



Pan Head Slot AB Tappers


Slot AB - steel, zinc-plated




Self Tappers

SELF TAPPERS

Order No.	d ₁	l ₁	d ₂	h ₁ max.	h ₂ max.	w ₁
P0624.042-045-ZP	4.2	45.0	8.2	2.45	1.5	1.2
P0624.042-500-ZP	4.2	50.0	8.2	2.45	1.5	1.2
P0624.048-009-ZP	4.8	9.5	9.5	2.80	1.7	1.2
P0624.048-013-ZP	4.8	13.0	9.5	2.80	1.7	1.2
P0624.048-016-ZP	4.8	16.0	9.5	2.80	1.7	1.2
P0624.048-019-ZP	4.8	19.0	9.5	2.80	1.7	1.2
P0624.048-022-ZP	4.8	22.0	9.5	2.80	1.7	1.2
P0624.048-025-ZP	4.8	25.0	9.5	2.80	1.7	1.2
P0624.048-032-ZP	4.8	32.0	9.5	2.80	1.7	1.2
P0624.048-038-ZP	4.8	38.0	9.5	2.80	1.7	1.2
P0624.048-045-ZP	4.8	45.0	9.5	2.80	1.7	1.2
P0624.048-050-ZP	4.8	50.0	9.5	2.80	1.7	1.2
P0624.048-060-ZP	4.8	60.0	9.5	2.80	1.7	1.2
P0624.048-070-ZP	4.8	70.0	9.5	2.80	1.7	1.2
P0624.048-080-ZP	4.8	80.0	9.5	2.80	1.7	1.2
P0624.055-013-ZP	5.5	13.0	10.8	3.20	1.95	1.6
P0624.055-016-ZP	5.5	16.0	10.8	3.20	1.95	1.6
P0624.055-019-ZP	5.5	19.0	10.8	3.20	1.95	1.6
P0624.055-022-ZP	5.5	22.0	10.8	3.20	1.95	1.6
P0624.055-025-ZP	5.5	25.0	10.8	3.20	1.95	1.6
P0624.055-032-ZP	5.5	32.0	10.8	3.20	1.95	1.6
P0624.055-038-ZP	5.5	38.0	10.8	3.20	1.95	1.6
P0624.055-045-ZP	5.5	45.0	10.8	3.20	1.95	1.6
P0624.055-050-ZP	5.5	50.0	10.8	3.20	1.95	1.6
P0624.055-060-ZP	5.5	60.0	10.8	3.20	1.95	1.6
P0624.055-070-ZP	5.5	70.0	10.8	3.20	1.95	1.6
P0624.055-080-ZP	5.5	80.0	10.8	3.20	1.95	1.6
P0624.063-013-ZP	6.3	13.0	12.5	3.65	2.20	1.6
P0624.063-016-ZP	6.3	16.0	12.5	3.65	2.20	1.6
P0624.063-019-ZP	6.3	19.0	12.5	3.65	2.20	1.6
P0624.063-022-ZP	6.3	22.0	12.5	3.65	2.20	1.6
P0624.063-025-ZP	6.3	25.0	12.5	3.65	2.20	1.6
P0624.063-032-ZP	6.3	32.0	12.5	3.65	2.20	1.6
P0624.063-038-ZP	6.3	38.0	12.5	3.65	2.20	1.6
P0624.063-045-ZP	6.3	45.0	12.5	3.65	2.20	1.6
P0624.063-050-ZP	6.3	50.0	12.5	3.65	2.20	1.6
P0624.063-060-ZP	6.3	60.0	12.5	3.65	2.20	1.6
P0624.063-070-ZP	6.3	70.0	12.5	3.65	2.20	1.6
P0624.063-080-ZP	6.3	80.0	12.5	3.65	2.20	1.6
P0624.039-006-ZP	3.9	6.5	7.5	2.25	1.4	1.0
P0624.039-009-ZP	3.9	9.5	7.5	2.25	1.4	1.0
P0624.039-013-ZP	3.9	13.0	7.5	2.25	1.4	1.0
P0624.039-016-ZP	3.9	16.0	7.5	2.25	1.4	1.0
P0624.039-019-ZP	3.9	19.0	7.5	2.25	1.4	1.0
P0624.039-022-ZP	3.9	22.0	7.5	2.25	1.4	1.0
P0624.039-025-ZP	3.9	25.0	7.5	2.25	1.4	1.0
P0624.039-032-ZP	3.9	32.0	7.5	2.25	1.4	1.0
P0624.039-038-ZP	3.9	38.0	7.5	2.25	1.4	1.0
P0624.039-045-ZP	3.9	45.0	7.5	2.25	1.4	1.0
P0624.039-050-ZP	3.9	50.0	7.5	2.25	1.4	1.0

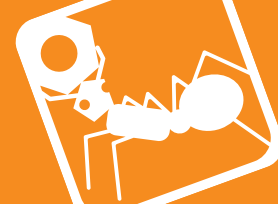

P0637.ZP

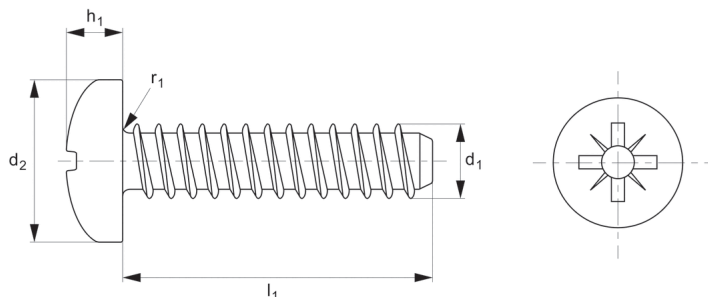

Material

Steel, zinc-plated.

Technical Notes

To DIN 7981F-Z, ISO 7049 type F (with dog point).

Order No.	d_1	l_1	d_2	h_1	Size
P0637.022-006-ZP	2.2	6.5	4.2	1.8	PZ-1
P0637.022-009-ZP	2.2	9.5	4.2	1.8	PZ-1
P0637.022-013-ZP	2.2	13.0	4.2	1.8	PZ-1
P0637.022-016-ZP	2.2	16.0	4.2	1.8	PZ-1
P0637.022-019-ZP	2.2	19.0	4.2	1.8	PZ-1
P0637.022-022-ZP	2.2	22.0	4.2	1.8	PZ-1
P0637.022-025-ZP	2.2	25.0	4.2	1.8	PZ-1
P0637.022-032-ZP	2.2	32.0	4.2	1.8	PZ-1
P0637.029-006-ZP	2.9	6.5	5.6	2.2	PZ-1
P0637.029-009-ZP	2.9	9.5	5.6	2.2	PZ-1
P0637.029-013-ZP	2.9	13.0	5.6	2.2	PZ-1
P0637.029-016-ZP	2.9	16.0	5.6	2.2	PZ-1
P0637.029-019-ZP	2.9	19.0	5.6	2.2	PZ-1
P0637.029-022-ZP	2.9	22.0	5.6	2.2	PZ-1
P0637.029-025-ZP	2.9	25.0	5.6	2.2	PZ-1
P0637.029-032-ZP	2.9	32.0	5.6	2.2	PZ-1
P0637.035-006-ZP	3.5	6.5	6.9	2.6	PZ-2
P0637.035-009-ZP	3.5	9.5	6.9	2.6	PZ-2
P0637.035-013-ZP	3.5	13.0	6.9	2.6	PZ-2
P0637.035-016-ZP	3.5	16.0	6.9	2.6	PZ-2
P0637.035-019-ZP	3.5	19.0	6.9	2.6	PZ-2
P0637.035-022-ZP	3.5	22.0	6.9	2.6	PZ-2
P0637.035-025-ZP	3.5	25.0	6.9	2.6	PZ-2
P0637.035-032-ZP	3.5	32.0	6.9	2.6	PZ-2
P0637.035-045-ZP	3.5	45.0	6.9	2.6	PZ-2
P0637.035-050-ZP	3.5	50.0	6.9	2.6	PZ-2
P0637.035-060-ZP	3.5	60.0	6.9	2.6	PZ-2
P0637.039-006-ZP	3.9	6.5	7.5	2.8	PZ-2
P0637.039-009-ZP	3.9	9.5	7.5	2.8	PZ-2
P0637.039-013-ZP	3.9	13.0	7.5	2.8	PZ-2
P0637.039-016-ZP	3.9	16.0	7.5	2.8	PZ-2
P0637.039-019-ZP	3.9	19.0	7.5	2.8	PZ-2
P0637.039-022-ZP	3.9	22.0	7.5	2.8	PZ-2
P0637.039-025-ZP	3.9	25.0	7.5	2.8	PZ-2
P0637.039-032-ZP	3.9	32.0	7.5	2.8	PZ-2



Pan Head Pozi Tappers

Pozi dog point - steel, zinc-plated



Self Tappers

Order No.	d ₁	l ₁	d ₂	h ₁	Size
P0637.039-045-ZP	3.9	45.0	7.5	2.8	PZ-2
P0637.039-050-ZP	3.9	50.0	7.5	2.8	PZ-2
P0637.039-060-ZP	3.9	60.0	7.5	2.8	PZ-2
P0637.039-070-ZP	3.9	70.0	7.5	2.8	PZ-2
P0637.039-080-ZP	3.9	80.0	7.5	2.8	PZ-2
P0637.042-006-ZP	4.2	6.5	8.2	3.05	PZ-2
P0637.042-009-ZP	4.2	9.5	8.2	3.05	PZ-2
P0637.042-013-ZP	4.2	13.0	8.2	3.05	PZ-2
P0637.042-016-ZP	4.2	16.0	8.2	3.05	PZ-2
P0637.042-019-ZP	4.2	19.0	8.2	3.05	PZ-2
P0637.042-022-ZP	4.2	22.0	8.2	3.05	PZ-2
P0637.042-025-ZP	4.2	25.0	8.2	3.05	PZ-2
P0637.042-032-ZP	4.2	32.0	8.2	3.05	PZ-2
P0637.042-045-ZP	4.2	45.0	8.2	3.05	PZ-2
P0637.042-050-ZP	4.2	50.0	8.2	3.05	PZ-2
P0637.042-060-ZP	4.2	60.0	8.2	3.05	PZ-2
P0637.042-070-ZP	4.2	70.0	8.2	3.05	PZ-2
P0637.042-080-ZP	4.2	80.0	8.2	3.05	PZ-2
P0637.048-006-ZP	4.8	6.5	9.5	3.55	PZ-2
P0637.048-009-ZP	4.8	9.5	9.5	3.55	PZ-2
P0637.048-013-ZP	4.8	13.0	9.5	3.55	PZ-2
P0637.048-016-ZP	4.8	16.0	9.5	3.55	PZ-2
P0637.048-019-ZP	4.8	19.0	9.5	3.55	PZ-2
P0637.048-022-ZP	4.8	22.0	9.5	3.55	PZ-2
P0637.048-025-ZP	4.8	25.0	9.5	3.55	PZ-2
P0637.048-032-ZP	4.8	32.0	9.5	3.55	PZ-2
P0637.048-045-ZP	4.8	45.0	9.5	3.55	PZ-2
P0637.048-050-ZP	4.8	50.0	9.5	3.55	PZ-2
P0637.048-060-ZP	4.8	60.0	9.5	3.55	PZ-2
P0637.048-070-ZP	4.8	70.0	9.5	3.55	PZ-2
P0637.048-080-ZP	4.8	80.0	9.5	3.55	PZ-2
P0637.048-090-ZP	4.8	90.0	9.5	3.55	PZ-2
P0637.048-100-ZP	4.8	100.0	9.5	3.55	PZ-2
P0637.055-006-ZP	5.5	6.5	10.8	3.95	PZ-3
P0637.055-009-ZP	5.5	9.5	10.8	3.95	PZ-3
P0637.055-013-ZP	5.5	13.0	10.8	3.95	PZ-3
P0637.055-016-ZP	5.5	16.0	10.8	3.95	PZ-3
P0637.055-019-ZP	5.5	19.0	10.8	3.95	PZ-3
P0637.055-022-ZP	5.5	22.0	10.8	3.95	PZ-3
P0637.055-025-ZP	5.5	25.0	10.8	3.95	PZ-3
P0637.055-032-ZP	5.5	32.0	10.8	3.95	PZ-3
P0637.055-045-ZP	5.5	45.0	10.8	3.95	PZ-3
P0637.055-050-ZP	5.5	50.0	10.8	3.95	PZ-3
P0637.055-060-ZP	5.5	60.0	10.8	3.95	PZ-3
P0637.055-070-ZP	5.5	70.0	10.8	3.95	PZ-3
P0637.055-080-ZP	5.5	80.0	10.8	3.95	PZ-3
P0637.055-090-ZP	5.5	90.0	10.8	3.95	PZ-3
P0637.055-100-ZP	5.5	100.0	10.8	3.95	PZ-3
P0637.063-013-ZP	6.3	13.0	12.5	4.55	PZ-3
P0637.063-016-ZP	6.3	16.0	12.5	4.55	PZ-3
P0637.063-019-ZP	6.3	19.0	12.5	4.55	PZ-3
P0637.063-022-ZP	6.3	22.0	12.5	4.55	PZ-3
P0637.063-025-ZP	6.3	25.0	12.5	4.55	PZ-3
P0637.063-032-ZP	6.3	32.0	12.5	4.55	PZ-3
P0637.063-038-ZP	6.3	38.0	12.5	4.55	PZ-3
P0637.063-045-ZP	6.3	45.0	12.5	4.55	PZ-3
P0637.063-050-ZP	6.3	50.0	12.5	4.55	PZ-3
P0637.063-060-ZP	6.3	60.0	12.5	4.55	PZ-3
P0637.063-070-ZP	6.3	70.0	12.5	4.55	PZ-3
P0637.063-080-ZP	6.3	80.0	12.5	4.55	PZ-3
P0637.063-090-ZP	6.3	90.0	12.5	4.55	PZ-3
P0637.063-100-ZP	6.3	100.0	12.5	4.55	PZ-3

SELF TAPPERS