



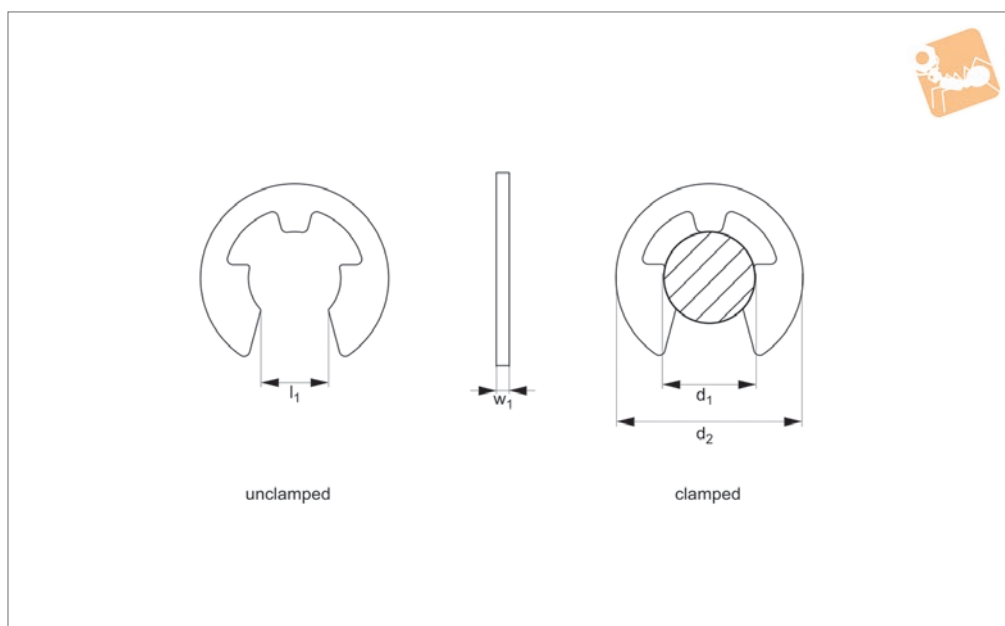

E Clips

A2 stainless

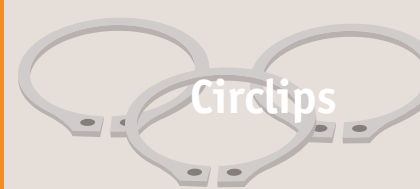

P0382.A2

CIRCLIPS


Material

Stainless steel (A2, AISI 303).

Technical Notes

To DIN 6799.

Order No.	d ₁	For shaft dia.	d ₂	l ₁	w ₁	Material
P0382.012-A2	1.2	1,4-2,0	3.25	1.01	0.30	A2 s/s
P0382.015-A2	1.5	2,0-2,5	4.25	1.28	0.40	A2 s/s
P0382.019-A2	1.9	2,5-3,0	4.80	1.61	0.50	A2 s/s
P0382.023-A2	2.3	3,0-4,0	6.30	1.94	0.60	A2 s/s
P0382.032-A2	3.2	4,0-5,0	7.30	2.70	0.60	A2 s/s
P0382.040-A2	4.0	5,0-7,0	9.30	3.34	0.70	A2 s/s
P0382.050-A2	5.0	6,0-8,0	11.30	4.11	0.70	A2 s/s
P0382.060-A2	6.0	7,0-9,0	12.30	5.26	0.70	A2 s/s
P0382.070-A2	7.0	8,0-11,0	14.30	5.84	0.90	A2 s/s
P0382.080-A2	8.0	9,0-12,0	16.30	6.52	1.00	A2 s/s
P0382.090-A2	9.0	10,0-14,0	18.80	7.63	1.10	A2 s/s
P0382.100-A2	10.0	11,0-15,0	20.40	8.32	1.20	A2 s/s
P0382.120-A2	12.0	13,0-18,0	23.40	10.45	1.30	A2 s/s
P0382.150-A2	15.0	16,0-24,0	29.40	12.61	1.50	A2 s/s
P0382.190-A2	19.0	20,0-31,0	37.60	15.92	1.75	A2 s/s
P0382.240-A2	24.0	25,0-38,0	44.60	21.88	2.00	A2 s/s

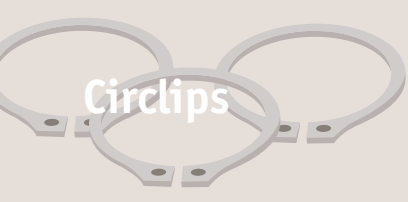

Circlips

E Clips


Steel phosphated



CIRCLIPS



P0382.PH

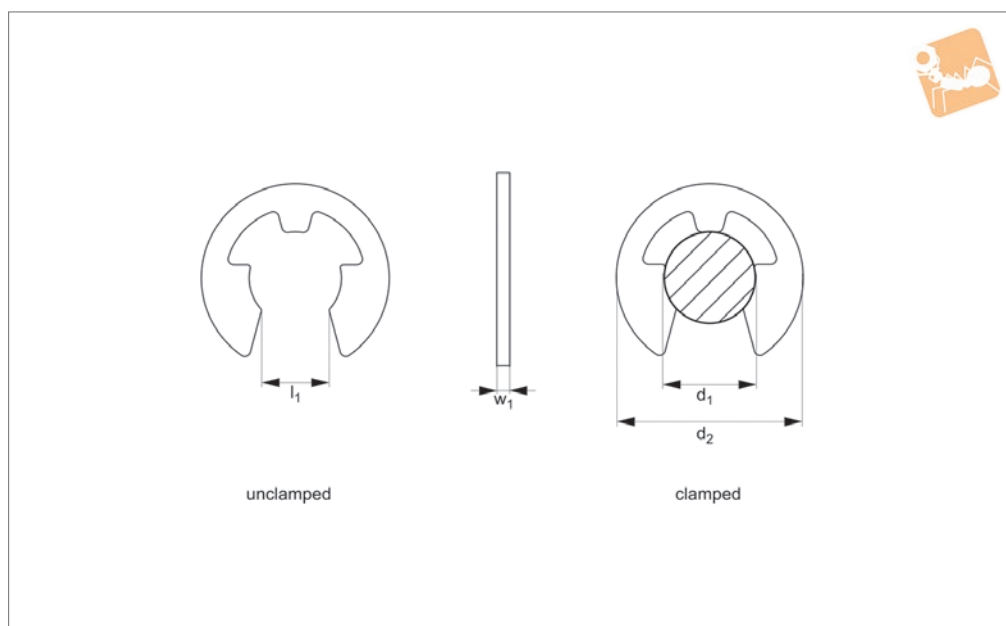

Material
Steel, phosphated.

Technical Notes
To DIN 6799.

Order No.	d ₁	For shaft dia.	d ₂	l ₁	w ₁	Material
P0382.012-PH	1.2	1,4-2,0	3.25	1.01	0.30	Steel PH
P0382.015-PH	1.5	2,0-2,5	4.25	1.28	0.40	Steel PH
P0382.019-PH	1.9	2,5-3,0	4.80	1.61	0.50	Steel PH
P0382.023-PH	2.3	3,0-4,0	6.30	1.94	0.60	Steel PH
P0382.032-PH	3.2	4,0-5,0	7.30	2.70	0.60	Steel PH
P0382.040-PH	4.0	5,0-7,0	9.30	3.34	0.70	Steel PH
P0382.050-PH	5.0	6,0-8,0	11.30	4.11	0.70	Steel PH
P0382.060-PH	6.0	7,0-9,0	12.30	5.26	0.70	Steel PH
P0382.070-PH	7.0	8,0-11,0	14.30	5.84	0.90	Steel PH
P0382.080-PH	8.0	9,0-12,0	16.30	6.52	1.00	Steel PH
P0382.090-PH	9.0	10,0-14,0	18.80	7.63	1.10	Steel PH
P0382.100-PH	10.0	11,0-15,0	20.40	8.32	1.20	Steel PH
P0382.120-PH	12.0	13,0-18,0	23.40	10.45	1.30	Steel PH
P0382.150-PH	15.0	16,0-24,0	29.40	12.61	1.50	Steel PH
P0382.190-PH	19.0	20,0-31,0	37.60	15.92	1.75	Steel PH
P0382.240-PH	24.0	25,0-38,0	44.60	21.88	2.00	Steel PH