




20mm Linear Guide Rail

standard, blackened

Linear Guide-ways

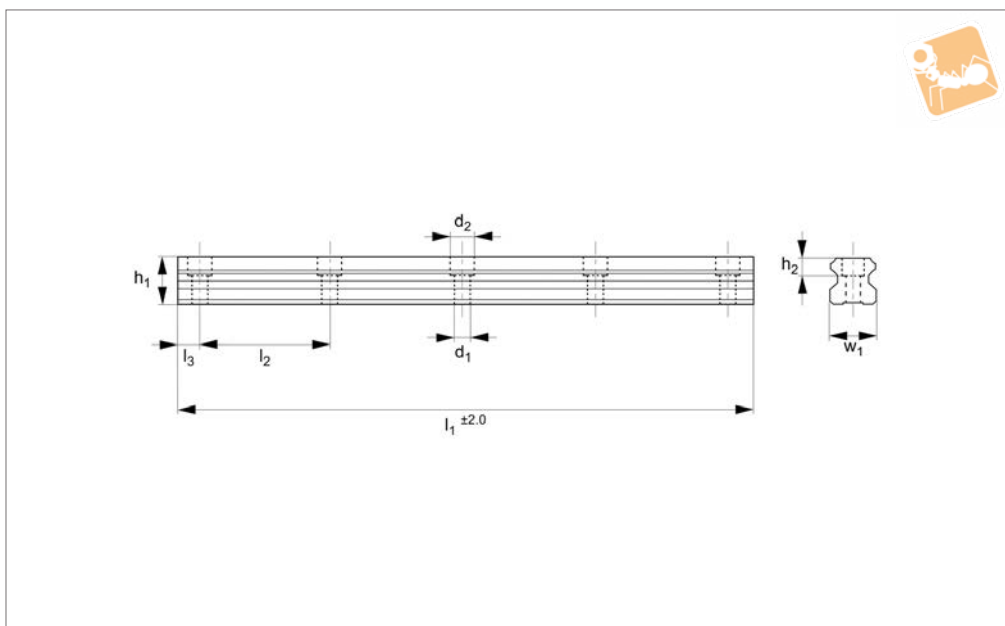

L1016.BL20

LINEAR GUIDEWAYS

Material

Hardened and ground steel (typically 60 HRC). Black oxide.

Technical Notes

For carriages to suit the required load see

part nos. L1016.F (flanged) and L1016.U (unflanged).


Other rail lengths on request.

Weight: 2,6 Kg/m.

Tips

Plastic screw covers issued with the rails to protect the holes from debris.

Order No.	Rail size	l_1	h_1	l_2	w_1	l_3	h_2	d_1	d_2	For screws	Weight kg
L1016.BL20-0160	20	160	16.3	60	20	20	8.5	6	9.5	M 5	0.42
L1016.BL20-0220	20	220	16.3	60	20	20	8.5	6	9.5	M 5	0.57
L1016.BL20-0280	20	280	16.3	60	20	20	8.5	6	9.5	M 5	0.73
L1016.BL20-0340	20	340	16.3	60	20	20	8.5	6	9.5	M 5	0.88
L1016.BL20-0400	20	400	16.3	60	20	20	8.5	6	9.5	M 5	1.04
L1016.BL20-0460	20	460	16.3	60	20	20	8.5	6	9.5	M 5	1.20
L1016.BL20-0520	20	520	16.3	60	20	20	8.5	6	9.5	M 5	1.35
L1016.BL20-0580	20	580	16.3	60	20	20	8.5	6	9.5	M 5	1.51
L1016.BL20-0640	20	640	16.3	60	20	20	8.5	6	9.5	M 5	1.66
L1016.BL20-0700	20	700	16.3	60	20	20	8.5	6	9.5	M 5	1.82
L1016.BL20-0760	20	760	16.3	60	20	20	8.5	6	9.5	M 5	1.98
L1016.BL20-0820	20	820	16.3	60	20	20	8.5	6	9.5	M 5	2.13
L1016.BL20-0880	20	880	16.3	60	20	20	8.5	6	9.5	M 5	2.29
L1016.BL20-0940	20	940	16.3	60	20	20	8.5	6	9.5	M 5	2.44
L1016.BL20-1000	20	1000	16.3	60	20	20	8.5	6	9.5	M 5	2.60
L1016.BL20-1060	20	1060	16.3	60	20	20	8.5	6	9.5	M 5	2.76
L1016.BL20-1120	20	1120	16.3	60	20	20	8.5	6	9.5	M 5	2.91
L1016.BL20-1180	20	1180	16.3	60	20	20	8.5	6	9.5	M 5	3.07
L1016.BL20-1240	20	1240	16.3	60	20	20	8.5	6	9.5	M 5	3.22
L1016.BL20-1300	20	1300	16.3	60	20	20	8.5	6	9.5	M 5	3.38
L1016.BL20-1360	20	1360	16.3	60	20	20	8.5	6	9.5	M 5	3.54
L1016.BL20-1420	20	1420	16.3	60	20	20	8.5	6	9.5	M 5	3.69
L1016.BL20-1480	20	1480	16.3	60	20	20	8.5	6	9.5	M 5	3.85
L1016.BL20-1540	20	1540	16.3	60	20	20	8.5	6	9.5	M 5	4.00
L1016.BL20-1600	20	1600	16.3	60	20	20	8.5	6	9.5	M 5	4.16
L1016.BL20-1660	20	1660	16.3	60	20	20	8.5	6	9.5	M 5	4.32
L1016.BL20-1720	20	1720	16.3	60	20	20	8.5	6	9.5	M 5	4.47
L1016.BL20-1780	20	1780	16.3	60	20	20	8.5	6	9.5	M 5	4.63
L1016.BL20-1840	20	1840	16.3	60	20	20	8.5	6	9.5	M 5	4.78
L1016.BL20-1900	20	1900	16.3	60	20	20	8.5	6	9.5	M 5	4.94
L1016.BL20-1960	20	1960	16.3	60	20	20	8.5	6	9.5	M 5	5.10
L1016.BL20-2020	20	2020	16.3	60	20	20	8.5	6	9.5	M 5	5.25

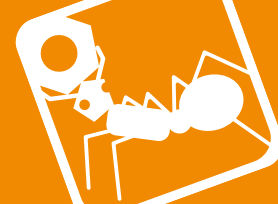

Order No.	Rail size	l_1	h_1	l_2	w_1	l_3	h_2	d_1	d_2	For screws	Weight kg
L1016.BL20-2080	20	2080	16.3	60	20	20	8.5	6	9.5	M 5	5.41
L1016.BL20-2140	20	2140	16.3	60	20	20	8.5	6	9.5	M 5	5.56
L1016.BL20-2200	20	2200	16.3	60	20	20	8.5	6	9.5	M 5	5.72
L1016.BL20-2260	20	2260	16.3	60	20	20	8.5	6	9.5	M 5	5.88
L1016.BL20-2320	20	2320	16.3	60	20	20	8.5	6	9.5	M 5	6.03
L1016.BL20-2380	20	2380	16.3	60	20	20	8.5	6	9.5	M 5	6.19
L1016.BL20-2440	20	2440	16.3	60	20	20	8.5	6	9.5	M 5	6.34
L1016.BL20-2500	20	2500	16.3	60	20	20	8.5	6	9.5	M 5	6.50
L1016.BL20-2560	20	2560	16.3	60	20	20	8.5	6	9.5	M 5	6.66
L1016.BL20-2620	20	2620	16.3	60	20	20	8.5	6	9.5	M 5	6.81
L1016.BL20-2680	20	2680	16.3	60	20	20	8.5	6	9.5	M 5	6.97
L1016.BL20-2740	20	2740	16.3	60	20	20	8.5	6	9.5	M 5	7.12
L1016.BL20-2800	20	2800	16.3	60	20	20	8.5	6	9.5	M 5	7.28
L1016.BL20-2860	20	2860	16.3	60	20	20	8.5	6	9.5	M 5	7.44
L1016.BL20-2920	20	2920	16.3	60	20	20	8.5	6	9.5	M 5	7.59
L1016.BL20-2980	20	2980	16.3	60	20	20	8.5	6	9.5	M 5	7.75
L1016.BL20-3040	20	3040	16.3	60	20	20	8.5	6	9.5	M 5	7.90
L1016.BL20-3100	20	3100	16.3	60	20	20	8.5	6	9.5	M 5	8.06
L1016.BL20-3160	20	3160	16.3	60	20	20	8.5	6	9.5	M 5	8.22
L1016.BL20-3220	20	3220	16.3	60	20	20	8.5	6	9.5	M 5	8.37
L1016.BL20-3280	20	3280	16.3	60	20	20	8.5	6	9.5	M 5	8.53
L1016.BL20-3340	20	3340	16.3	60	20	20	8.5	6	9.5	M 5	8.68
L1016.BL20-3400	20	3400	16.3	60	20	20	8.5	6	9.5	M 5	8.84
L1016.BL20-3460	20	3460	16.3	60	20	20	8.5	6	9.5	M 5	9.00
L1016.BL20-3520	20	3520	16.3	60	20	20	8.5	6	9.5	M 5	9.15
L1016.BL20-3580	20	3580	16.3	60	20	20	8.5	6	9.5	M 5	9.31
L1016.BL20-3640	20	3640	16.3	60	20	20	8.5	6	9.5	M 5	9.46
L1016.BL20-3700	20	3700	16.3	60	20	20	8.5	6	9.5	M 5	9.62
L1016.BL20-3760	20	3760	16.3	60	20	20	8.5	6	9.5	M 5	9.78
L1016.BL20-3820	20	3820	16.3	60	20	20	8.5	6	9.5	M 5	9.93
L1016.BL20-3880	20	3880	16.3	60	20	20	8.5	6	9.5	M 5	10.09
L1016.BL20-3940	20	3940	16.3	60	20	20	8.5	6	9.5	M 5	10.24
L1016.BL20-4000	20	4000	16.3	60	20	20	8.5	6	9.5	M 5	10.40