




15mm Linear Guide Rail

rear fixing

Linear Guide-ways

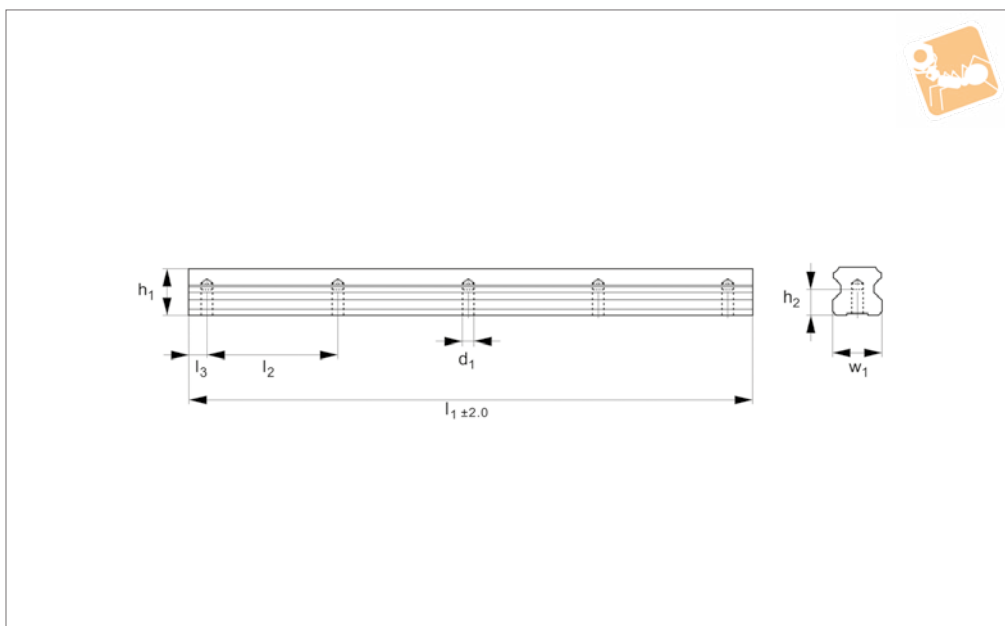

L1016.RF15

LINEAR GUIDEWAYS

Material

Hardened and ground steel (typically 60 HRC).

part nos. L1016.F (flanged) and L1016.U (unflanged).


Other rail lengths on request.

Weight: 1,4 Kg/m.

Technical Notes

For carriages to suit the required load see

Order No.	Rail size	l_1	h_1	l_2	w_1	l_3	h_2	d_1	Weight kg
L1016.RF15-0160	15	160	13.0	60	15	20	8	M5	0.22
L1016.RF15-0220	15	220	13.0	60	15	20	8	M5	0.31
L1016.RF15-0280	15	280	13.0	60	15	20	8	M5	0.39
L1016.RF15-0340	15	340	13.0	60	15	20	8	M5	0.48
L1016.RF15-0400	15	400	13.0	60	15	20	8	M5	0.56
L1016.RF15-0460	15	460	13.0	60	15	20	8	M5	0.64
L1016.RF15-0520	15	520	13.0	60	15	20	8	M5	0.73
L1016.RF15-0580	15	580	13.0	60	15	20	8	M5	0.81
L1016.RF15-0640	15	640	13.0	60	15	20	8	M5	0.90
L1016.RF15-0700	15	700	13.0	60	15	20	8	M5	0.98
L1016.RF15-0760	15	760	13.0	60	15	20	8	M5	1.06
L1016.RF15-0820	15	820	13.0	60	15	20	8	M5	1.15
L1016.RF15-0880	15	880	13.0	60	15	20	8	M5	1.23
L1016.RF15-0940	15	940	13.0	60	15	20	8	M5	1.32
L1016.RF15-1000	15	1000	13.0	60	15	20	8	M5	1.40
L1016.RF15-1060	15	1060	13.0	60	15	20	8	M5	1.48
L1016.RF15-1120	15	1120	13.0	60	15	20	8	M5	1.57
L1016.RF15-1180	15	1180	13.0	60	15	20	8	M5	1.65
L1016.RF15-1240	15	1240	13.0	60	15	20	8	M5	1.74
L1016.RF15-1300	15	1300	13.0	60	15	20	8	M5	1.82
L1016.RF15-1360	15	1360	13.0	60	15	20	8	M5	1.90
L1016.RF15-1420	15	1420	13.0	60	15	20	8	M5	1.99
L1016.RF15-1480	15	1480	13.0	60	15	20	8	M5	2.07
L1016.RF15-1540	15	1540	13.0	60	15	20	8	M5	2.16
L1016.RF15-1600	15	1600	13.0	60	15	20	8	M5	2.24
L1016.RF15-1660	15	1660	13.0	60	15	20	8	M5	2.32
L1016.RF15-1720	15	1720	13.0	60	15	20	8	M5	2.41
L1016.RF15-1780	15	1780	13.0	60	15	20	8	M5	2.49
L1016.RF15-1840	15	1840	13.0	60	15	20	8	M5	2.58
L1016.RF15-1900	15	1900	13.0	60	15	20	8	M5	2.66
L1016.RF15-1960	15	1960	13.0	60	15	20	8	M5	2.74
L1016.RF15-2020	15	2020	13.0	60	15	20	8	M5	2.83

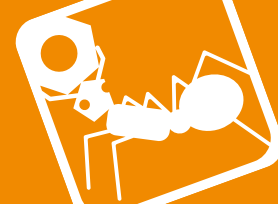

Order No.	Rail size	l_1	h_1	l_2	w_1	l_3	h_2	d_1	Weight kg
L1016.RF15-2080	15	2080	13.0	60	15	20	8	M5	2.91
L1016.RF15-2140	15	2140	13.0	60	15	20	8	M5	3.00
L1016.RF15-2200	15	2220	13.0	60	15	20	8	M5	3.08
L1016.RF15-2260	15	2260	13.0	60	15	20	8	M5	3.16
L1016.RF15-2320	15	2320	13.0	60	15	20	8	M5	3.25
L1016.RF15-2380	15	2380	13.0	60	15	20	8	M5	3.33
L1016.RF15-2440	15	2440	13.0	60	15	20	8	M5	3.42
L1016.RF15-2500	15	2500	13.0	60	15	20	8	M5	3.50
L1016.RF15-2560	15	2560	13.0	60	15	20	8	M5	3.58
L1016.RF15-2620	15	2620	13.0	60	15	20	8	M5	3.67
L1016.RF15-2680	15	2680	13.0	60	15	20	8	M5	3.75
L1016.RF15-2740	15	2740	13.0	60	15	20	8	M5	3.84
L1016.RF15-2800	15	2800	13.0	60	15	20	8	M5	3.92
L1016.RF15-2860	15	2860	13.0	60	15	20	8	M5	4.00
L1016.RF15-2920	15	2920	13.0	60	15	20	8	M5	4.09
L1016.RF15-2980	15	2980	13.0	60	15	20	8	M5	4.17
L1016.RF15-3040	15	3040	13.0	60	15	20	8	M5	4.26
L1016.RF15-3100	15	3100	13.0	60	15	20	8	M5	4.34
L1016.RF15-3160	15	3160	13.0	60	15	20	8	M5	4.42
L1016.RF15-3220	15	3220	13.0	60	15	20	8	M5	4.51
L1016.RF15-3280	15	3280	13.0	60	15	20	8	M5	4.59
L1016.RF15-3340	15	3340	13.0	60	15	20	8	M5	4.68
L1016.RF15-3400	15	3400	13.0	60	15	20	8	M5	4.76
L1016.RF15-3460	15	3460	13.0	60	15	20	8	M5	4.84
L1016.RF15-3520	15	3520	13.0	60	15	20	8	M5	4.93
L1016.RF15-3580	15	3580	13.0	60	15	20	8	M5	5.01
L1016.RF15-3640	15	3640	13.0	60	15	20	8	M5	5.10
L1016.RF15-3700	15	3700	13.0	60	15	20	8	M5	5.18
L1016.RF15-3760	15	3760	13.0	60	15	20	8	M5	5.26
L1016.RF15-3820	15	3820	13.0	60	15	20	8	M5	5.35
L1016.RF15-3880	15	3880	13.0	60	15	20	8	M5	5.43
L1016.RF15-3940	15	3940	13.0	60	15	20	8	M5	5.52
L1016.RF15-4000	15	4000	13.0	60	15	20	8	M5	5.60