



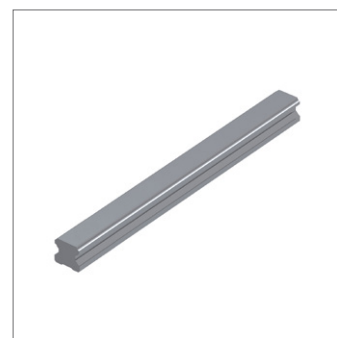

20mm Linear Guide Rail

rear fixing

Linear Guide-ways

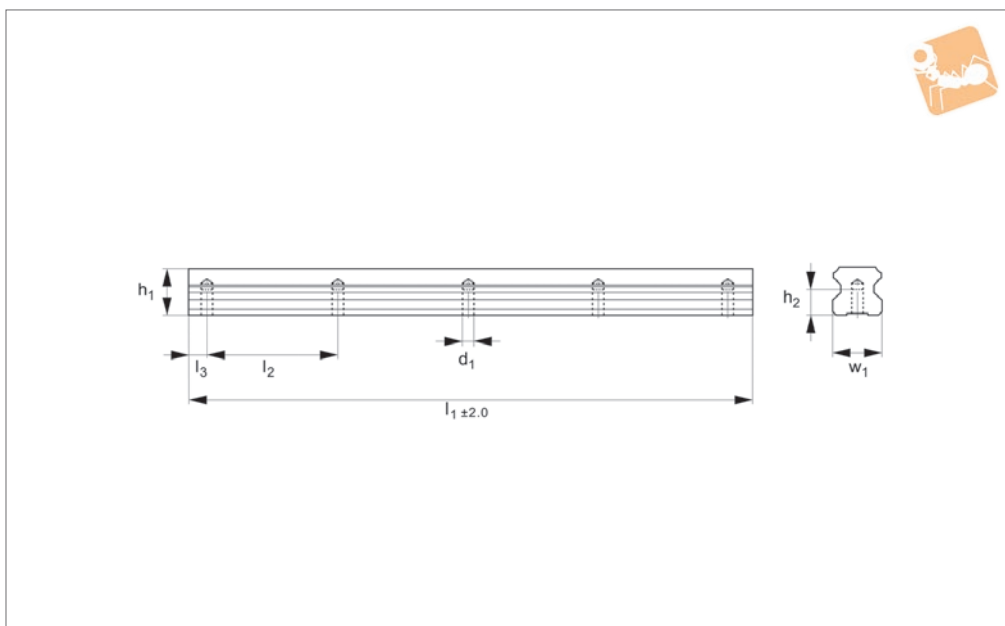

L1016.RF20

LINEAR GUIDEWAYS

Material

Hardened and ground steel (typically 60 HRC).

part nos. L1016.F (flanged) and L1016.U (unflanged).


Other rail lengths on request.

Weight: 2,6 Kg/m.

Technical Notes

For carriages to suit the required load see

Order No.	Rail size	l_1	h_1	l_2	w_1	l_3	h_2	d_1	Weight kg
L1016.RF20-0160	20	160	16.3	60	20	20	10	M6	0.42
L1016.RF20-0220	20	220	16.3	60	20	20	10	M6	0.57
L1016.RF20-0280	20	280	16.3	60	20	20	10	M6	0.73
L1016.RF20-0340	20	340	16.3	60	20	20	10	M6	0.88
L1016.RF20-0400	20	400	16.3	60	20	20	10	M6	1.04
L1016.RF20-0460	20	460	16.3	60	20	20	10	M6	1.20
L1016.RF20-0520	20	520	16.3	60	20	20	10	M6	1.35
L1016.RF20-0580	20	580	16.3	60	20	20	10	M6	1.51
L1016.RF20-0640	20	640	16.3	60	20	20	10	M6	1.66
L1016.RF20-0700	20	700	16.3	60	20	20	10	M6	1.82
L1016.RF20-0760	20	760	16.3	60	20	20	10	M6	1.98
L1016.RF20-0820	20	820	16.3	60	20	20	10	M6	2.13
L1016.RF20-0880	20	880	16.3	60	20	20	10	M6	2.29
L1016.RF20-0940	20	940	16.3	60	20	20	10	M6	2.44
L1016.RF20-1000	20	1000	16.3	60	20	20	10	M6	2.60
L1016.RF20-1060	20	1060	16.3	60	20	20	10	M6	2.76
L1016.RF20-1120	20	1120	16.3	60	20	20	10	M6	2.91
L1016.RF20-1180	20	1180	16.3	60	20	20	10	M6	3.07
L1016.RF20-1240	20	1240	16.3	60	20	20	10	M6	3.22
L1016.RF20-1300	20	1300	16.3	60	20	20	10	M6	3.38
L1016.RF20-1360	20	1360	16.3	60	20	20	10	M6	3.54
L1016.RF20-1420	20	1420	16.3	60	20	20	10	M6	3.69
L1016.RF20-1480	20	1480	16.3	60	20	20	10	M6	3.85
L1016.RF20-1540	20	1540	16.3	60	20	20	10	M6	4.00
L1016.RF20-1600	20	1600	16.3	60	20	20	10	M6	4.16
L1016.RF20-1660	20	1660	16.3	60	20	20	10	M6	4.32
L1016.RF20-1720	20	1720	16.3	60	20	20	10	M6	4.47
L1016.RF20-1780	20	1780	16.3	60	20	20	10	M6	4.63
L1016.RF20-1840	20	1840	16.3	60	20	20	10	M6	4.78
L1016.RF20-1900	20	1900	16.3	60	20	20	10	M6	4.94
L1016.RF20-1960	20	1960	16.3	60	20	20	10	M6	5.10
L1016.RF20-2020	20	2020	16.3	60	20	20	10	M6	5.25

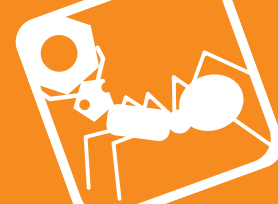

Order No.	Rail size	l_1	h_1	l_2	w_1	l_3	h_2	d_1	Weight kg
L1016.RF20-2080	20	2080	16.3	60	20	20	10	M6	5.41
L1016.RF20-2140	20	2140	16.3	60	20	20	10	M6	5.56
L1016.RF20-2200	20	2200	16.3	60	20	20	10	M6	5.72
L1016.RF20-2260	20	2260	16.3	60	20	20	10	M6	5.88
L1016.RF20-2320	20	2320	16.3	60	20	20	10	M6	6.03
L1016.RF20-2380	20	2380	16.3	60	20	20	10	M6	6.19
L1016.RF20-2440	20	2440	16.3	60	20	20	10	M6	6.34
L1016.RF20-2500	20	2500	16.3	60	20	20	10	M6	6.50
L1016.RF20-2560	20	2560	16.3	60	20	20	10	M6	6.66
L1016.RF20-2620	20	2620	16.3	60	20	20	10	M6	6.81
L1016.RF20-2680	20	2680	16.3	60	20	20	10	M6	6.97
L1016.RF20-2740	20	2740	16.3	60	20	20	10	M6	7.12
L1016.RF20-2800	20	2800	16.3	60	20	20	10	M6	7.28
L1016.RF20-2860	20	2860	16.3	60	20	20	10	M6	7.44
L1016.RF20-2920	20	2920	16.3	60	20	20	10	M6	7.59
L1016.RF20-2980	20	2980	16.3	60	20	20	10	M6	7.75
L1016.RF20-3040	20	3040	16.3	60	20	20	10	M6	7.90
L1016.RF20-3100	20	3100	16.3	60	20	20	10	M6	8.06
L1016.RF20-3160	20	3160	16.3	60	20	20	10	M6	8.22
L1016.RF20-3220	20	3220	16.3	60	20	20	10	M6	8.37
L1016.RF20-3280	20	3280	16.3	60	20	20	10	M6	8.53
L1016.RF20-3340	20	3340	16.3	60	20	20	10	M6	8.68
L1016.RF20-3400	20	3400	16.3	60	20	20	10	M6	8.84
L1016.RF20-3460	20	3460	16.3	60	20	20	10	M6	9.00
L1016.RF20-3520	20	3520	16.3	60	20	20	10	M6	9.15
L1016.RF20-3580	20	3580	16.3	60	20	20	10	M6	9.31
L1016.RF20-3640	20	3640	16.3	60	20	20	10	M6	9.46
L1016.RF20-3700	20	3700	16.3	60	20	20	10	M6	9.62
L1016.RF20-3760	20	3760	16.3	60	20	20	10	M6	9.78
L1016.RF20-3820	20	3820	16.3	60	20	20	10	M6	9.93
L1016.RF20-3880	20	3880	16.3	60	20	20	10	M6	10.09
L1016.RF20-3940	20	3940	16.3	60	20	20	10	M6	10.24
L1016.RF20-4000	20	4000	16.3	60	20	20	10	M6	10.40