




30mm Linear Guide Rail

rear fixing

Linear Guide-ways

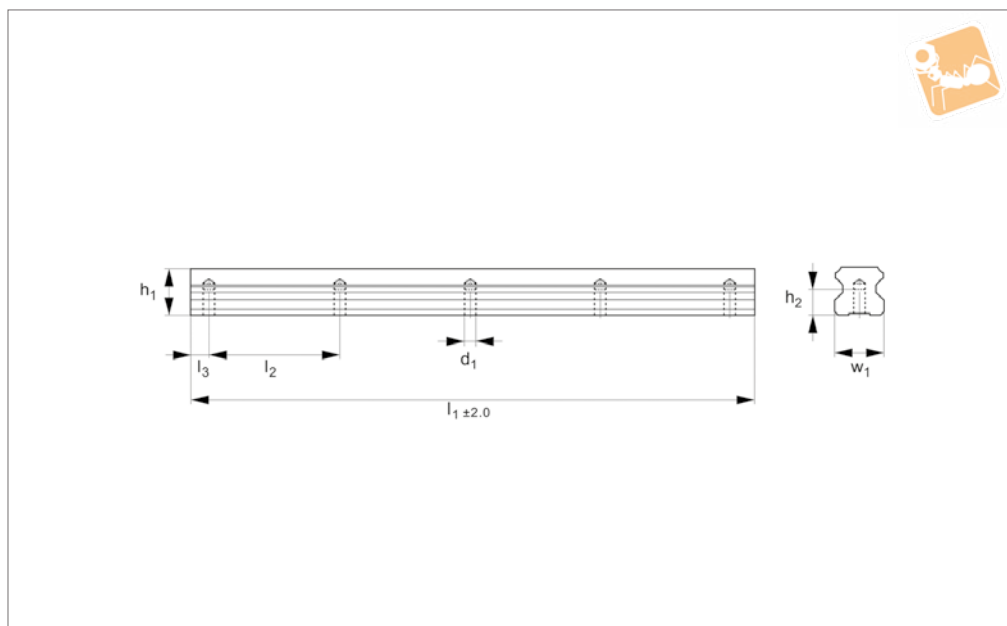

L1016.RF30

LINEAR GUIDEWAYS

Material

Hardened and ground steel (typically 60 HRC).

part nos. L1016.F (flanged) and L1016.U (unflanged).


Other rail lengths on request.

Weight: 5,2 Kg/m.

Technical Notes

For carriages to suit the required load see

Order No.	Rail size	l_1	h_1	l_2	w_1	l_3	h_2	d_1	Weight kg
L1016.RF30-0200	30	200	22.8	80	28	20	15	M8	1.04
L1016.RF30-0280	30	280	22.8	80	28	20	15	M8	1.46
L1016.RF30-0360	30	360	22.8	80	28	20	15	M8	1.87
L1016.RF30-0440	30	440	22.8	80	28	20	15	M8	2.29
L1016.RF30-0520	30	520	22.8	80	28	20	15	M8	2.70
L1016.RF30-0600	30	600	22.8	80	28	20	15	M8	3.12
L1016.RF30-0680	30	680	22.8	80	28	20	15	M8	3.54
L1016.RF30-0760	30	760	22.8	80	28	20	15	M8	3.95
L1016.RF30-0840	30	840	22.8	80	28	20	15	M8	4.37
L1016.RF30-0920	30	920	22.8	80	28	20	15	M8	4.78
L1016.RF30-1000	30	1000	22.8	80	28	20	15	M8	5.20
L1016.RF30-1080	30	1080	22.8	80	28	20	15	M8	5.62
L1016.RF30-1160	30	1160	22.8	80	28	20	15	M8	6.03
L1016.RF30-1240	30	1240	22.8	80	28	20	15	M8	6.45
L1016.RF30-1320	30	1320	22.8	80	28	20	15	M8	6.86
L1016.RF30-1400	30	1400	22.8	80	28	20	15	M8	7.28
L1016.RF30-1480	30	1480	22.8	80	28	20	15	M8	7.70
L1016.RF30-1560	30	1560	22.8	80	28	20	15	M8	8.11
L1016.RF30-1640	30	1640	22.8	80	28	20	15	M8	8.53
L1016.RF30-1720	30	1720	22.8	80	28	20	15	M8	8.94
L1016.RF30-1800	30	1800	22.8	80	28	20	15	M8	9.36
L1016.RF30-1880	30	1880	22.8	80	28	20	15	M8	9.78
L1016.RF30-1960	30	1960	22.8	80	28	20	15	M8	10.19
L1016.RF30-2040	30	2040	22.8	80	28	20	15	M8	10.61
L1016.RF30-2120	30	2120	22.8	80	28	20	15	M8	11.02
L1016.RF30-2200	30	2200	22.8	80	28	20	15	M8	11.44
L1016.RF30-2280	30	2280	22.8	80	28	20	15	M8	11.86
L1016.RF30-2360	30	2360	22.8	80	28	20	15	M8	12.27
L1016.RF30-2440	30	2440	22.8	80	28	20	15	M8	12.69
L1016.RF30-2520	30	2520	22.8	80	28	20	15	M8	13.10
L1016.RF30-2600	30	2600	22.8	80	28	20	15	M8	13.52
L1016.RF30-2680	30	2680	22.8	80	28	20	15	M8	13.94

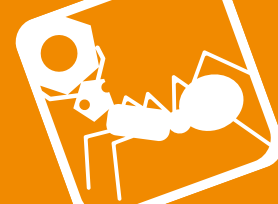

Order No.	Rail size	l_1	h_1	l_2	w_1	l_3	h_2	d_1	Weight kg
L1016.RF30-2760	30	2760	22.8	80	28	20	15	M8	14.35
L1016.RF30-2840	30	2840	22.8	80	28	20	15	M8	14.77
L1016.RF30-2920	30	2920	22.8	80	28	20	15	M8	15.18
L1016.RF30-3000	30	3000	22.8	80	28	20	15	M8	15.60
L1016.RF30-3080	30	3080	22.8	80	28	20	15	M8	16.02
L1016.RF30-3160	30	3160	22.8	80	28	20	15	M8	16.43
L1016.RF30-3240	30	3240	22.8	80	28	20	15	M8	16.85
L1016.RF30-3320	30	3320	22.8	80	28	20	15	M8	17.26
L1016.RF30-3400	30	3400	22.8	80	28	20	15	M8	17.68
L1016.RF30-3480	30	3480	22.8	80	28	20	15	M8	18.10
L1016.RF30-3560	30	3560	22.8	80	28	20	15	M8	18.51
L1016.RF30-3640	30	3640	22.8	80	28	20	15	M8	18.93
L1016.RF30-3720	30	3720	22.8	80	28	20	15	M8	19.34
L1016.RF30-3800	30	3800	22.8	80	28	20	15	M8	19.76
L1016.RF30-3880	30	3880	22.8	80	28	20	15	M8	20.18
L1016.RF30-3960	30	3960	22.8	80	28	20	15	M8	20.59
L1016.RF30-4000	30	4000	22.8	80	28	20	15	M8	20.80