



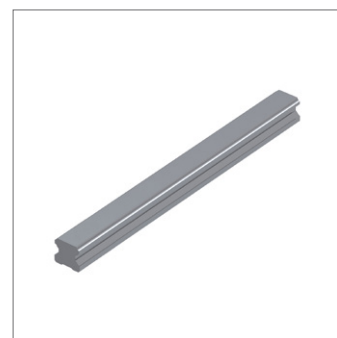

45mm Linear Guide Rail

rear fixing

Linear Guide-
ways

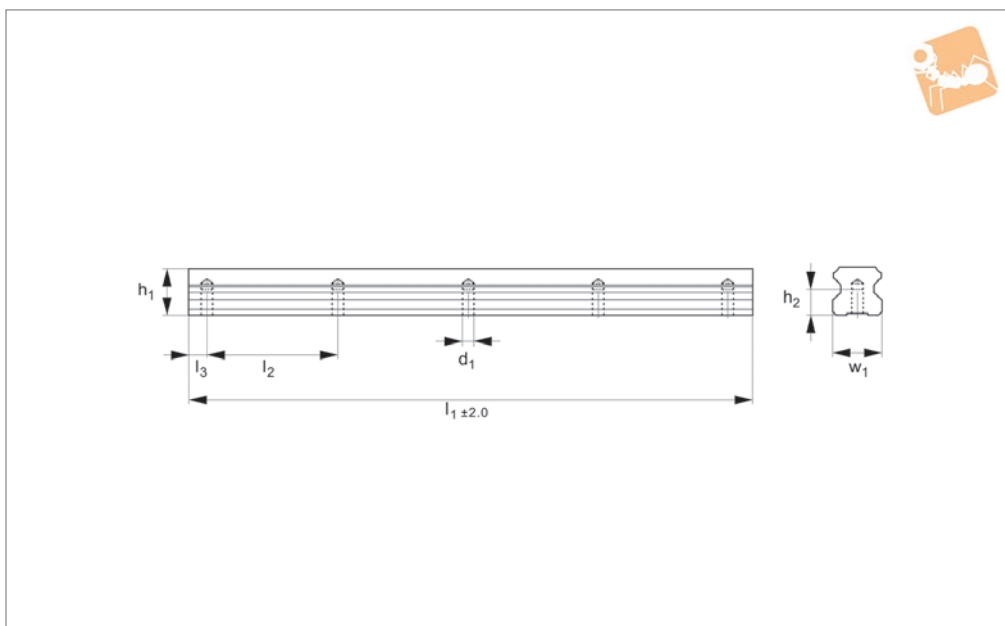

L1016.RF45

LINEAR GUIDEWAYS

Material

Hardened and ground steel (typically 60 HRC).

part nos. L1016.F (flanged) and L1016.U (unflanged).


Other rail lengths on request.

Weight: 12,3 Kg/m.

Technical Notes

For carriages to suit the required load see

Order No.	Rail size	l_1	h_1	l_2	w_1	l_3	h_2	d_1	Weight kg
L1016.RF45-0255	45	255	31.1	105	45	22.5	24	M12	26.09
L1016.RF45-0360	45	360	31.1	105	45	22.5	24	M12	36.83
L1016.RF45-0465	45	465	31.1	105	45	22.5	24	M12	47.57
L1016.RF45-0570	45	570	31.1	105	45	22.5	24	M12	58.31
L1016.RF45-0675	45	675	31.1	105	45	22.5	24	M12	69.05
L1016.RF45-0780	45	780	31.1	105	45	22.5	24	M12	79.79
L1016.RF45-0885	45	885	31.1	105	45	22.5	24	M12	90.54
L1016.RF45-0990	45	990	31.1	105	45	22.5	24	M12	101.28
L1016.RF45-1095	45	1095	31.1	105	45	22.5	24	M12	13.47
L1016.RF45-1200	45	1200	31.1	105	45	22.5	24	M12	14.76
L1016.RF45-1305	45	1305	31.1	105	45	22.5	24	M12	16.05
L1016.RF45-1410	45	1410	31.1	105	45	22.5	24	M12	17.34
L1016.RF45-1515	45	1515	31.1	105	45	22.5	24	M12	18.63
L1016.RF45-1620	45	1620	31.1	105	45	22.5	24	M12	19.93
L1016.RF45-1725	45	1725	31.1	105	45	22.5	24	M12	21.22
L1016.RF45-1830	45	1830	31.1	105	45	22.5	24	M12	22.51
L1016.RF45-1935	45	1935	31.1	105	45	22.5	24	M12	23.80
L1016.RF45-2040	45	2040	31.1	105	45	22.5	24	M12	25.09
L1016.RF45-2145	45	2145	31.1	105	45	22.5	24	M12	26.38
L1016.RF45-2250	45	2250	31.1	105	45	22.5	24	M12	27.68
L1016.RF45-2355	45	2355	31.1	105	45	22.5	24	M12	28.97
L1016.RF45-2460	45	2460	31.1	105	45	22.5	24	M12	30.26
L1016.RF45-2565	45	2565	31.1	105	45	22.5	24	M12	31.55
L1016.RF45-2670	45	2670	31.1	105	45	22.5	24	M12	32.84
L1016.RF45-2775	45	2775	31.1	105	45	22.5	24	M12	34.13
L1016.RF45-2880	45	2880	31.1	105	45	22.5	24	M12	35.42
L1016.RF45-2985	45	2985	31.1	105	45	22.5	24	M12	36.72
L1016.RF45-3090	45	3090	31.1	105	45	22.5	24	M12	38.01
L1016.RF45-3195	45	3195	31.1	105	45	22.5	24	M12	39.30
L1016.RF45-3300	45	3300	31.1	105	45	22.5	24	M12	40.59
L1016.RF45-3405	45	3405	31.1	105	45	22.5	24	M12	41.88
L1016.RF45-3510	45	3510	31.1	105	45	22.5	24	M12	43.17

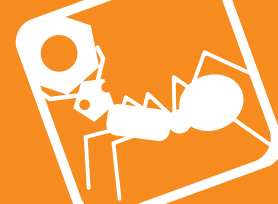

Order No.	Rail size	l_1	h_1	l_2	w_1	l_3	h_2	d_1	Weight kg
L1016.RF45-3615	45	3615	31.1	105	45	22.5	24	M12	44.46
L1016.RF45-3720	45	3720	31.1	105	45	22.5	24	M12	45.76
L1016.RF45-3825	45	3825	31.1	105	45	22.5	24	M12	47.05
L1016.RF45-3930	45	3930	31.1	105	45	22.5	24	M12	48.34
L1016.RF45-4000	45	4000	31.1	105	45	22.5	24	M12	49.20