




Shaft End Supports

316 series stainless steel

Linear Shaft Bars

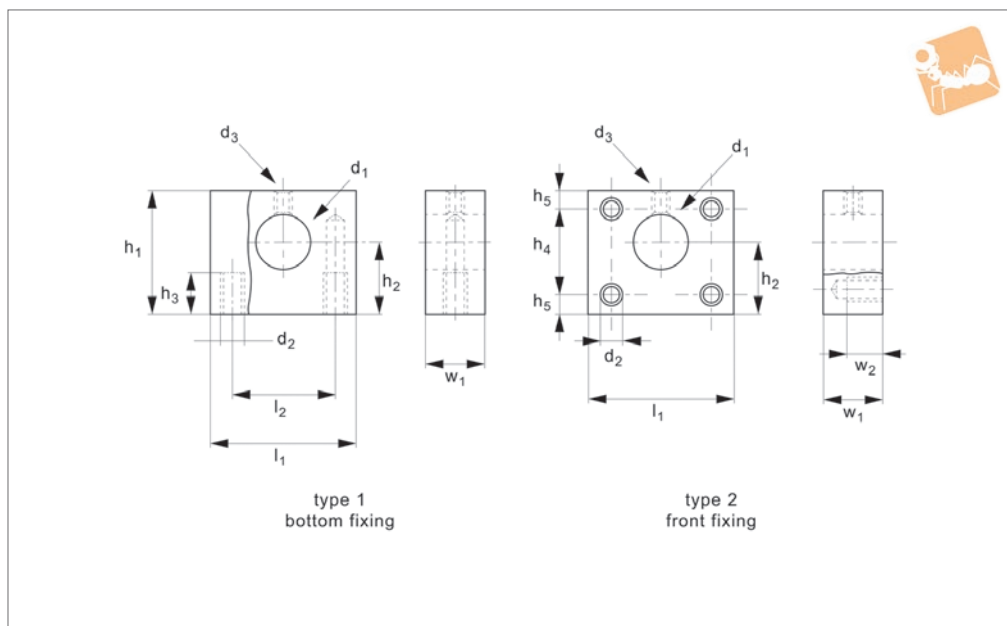

L1779.A4

LINEAR SHAFT BARS

Material

Stainless steel (AISI 316, 1.440).

Technical Notes

For mounting of standard shaft diameters, tolerance h6.

Order No.	Type	d ₁ tol. G7	d ₂	d ₃	h ₁	h ₂	h ₃	h ₄	h ₅	l ₁	l ₂	w ₁	w ₂
L1779.01-120-A4	1	12	M 6	M 3	34	19	12	-	-	40	27	18	-
L1779.01-160-A4	1	16	M 6	M 3	38	22	13	-	-	45	32	20	-
L1779.01-200-A4	1	20	M 8	M 4	46	26	15	-	-	46	39	24	-
L1779.01-250-A4	1	25	M10	M 4	54	31	18	-	-	54	44	28	-
L1779.01-300-A4	1	30	M10	M 4	62	36	22	-	-	67	49	30	-
L1779.01-400-A4	1	40	M12	M 5	80	46	22	-	-	87	66	40	-
L1779.02-120-A4	2	12	M 6	M 3	34	19	-	22	6	40	-	18	12
L1779.02-160-A4	2	16	M 6	M 3	38	22	-	26	6	45	-	20	13
L1779.02-200-A4	2	20	M 8	M 4	46	26	-	30	8	46	-	24	15
L1779.02-250-A4	2	25	M10	M 4	54	31	-	38	8	54	-	28	18
L1779.02-300-A4	2	30	M10	M 4	62	36	-	42	10	67	-	30	22
L1779.02-400-A4	2	40	M12	M 5	80	46	-	60	10	87	-	40	22