




# Curviline Sliders

Stainless steel; size 16



## Long Linear Rails

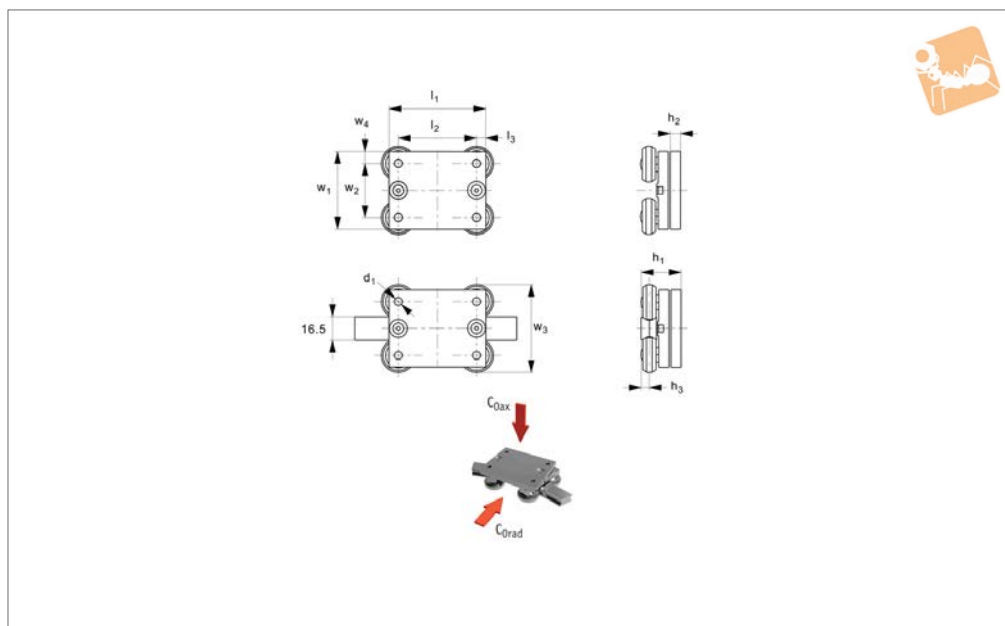

**L1979.CR16**

LONG LINEAR RAILS

### Material

Slider body: AISI 316L. Roller AISI 440.

or more sliders.

Temperature range -30oC to +100oC.

Other coatings and finishes are also available.

### Technical Notes

Where moment loads are present, use two

### Tips

All stainless available.

| Order No.      | w <sub>1</sub> | h <sub>1</sub> | d <sub>1</sub> | h <sub>2</sub> | h <sub>3</sub> | l <sub>1</sub> | l <sub>2</sub> | l <sub>3</sub> | w <sub>2</sub> | w <sub>3</sub> | w <sub>4</sub> | Load C <sub>0 rad</sub><br>N max. | Load C <sub>0 ax</sub><br>N max. | Weight<br>kg |
|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|----------------|-----------------------------------|----------------------------------|--------------|
| L1979.CR16-070 | 50             | 32.3           | M5             | 10             | 5.7            | 70             | 50             | 10             | 30             | 60             | 10             | 570                               | 400                              | 0.45         |