




# Curviline Sliders

Stainless steel; size 23



## Long Linear Rails

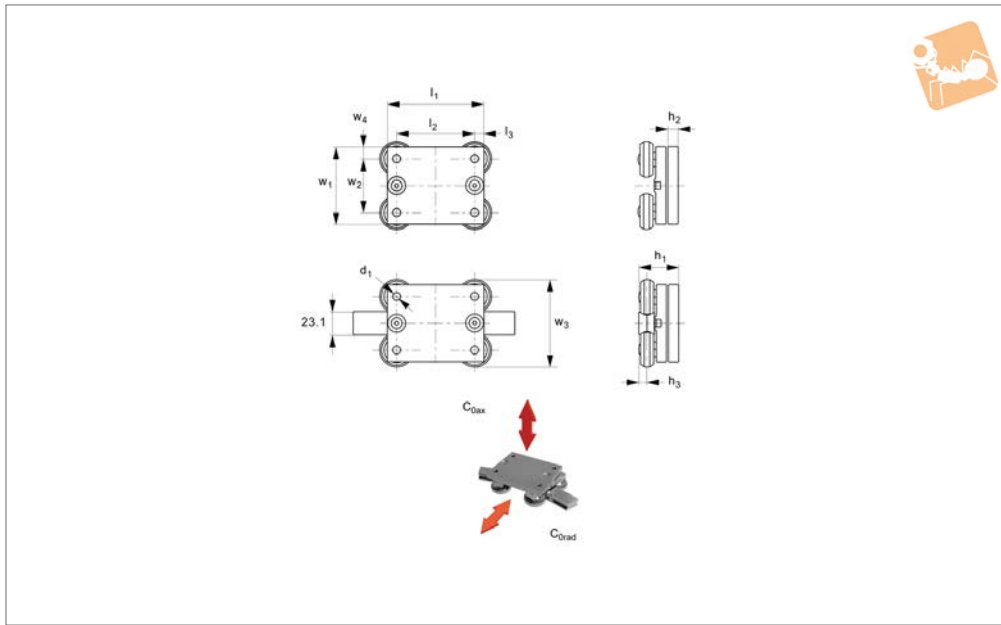

## L1979.CR23

LONG LINEAR RAILS

### Material

Slider body: AISI 316L. Roller AISI 440.

or more sliders.

Temperature range -30°C to +100°C.

Other coatings and finishes are also available.

### Technical Notes

Where moment loads are present use two

### Tips

All stainless steel available.

Order No.	w <sub>1</sub>	h <sub>1</sub>	d <sub>1</sub>	h <sub>2</sub>	h <sub>3</sub>	l <sub>1</sub>	l <sub>2</sub>	l <sub>3</sub>	w <sub>2</sub>	w <sub>3</sub>	w <sub>4</sub>	Load C <sub>0 rad</sub> N max.	Load C <sub>0 ax</sub> N max.	Weight kg
L1979.CR23-100	80	36.4	M8	10	7.5	100	80	10	55	89.5	12.5	1615	1130	1.10