



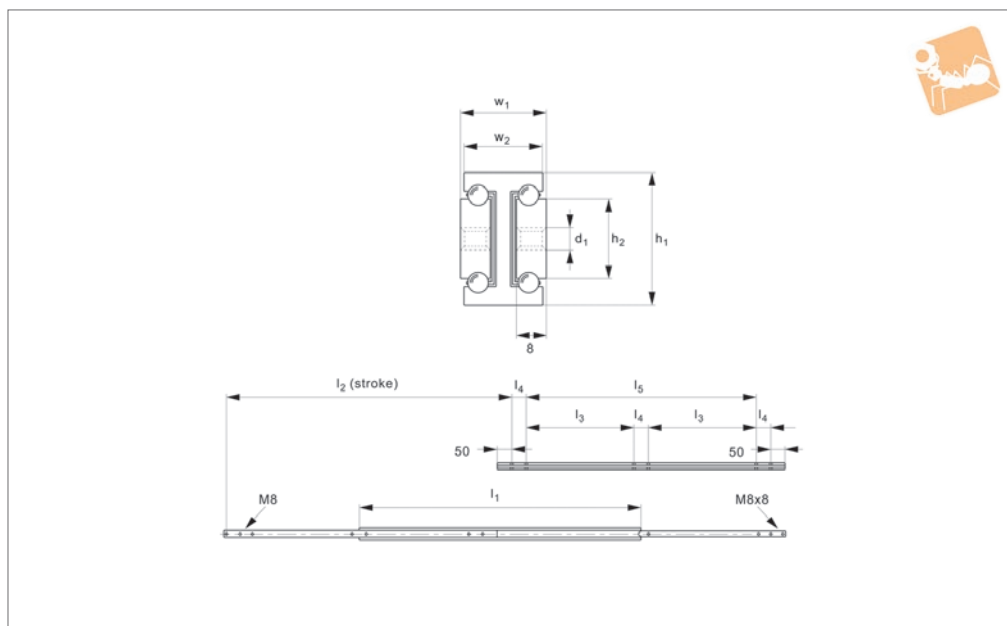

Stainless AISI 316 Slides

fully telescopic, size 40

Telescopic Slides

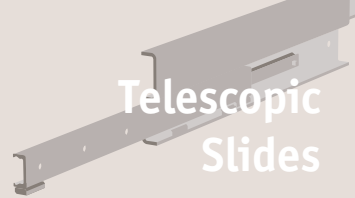

L2051

TELESCOPIC SLIDES

Material

Stainless steel (A4, AISI 316) - rail, balls and ball cage.

an evenly distributed load centred around the mid extension point of the slide. Other sizes on request.

Technical Notes

Full extension. Load ratings are based on

Ideal for applications requiring a high degree of corrosion resistance.

Order No.	l_1	l_2 stroke	h_1	h_2	d_1	l_3	l_4	l_5	w_1	w_2	Load/pair kg max.
L2051.0200	200	200	40	25	M8	-	-	50	24	22	250
L2051.0250	250	250	40	25	M8	-	50	50	24	22	245
L2051.0300	300	300	40	25	M8	-	100	50	24	22	240
L2051.0350	350	350	40	25	M8	-	150	50	24	22	235
L2051.0400	400	400	40	25	M8	-	200	50	24	22	230
L2051.0450	450	450	40	25	M8	-	250	50	24	22	225
L2051.0500	500	500	40	25	M8	-	300	50	24	22	220
L2051.0550	550	550	40	25	M8	150	-	50	24	22	210
L2051.0600	600	600	40	25	M8	175	-	50	24	22	205
L2051.0650	650	650	40	25	M8	200	-	50	24	22	200
L2051.0700	700	700	40	25	M8	225	-	50	24	22	195
L2051.0750	750	750	40	25	M8	250	-	50	24	22	190
L2051.0800	800	800	40	25	M8	275	-	50	24	22	180
L2051.0850	850	850	40	25	M8	300	-	50	24	22	170
L2051.0900	900	900	40	25	M8	325	-	50	24	22	160
L2051.0950	950	950	40	25	M8	350	-	50	24	22	150
L2051.1000	1000	1000	40	25	M8	375	-	50	24	22	140