



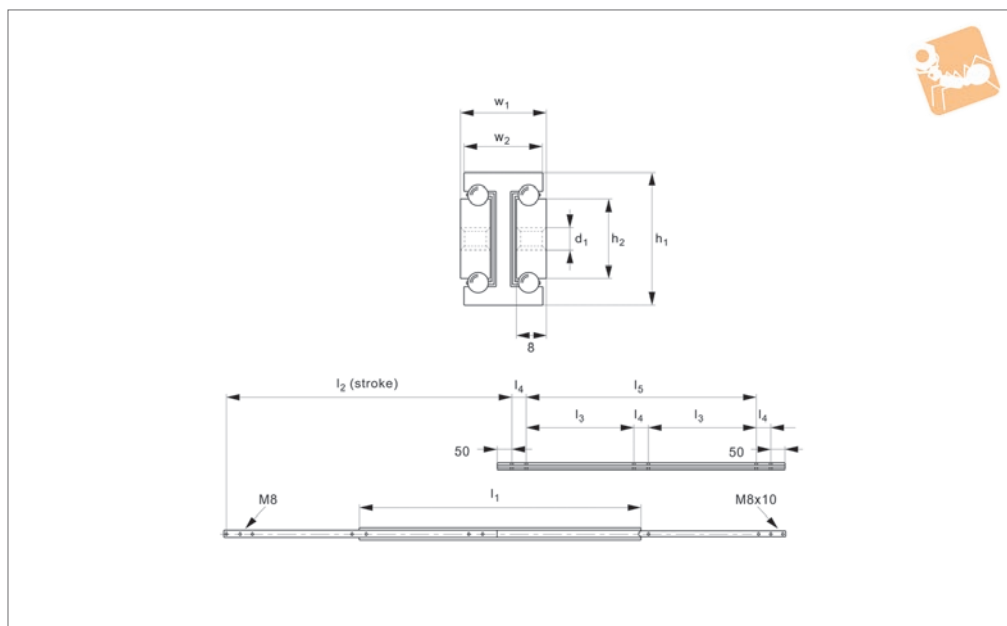

Stainless AISI 316 Slides

fully telescopic, size 50

Telescopic Slides

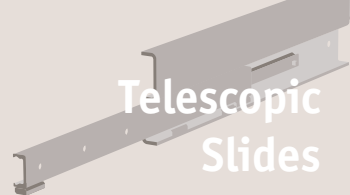

L2052

TELESCOPIC SLIDES

Material

Stainless steel (A4, AISI 316) - rail, balls and ball cage.

an evenly distributed load centred around the mid extension point of the slide. Other sizes on request.

Technical Notes

Full extension. Load ratings are based on

Ideal for applications requiring a high degree of corrosion resistance.

Order No.	l_1	l_2 stroke	h_1	h_2	d_1	l_3	l_4	l_5	w_1	w_2	Load/pair kg max.
L2052.0200	200	200	50	30	M8	-	-	50	30	25	390
L2052.0250	250	250	50	30	M8	-	50	50	30	25	380
L2052.0350	350	350	50	30	M8	-	150	50	30	25	360
L2052.0400	400	400	50	30	M8	-	200	50	30	25	350
L2052.0450	450	450	50	30	M8	-	250	50	30	25	340
L2052.0500	500	500	50	30	M8	-	300	50	30	25	330
L2052.0550	550	550	50	30	M8	150	-	50	30	25	320
L2052.0600	600	600	50	30	M8	175	-	50	30	25	310
L2052.0650	650	650	50	30	M8	200	-	50	30	25	300
L2052.0700	700	700	50	30	M8	225	-	50	30	25	290
L2052.0750	750	750	50	30	M8	250	-	50	30	25	280
L2052.0800	800	800	50	30	M8	275	-	50	30	25	270
L2052.0850	850	850	50	30	M8	300	-	50	30	25	260
L2052.0900	900	900	50	30	M8	325	-	50	30	25	250
L2052.0950	950	950	50	30	M8	350	-	50	30	25	240
L2052.1000	1000	1000	50	30	M8	375	-	50	30	25	230
L2052.1050	1050	1050	50	30	M8	400	-	50	30	25	220
L2052.1100	1100	1100	50	30	M8	425	-	50	30	25	210
L2052.1150	1150	1150	50	30	M8	450	-	50	30	25	205
L2052.1200	1200	1200	50	30	M8	475	-	50	30	25	200
L2052.1250	1250	1250	50	30	M8	500	-	50	30	25	195
L2052.1300	1300	1300	50	30	M8	525	-	50	30	25	190
L2052.1350	1350	1350	50	30	M8	550	-	50	30	25	185
L2052.1400	1400	1400	50	30	M8	575	-	50	30	25	180