



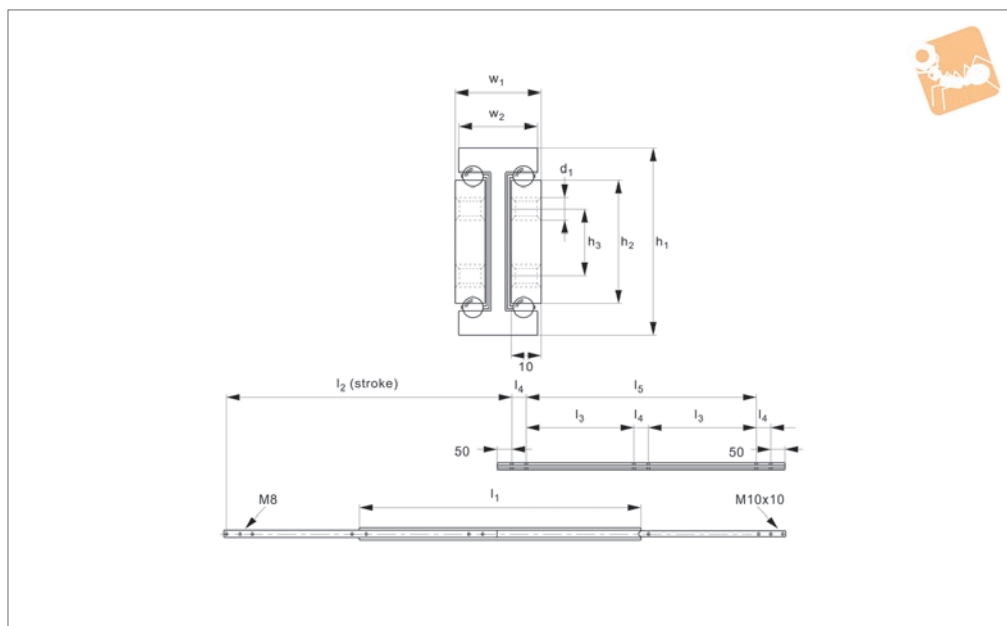

Stainless AISI 316 Slides

fully telescopic, size 70

Telescopic Slides

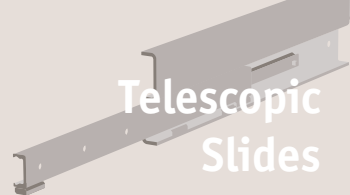

L2054

TELESCOPIC SLIDES

Material

Stainless steel (A4, AISI 316) - rail, balls and ball cage.

an evenly distributed load centred around the mid extension point of the slide. Other sizes on request.

Technical Notes

Full extension. Load ratings are based on

Ideal for applications requiring a high degree of corrosion resistance.

Order No.	l_1	l_2 stroke	h_1	h_2	h_3	d_1	l_3	l_4	l_5	w_1	w_2	Load/pair kg max.
L2054.0400	400	400	70	45	25	M8	-	200	50	32	30	470
L2054.0450	450	450	70	45	25	M8	-	250	50	32	30	460
L2054.0500	500	500	70	45	25	M8	-	300	50	32	30	450
L2054.0550	550	550	70	45	25	M8	-	350	50	32	30	440
L2054.0600	600	600	70	45	25	M8	-	400	50	32	30	430
L2054.0650	650	650	70	45	25	M8	200	-	50	32	30	420
L2054.0700	700	700	70	45	25	M8	225	-	50	32	30	410
L2054.0750	750	750	70	45	25	M8	250	-	50	32	30	400
L2054.0800	800	800	70	45	25	M8	275	-	50	32	30	390
L2054.0850	850	850	70	45	25	M8	300	-	50	32	30	380
L2054.0900	900	900	70	45	25	M8	325	-	50	32	30	370
L2054.0950	950	950	70	45	25	M8	350	-	50	32	30	360
L2054.1000	1000	1000	70	45	25	M8	375	-	50	32	30	350
L2054.1050	1050	1050	70	45	25	M8	400	-	50	32	30	340
L2054.1100	1100	1100	70	45	25	M8	425	-	50	32	30	330
L2054.1150	1150	1150	70	45	25	M8	450	-	50	32	30	320
L2054.1200	1200	1200	70	45	25	M8	475	-	50	32	30	310
L2054.1250	1250	1250	70	45	25	M8	500	-	50	32	30	300
L2054.1300	1300	1300	70	45	25	M8	525	-	50	32	30	290
L2054.1350	1350	1350	70	45	25	M8	550	-	50	32	30	280
L2054.1400	1400	1400	70	45	25	M8	575	-	50	32	30	270
L2054.1450	1450	1450	70	45	25	M8	600	-	50	32	30	260
L2054.1500	1500	1500	70	45	25	M8	625	-	50	32	30	250
L2054.1550	1550	1550	70	45	25	M8	650	-	50	32	30	240
L2054.1600	1600	1600	70	45	25	M8	675	-	50	32	30	230
L2054.1650	1650	1650	70	45	25	M8	700	-	50	32	30	220
L2054.1700	1700	1700	70	45	25	M8	650	-	100	32	30	210
L2054.1750	1750	1750	70	45	25	M8	675	-	100	32	30	200
L2054.1800	1800	1800	70	45	25	M8	700	-	100	32	30	190
L2054.1850	1850	1850	70	45	25	M8	725	-	100	32	30	180
L2054.1900	1900	1900	70	45	25	M8	750	-	100	32	30	170



Order No.	l_1	l_2 stroke	h_1	h_2	h_3	d_1	l_3	l_4	l_5	w_1	w_2	Load/pair kg max.
L2054.1950	1950	1950	70	45	25	M8	775	-	100	32	30	160
L2054.2000	2000	2000	70	45	25	M8	800	-	100	32	30	150