



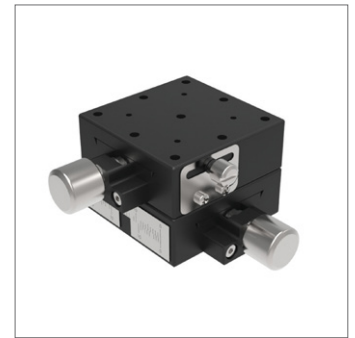

Miniature Dovetail Stages

XY axis

Manual Positioning Stages

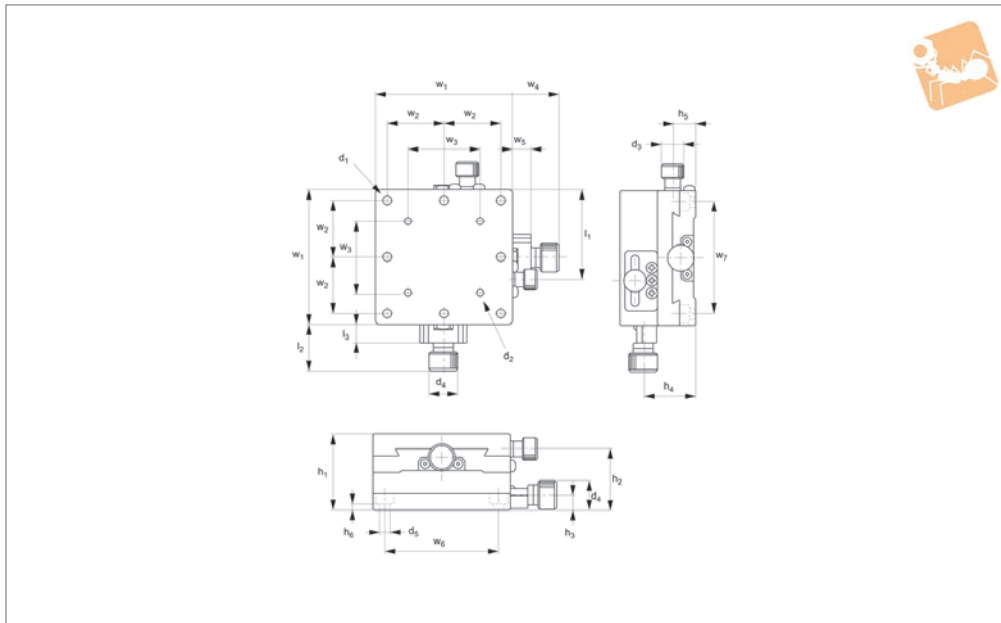

L3300.XY

MANUAL POSITIONING STAGES

Material

Brass, blackened body, aluminium knob.

Minimum vernier reading 0,1mm.

Straightness accuracy 30μ.

Technical Notes

Travel 0,5mm for one revolution.

Order No.	h_1	Travel	Load kg max.	w_1	d_1	d_2	d_3	d_4
L3300.025-XY	30	±3	2.9	25	M2	-	6	12
L3300.040-XY	30	±7	2.8	40	M3	M2	6	12
L3300.060-XY	34	±9	3.4	60	M4	M3	10	12

Order No.	d_5	h_2	h_3	h_4	h_5	h_6	l_1	l_2	l_3	w_2	w_3	w_4	w_5	w_6	w_7
L3300.025-XY	2.5	26.5	7.0	22.0	11.5	4.5	15	20	8	10	-	20	8.0	8	20
L3300.040-XY	3.5	26.5	7.0	22.0	11.5	3.5	28	20	8	20	20	20	8.0	8	32
L3300.060-XY	4.5	27.5	6.5	23.5	10.5	2.5	40	20	8	25	32	20	11.5	8	50