




Dovetail Stages - Rack & Pinion

X axis

Manual Positioning Stages

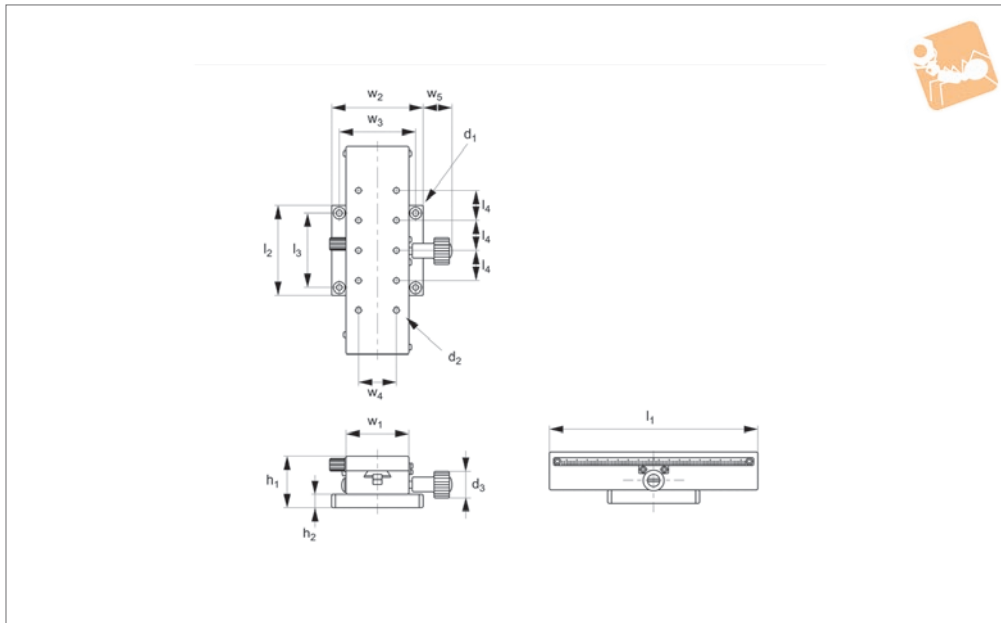

L3303.X

MANUAL POSITIONING STAGES

Material

Aluminium body blackened, steel knob.

Minimum vernier reading 0,1mm.

Straightness accuracy 30μ.

Technical Notes

Travel 18mm for one revolution.

Order No.	h_1	Travel	Load kg max.	w_1	d_1	d_2	d_3	h_2	l_1	l_2	l_3	l_4	w_2	w_3	w_4	w_5
L3303.042-X	34	±12	3.0	24.8	4.5	M4	15	8	42	50	40	20	50	40	15	17.8
L3303.060-X	34	±21	4.0	40.0	4.5	M4	15	8	60	60	50	20	60	50	25	17.8
L3303.090-X	34	±35	4.0	40.0	4.5	M4	15	8	90	60	50	20	60	50	25	17.8
L3303.140-X	34	±60	4.0	40.0	4.5	M4	15	8	140	60	50	20	60	50	25	17.8