




Dovetail Stages - Rack & Pinion XY axis

Manual Positioning Stages

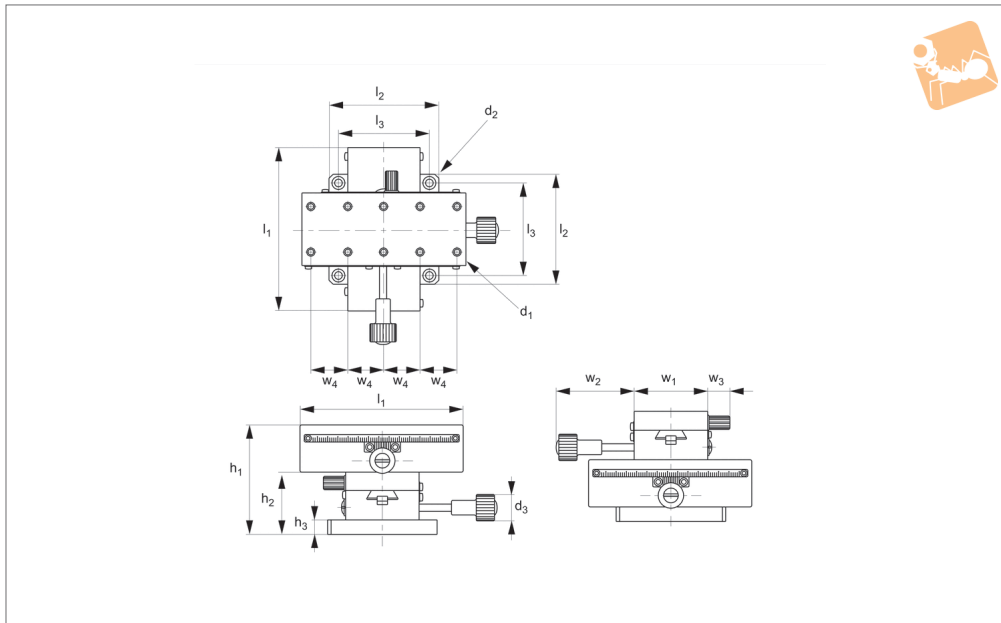

L3303.XY

MANUAL POSITIONING STAGES

Material

Aluminium body blackened, steel knob.

Minimum vernier reading 0,1mm.

Straightness accuracy 30μ.

Technical Notes

Travel 18mm for one revolution.

Order No.	h_1	Travel	Load kg max.	w_1	d_1	d_2	d_3	h_2	h_3	l_1	l_2	l_3	w_2	w_3	w_4
L3303.042-XY	60	±12	2.5	24.8	M4	4.5	15	8	34	42	50	40	28	12	12.5
L3303.060-XY	60	±21	3.5	40.0	M4	4.5	15	8	34	60	60	50	28	12	20
L3303.090-XY	60	±35	3.5	40.0	M4	4.5	15	8	34	90	60	50	43	13	20