




L4546

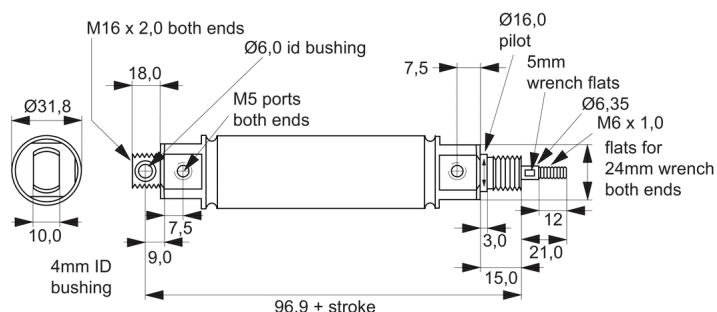

Order No.	Bore dia.	Stroke	Length	Pressure MPa max.	Leak rate by piston SL/min max.	Leak rate by rod SL/mm max.	Reset spring force rod extended N	Reset spring force rod retracted N	Weight g
L4546.012	24,0	12,5	109,4	0,7	2,2	2,6	1,44	1,34	172,49
L4546.025	24,0	25,0	121,9	0,7	2,2	2,6	1,44	1,26	187,81
L4546.037	24,0	37,5	134,4	0,7	2,2	2,6	1,44	1,17	203,12
L4546.050	24,0	50,0	146,9	0,7	2,2	2,6	1,44	1,09	218,43