




# Cylinder / Piston Set

1,281" bore

## Cylinders

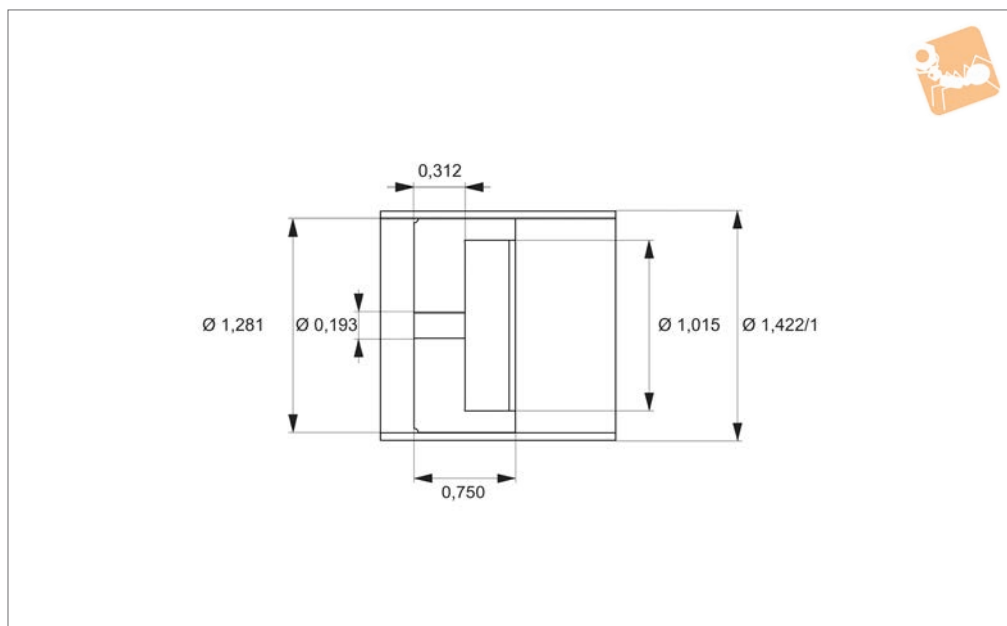

**L4638**

CYLINDERS

### Material

Piston: Carbon graphite  
Cylinder: Glass

### Technical Notes

Max operating temp = 260°C

### Important Notes

Specials available on request.

| Order No.  | Stroke | Bore dia. | Outside dia. | Cylinder length | Piston length | Piston area<br>in <sup>2</sup> | Friction<br>g<br>w/o sideload | Cylinder weight<br>g | Piston weight<br>g |
|------------|--------|-----------|--------------|-----------------|---------------|--------------------------------|-------------------------------|----------------------|--------------------|
| L4638.0500 | 0,5"   | 1.281     | 1.456        | 1,350"          | 0.750         | 1.289                          | < 1                           | 13.82                | 17.75              |
| L4638.1000 | 1,0"   | 1.281     | 1.456        | 1,850"          | 0.750         | 1.289                          | < 1                           | 13.82                | 17.75              |
| L4638.2000 | 2,0"   | 1.281     | 1.456        | 2,850"          | 0.750         | 1.289                          | < 1                           | 13.82                | 17.75              |
| L4638.3000 | 3,0"   | 1.281     | 1.456        | 3,850"          | 0.750         | 1.289                          | < 1                           | 13.82                | 17.75              |
| L4638.4000 | 4,0"   | 1.281     | 1.456        | 4,850"          | 0.750         | 1.289                          | < 1                           | 13.82                | 17.75              |
| L4638.5000 | 5,0"   | 1.281     | 1.456        | 5,850"          | 0.750         | 1.289                          | < 1                           | 13.82                | 17.75              |
| L4638.6000 | 6,0"   | 1.281     | 1.456        | 6,850"          | 0.750         | 1.289                          | < 1                           | 13.82                | 17.75              |
| L4638.7000 | 7,0"   | 1.281     | 1.456        | 7,850"          | 0.750         | 1.289                          | < 1                           | 13.82                | 17.75              |
| L4638.8000 | 8,0"   | 1.281     | 1.456        | 8,850"          | 0.750         | 1.289                          | < 1                           | 13.82                | 17.75              |