




Air Cylinder Mounts - ISO Series

clevis foot bracket

Cylinders

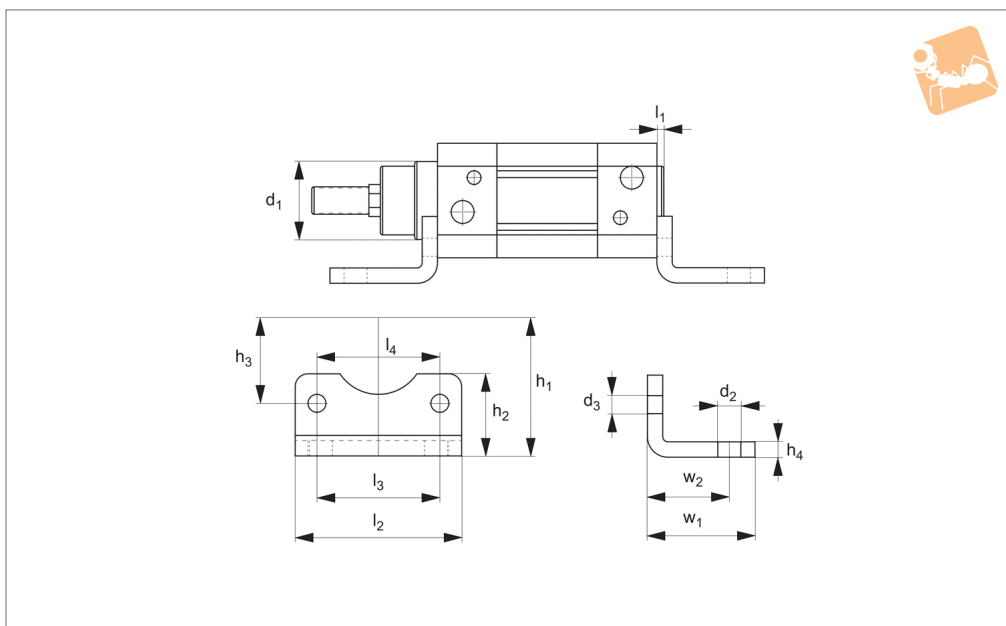

L4806

CYLINDERS

Material

Steel (DIN 1040).

Technical Notes

ISO series

Order No.	Cylinder dia.	d ₁	d ₂	d ₃	l ₁	l ₂	l ₃	l ₄	w ₁	w ₂	h ₁	h ₂	h ₃	h ₄
L4806.032	32	30	7	7	4	45	32	32.5	35	24	32	31.0	16.3	4
L4806.040	40	35	9	7	4	52	36	38.0	36	28	36	31.5	19.0	4
L4806.050	50	40	9	9	4	65	45	46.5	47	32	45	37.0	23.3	5
L4806.063	63	45	9	9	4	75	50	56.5	45	32	50	36.0	28.3	5
L4806.080	80	45	12	1	5	95	63	72.0	53	41	63	47.8	36.0	6
L4806.100	100	55	14	1	6	115	75	89.0	56	41	71	53.0	44.5	6
L4806.125	125	60	16	13	7	139	90	110.0	70	45	90	80.5	55.0	8
L4806.160	160	65	18	17	8	186	115	140.0	85	60	115	100.0	70.0	10