




# Air Cylinder Mounts - ISO Series

## EBX mounting foot

Cylinders

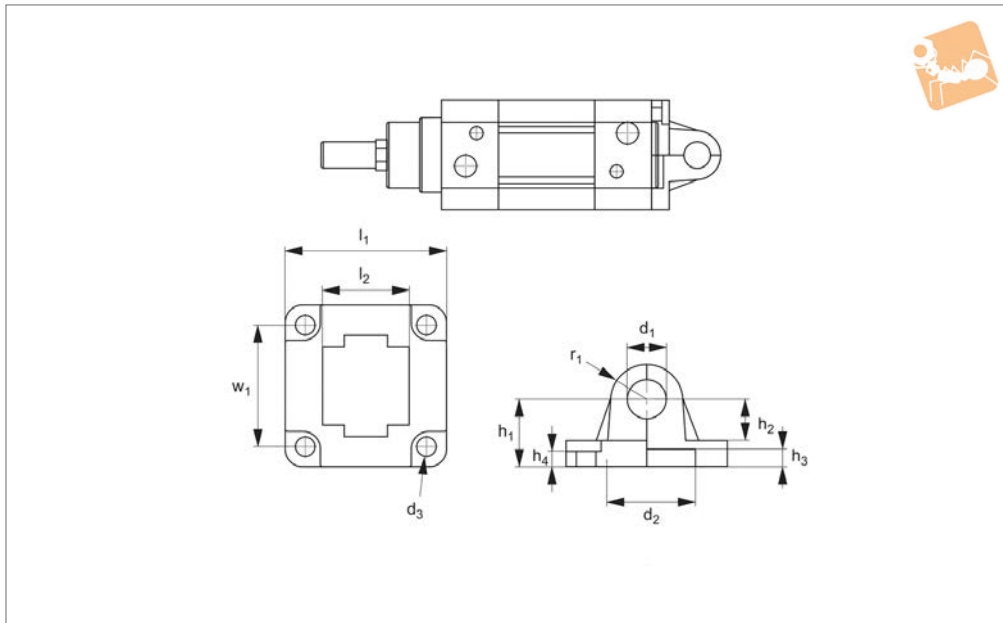

**L4808**

CYLINDERS

### Material

Steel (DIN 1040).

### Technical Notes

ISO series

Order No.	Cylinder dia.	d <sub>1</sub>	d <sub>2</sub>	d <sub>3</sub>	r <sub>1</sub>	l <sub>1</sub>	l <sub>2</sub>	w <sub>1</sub>	h <sub>1</sub>	h <sub>2</sub>	h <sub>3</sub>	h <sub>4</sub>
L4808.032	32	10	30	7	10	45	26	32.5	22	11	4.5	7.0
L4808.040	40	12	35	7	12	52	28	38.0	25	16	4.5	6.0
L4808.050	50	12	40	9	13	64	32	46.5	27	16	4.5	8.0
L4808.063	63	16/18	45	9	16	78	40	56.5	32	20	6.5	6.5
L4808.080	80	16	45	11	16	96	50	72.0	36	22	6.5	10.0
L4808.100	100	20	55	11	20	115	60	89.0	41	27	8.0	10.0
L4808.125	125	25	60	13	25	136	70	110.0	55	30	11.0	13.0