



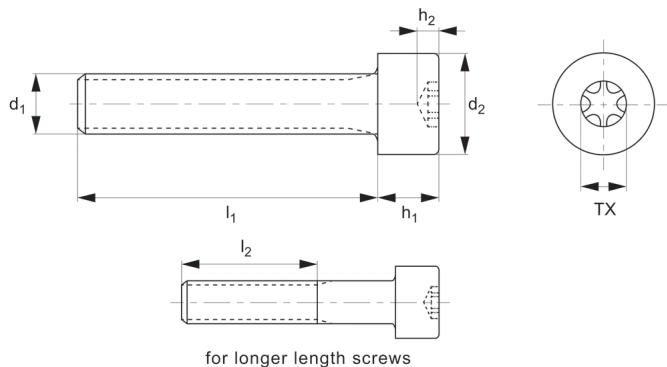

TX Cap Screws- hexalobular drive

A4 stainless

Standard Screws

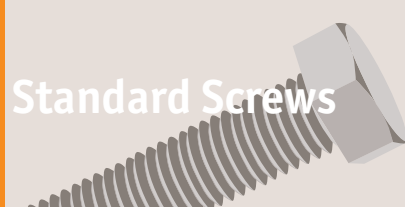

P0202.A4

STANDARD SCREWS

Material

Stainless steel (A4 class 70, class 80 on request).

Technical Notes

To ISO 14579. For the majority of screw

lengths the threads goes all the way to the head of the screw (i.e. $l_1 = l_2$) less 2.5 thread pitches.

For longer length screws the threaded portion $l_2 < l_1$.

Order No.	d_1	l_1	d_2	h_1	h_2	l_2	TX
P0202.020-003-A4	M 2	3	3.8	2.0	1.0	-	TX- 6
P0202.020-004-A4	M 2	4	3.8	2.0	1.0	-	TX- 6
P0202.020-005-A4	M 2	5	3.8	2.0	1.0	-	TX- 6
P0202.020-006-A4	M 2	6	3.8	2.0	1.0	-	TX- 6
P0202.020-008-A4	M 2	8	3.8	2.0	1.0	-	TX- 6
P0202.020-010-A4	M 2	10	3.8	2.0	1.0	-	TX- 6
P0202.020-012-A4	M 2	12	3.8	2.0	1.0	-	TX- 6
P0202.020-014-A4	M 2	14	3.8	2.0	1.0	-	TX- 6
P0202.020-016-A4	M 2	16	3.8	2.0	1.0	-	TX- 6
P0202.020-018-A4	M 2	18	3.8	2.0	1.0	16	TX- 6
P0202.020-020-A4	M 2	20	3.8	2.0	1.0	16	TX- 6
P0202.025-003-A4	M2,5	3	4.5	2.5	1.1	-	TX- 8
P0202.025-004-A4	M2,5	4	4.5	2.5	1.1	-	TX- 8
P0202.025-005-A4	M2,5	5	4.5	2.5	1.1	-	TX- 8
P0202.025-006-A4	M2,5	6	4.5	2.5	1.1	-	TX- 8
P0202.025-008-A4	M2,5	8	4.5	2.5	1.1	-	TX- 8
P0202.025-010-A4	M2,5	10	4.5	2.5	1.1	-	TX- 8
P0202.025-012-A4	M2,5	12	4.5	2.5	1.1	-	TX- 8
P0202.025-014-A4	M2,5	14	4.5	2.5	1.1	-	TX- 8
P0202.025-016-A4	M2,5	16	4.5	2.5	1.1	-	TX- 8
P0202.025-018-A4	M2,5	18	4.5	2.5	1.1	17	TX- 8
P0202.025-020-A4	M2,5	20	4.5	2.5	1.1	17	TX- 8
P0202.030-004-A4	M 3	4	5.5	3	1.3	-	TX- 10
P0202.030-005-A4	M 3	5	5.5	3	1.3	-	TX- 10
P0202.030-006-A4	M 3	6	5.5	3	1.3	-	TX- 10
P0202.030-008-A4	M 3	8	5.5	3	1.3	-	TX- 10
P0202.030-010-A4	M 3	10	5.5	3	1.3	-	TX- 10
P0202.030-012-A4	M 3	12	5.5	3	1.3	-	TX- 10
P0202.030-014-A4	M 3	14	5.5	3	1.3	-	TX- 10
P0202.030-016-A4	M 3	16	5.5	3	1.3	-	TX- 10
P0202.030-018-A4	M 3	18	5.5	3	1.3	-	TX- 10
P0202.030-020-A4	M 3	20	5.5	3	1.3	18	TX- 10
P0202.030-022-A4	M 3	22	5.5	3	1.3	18	TX- 10



Automotion
AN ESSENTIA COMPANY

0333 207 4498

sales@automotioncomponents.co.uk



Order No.	d ₁	l ₁	d ₂	h ₁	h ₂	l ₂	TX
P0202.030-025-A4	M 3	25	5.5	3	1.3	18	TX- 10
P0202.030-030-A4	M 3	30	5.5	3	1.3	18	TX- 10
P0202.040-005-A4	M 4	5	7.0	4	2.0	-	TX- 20
P0202.040-006-A4	M 4	6	7.0	4	2.0	-	TX- 20
P0202.040-008-A4	M 4	8	7.0	4	2.0	-	TX- 20
P0202.040-010-A4	M 4	10	7.0	4	2.0	-	TX- 20
P0202.040-012-A4	M 4	12	7.0	4	2.0	-	TX- 20
P0202.040-014-A4	M 4	14	7.0	4	2.0	-	TX- 20
P0202.040-016-A4	M 4	16	7.0	4	2.0	-	TX- 20
P0202.040-018-A4	M 4	18	7.0	4	2.0	-	TX- 20
P0202.040-020-A4	M 4	20	7.0	4	2.0	-	TX- 20
P0202.040-022-A4	M 4	22	7.0	4	2.0	20	TX- 20
P0202.040-025-A4	M 4	25	7.0	4	2.0	20	TX- 20
P0202.040-030-A4	M 4	30	7.0	4	2.0	20	TX- 20
P0202.040-035-A4	M 4	35	7.0	4	2.0	20	TX- 20
P0202.040-040-A4	M 4	40	7.0	4	2.0	20	TX- 20
P0202.040-045-A4	M 4	45	7.0	4	2.0	20	TX- 20
P0202.040-050-A4	M 4	50	7.0	4	2.0	20	TX- 20
P0202.040-060-A4	M 4	60	7.0	4	2.0	20	TX- 20
P0202.050-006-A4	M 5	6	8.5	5	2.5	-	TX- 25
P0202.050-008-A4	M 5	8	8.5	5	2.5	-	TX- 25
P0202.050-010-A4	M 5	10	8.5	5	2.5	-	TX- 25
P0202.050-012-A4	M 5	12	8.5	5	2.5	-	TX- 25
P0202.050-014-A4	M 5	30	8.5	5	2.5	-	TX- 25
P0202.050-016-A4	M 5	35	8.5	5	2.5	-	TX- 25
P0202.050-018-A4	M 5	40	8.5	5	2.5	-	TX- 25
P0202.050-020-A4	M 5	45	8.5	5	2.5	-	TX- 25
P0202.050-022-A4	M 5	50	8.5	5	2.5	-	TX- 25
P0202.050-025-A4	M 5	60	8.5	5	2.5	22	TX- 25
P0202.050-030-A4	M 5	30	8.5	5	2.5	22	TX- 25
P0202.050-035-A4	M 5	35	8.5	5	2.5	22	TX- 25
P0202.050-040-A4	M 5	40	8.5	5	2.5	22	TX- 25
P0202.050-045-A4	M 5	45	8.5	5	2.5	22	TX- 25
P0202.050-050-A4	M 5	50	8.5	5	2.5	22	TX- 25
P0202.050-060-A4	M 5	60	8.5	5	2.5	22	TX- 25
P0202.060-006-A4	M 6	6	10	6	3.0	-	TX- 30
P0202.060-008-A4	M 6	8	10	6	3.0	-	TX- 30
P0202.060-010-A4	M 6	10	10	6	3.0	-	TX- 30
P0202.060-012-A4	M 6	12	10	6	3.0	-	TX- 30
P0202.060-014-A4	M 6	30	10	6	3.0	-	TX- 30
P0202.060-016-A4	M 6	35	10	6	3.0	-	TX- 30
P0202.060-018-A4	M 6	40	10	6	3.0	-	TX- 30
P0202.060-020-A4	M 6	45	10	6	3.0	-	TX- 30
P0202.060-022-A4	M 6	50	10	6	3.0	-	TX- 30
P0202.060-025-A4	M 6	60	10	6	3.0	24	TX- 30
P0202.060-030-A4	M 6	30	10	6	3.0	24	TX- 30
P0202.060-035-A4	M 6	35	10	6	3.0	24	TX- 30
P0202.060-040-A4	M 6	40	10	6	3.0	24	TX- 30
P0202.060-045-A4	M 6	45	10	6	3.0	24	TX- 30
P0202.060-050-A4	M 6	50	10	6	3.0	24	TX- 30
P0202.060-060-A4	M 6	60	10	6	3.0	24	TX- 30
P0202.080-016-A4	M 8	16	13	8	4.0	-	TX- 45
P0202.080-018-A4	M 8	18	13	8	4.0	-	TX- 45
P0202.080-020-A4	M 8	20	13	8	4.0	-	TX- 45
P0202.080-022-A4	M 8	22	13	8	4.0	-	TX- 45
P0202.080-025-A4	M 8	25	13	8	4.0	-	TX- 45
P0202.080-030-A4	M 8	30	13	8	4.0	28	TX- 45
P0202.080-035-A4	M 8	35	13	8	4.0	28	TX- 45
P0202.080-040-A4	M 8	40	13	8	4.0	28	TX- 45
P0202.080-045-A4	M 8	45	13	8	4.0	28	TX- 45
P0202.080-050-A4	M 8	50	13	8	4.0	28	TX- 45
P0202.080-060-A4	M 8	60	13	8	4.0	28	TX- 45