



# Socket Button Screws


## A2 stainless

Standard Screws



**P0210.A2**

STANDARD SCREWS

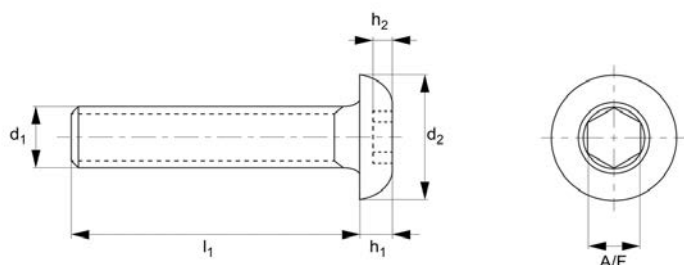

### Material

Stainless steel A2.


head.

### Technical Notes

To ISO 7380. Threaded within 2,5 x pitch of

See technical page for tightening torques.

| Order No.        | d <sub>1</sub> | l <sub>1</sub> | d <sub>2</sub> | h <sub>1</sub> | h <sub>2</sub> | A/F |
|------------------|----------------|----------------|----------------|----------------|----------------|-----|
| P0210.030-004-A2 | M 3            | 4              | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-005-A2 | M 3            | 5              | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-006-A2 | M 3            | 6              | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-008-A2 | M 3            | 8              | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-010-A2 | M 3            | 10             | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-012-A2 | M 3            | 12             | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-014-A2 | M 3            | 14             | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-016-A2 | M 3            | 16             | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-020-A2 | M 3            | 20             | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-025-A2 | M 3            | 25             | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-030-A2 | M 3            | 30             | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-035-A2 | M 3            | 35             | 5.7            | 1.65           | 1.04           | 2   |
| P0210.030-040-A2 | M 3            | 40             | 5.7            | 1.65           | 1.04           | 2   |
| P0210.040-004-A2 | M 4            | 4              | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-005-A2 | M 4            | 5              | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-006-A2 | M 4            | 6              | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-008-A2 | M 4            | 8              | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-010-A2 | M 4            | 10             | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-012-A2 | M 4            | 12             | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-014-A2 | M 4            | 14             | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-016-A2 | M 4            | 16             | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-020-A2 | M 4            | 20             | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-025-A2 | M 4            | 25             | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-030-A2 | M 4            | 30             | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-035-A2 | M 4            | 35             | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-040-A2 | M 4            | 40             | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-045-A2 | M 4            | 45             | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.040-050-A2 | M 4            | 50             | 7.6            | 2.2            | 1.3            | 2.5 |
| P0210.050-006-A2 | M 5            | 6              | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-008-A2 | M 5            | 8              | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-010-A2 | M 5            | 10             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-012-A2 | M 5            | 12             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-014-A2 | M 5            | 14             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-016-A2 | M 5            | 16             | 9.5            | 2.75           | 1.56           | 3   |

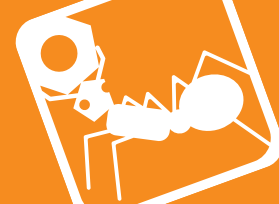

| Order No.        | d <sub>1</sub> | l <sub>1</sub> | d <sub>2</sub> | h <sub>1</sub> | h <sub>2</sub> | A/F |
|------------------|----------------|----------------|----------------|----------------|----------------|-----|
| P0210.050-020-A2 | M 5            | 20             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-025-A2 | M 5            | 25             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-030-A2 | M 5            | 30             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-035-A2 | M 5            | 35             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-040-A2 | M 5            | 40             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-045-A2 | M 5            | 45             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-050-A2 | M 5            | 50             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-055-A2 | M 5            | 55             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.050-060-A2 | M 5            | 60             | 9.5            | 2.75           | 1.56           | 3   |
| P0210.060-008-A2 | M 6            | 8              | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-010-A2 | M 6            | 10             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-012-A2 | M 6            | 12             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-014-A2 | M 6            | 14             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-016-A2 | M 6            | 16             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-020-A2 | M 6            | 20             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-025-A2 | M 6            | 25             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-030-A2 | M 6            | 30             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-035-A2 | M 6            | 35             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-040-A2 | M 6            | 40             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-045-A2 | M 6            | 45             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-050-A2 | M 6            | 50             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-055-A2 | M 6            | 55             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-060-A2 | M 6            | 60             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-070-A2 | M 6            | 70             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.060-080-A2 | M 6            | 80             | 10.5           | 3.3            | 2.08           | 4   |
| P0210.080-010-A2 | M 8            | 10             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-012-A2 | M 8            | 12             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-014-A2 | M 8            | 14             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-016-A2 | M 8            | 16             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-020-A2 | M 8            | 20             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-025-A2 | M 8            | 25             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-030-A2 | M 8            | 30             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-035-A2 | M 8            | 35             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-040-A2 | M 8            | 40             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-045-A2 | M 8            | 45             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-050-A2 | M 8            | 50             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-055-A2 | M 8            | 55             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-060-A2 | M 8            | 60             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-070-A2 | M 8            | 70             | 14             | 4.4            | 2.6            | 5   |
| P0210.080-080-A2 | M 8            | 80             | 14             | 4.4            | 2.6            | 5   |
| P0210.100-012-A2 | M10            | 12             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-016-A2 | M10            | 16             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-020-A2 | M10            | 20             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-025-A2 | M10            | 25             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-030-A2 | M10            | 30             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-035-A2 | M10            | 35             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-040-A2 | M10            | 40             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-045-A2 | M10            | 45             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-050-A2 | M10            | 50             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-055-A2 | M10            | 55             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-060-A2 | M10            | 60             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-070-A2 | M10            | 70             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.100-080-A2 | M10            | 80             | 17.5           | 5.5            | 3.12           | 6   |
| P0210.120-020-A2 | M12            | 20             | 21             | 6.6            | 4.16           | 8   |
| P0210.120-025-A2 | M12            | 25             | 21             | 6.6            | 4.16           | 8   |
| P0210.120-030-A2 | M12            | 30             | 21             | 6.6            | 4.16           | 8   |
| P0210.120-035-A2 | M12            | 35             | 21             | 6.6            | 4.16           | 8   |
| P0210.120-040-A2 | M12            | 40             | 21             | 6.6            | 4.16           | 8   |
| P0210.120-045-A2 | M12            | 45             | 21             | 6.6            | 4.16           | 8   |
| P0210.120-050-A2 | M12            | 50             | 21             | 6.6            | 4.16           | 8   |
| P0210.120-055-A2 | M12            | 55             | 21             | 6.6            | 4.16           | 8   |
| P0210.120-060-A2 | M12            | 60             | 21             | 6.6            | 4.16           | 8   |
| P0210.120-070-A2 | M12            | 70             | 21             | 6.6            | 4.16           | 8   |
| P0210.120-080-A2 | M12            | 80             | 21             | 6.6            | 4.16           | 8   |