




# Slot Pan Head Screws

Slot - A2 stainless

Standard Screws

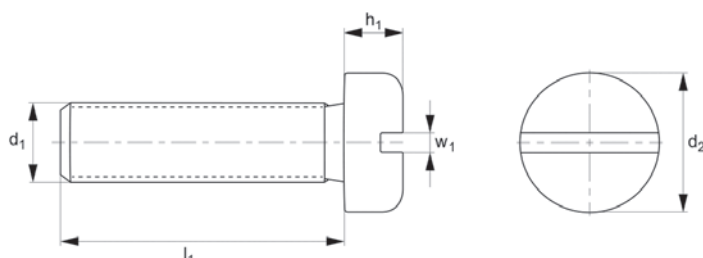

P0230.A2

STANDARD SCREWS

## Material

Stainless steel (A2).

pitch of head.


## Technical Notes

To DIN 85, ISO 1580. Threaded within 2,5 x

See technical page for tightening torques.

| Order No.        | d <sub>1</sub> | l <sub>1</sub> | d <sub>2</sub> | h <sub>1</sub> | w <sub>1</sub> |
|------------------|----------------|----------------|----------------|----------------|----------------|
| P0230.016-005-A2 | M1,6           | 5              | 3.2            | 1.0            | 0.4            |
| P0230.016-006-A2 | M1,6           | 6              | 3.2            | 1.0            | 0.4            |
| P0230.016-008-A2 | M1,6           | 8              | 3.2            | 1.0            | 0.4            |
| P0230.016-010-A2 | M1,6           | 10             | 3.2            | 1.0            | 0.4            |
| P0230.020-003-A2 | M 2            | 3              | 4              | 1.3            | 0.5            |
| P0230.020-004-A2 | M 2            | 4              | 4              | 1.3            | 0.5            |
| P0230.020-005-A2 | M 2            | 5              | 4              | 1.3            | 0.5            |
| P0230.020-006-A2 | M 2            | 6              | 4              | 1.3            | 0.5            |
| P0230.020-008-A2 | M 2            | 8              | 4              | 1.3            | 0.5            |
| P0230.020-010-A2 | M 2            | 10             | 4              | 1.3            | 0.5            |
| P0230.020-012-A2 | M 2            | 12             | 4              | 1.3            | 0.5            |
| P0230.020-016-A2 | M 2            | 16             | 4              | 1.3            | 0.5            |
| P0230.020-020-A2 | M 2            | 20             | 4              | 1.3            | 0.5            |
| P0230.025-003-A2 | M2,5           | 3              | 5              | 1.5            | 0.6            |
| P0230.025-004-A2 | M2,5           | 4              | 5              | 1.5            | 0.6            |
| P0230.025-005-A2 | M2,5           | 5              | 5              | 1.5            | 0.6            |
| P0230.025-006-A2 | M2,5           | 6              | 5              | 1.5            | 0.6            |
| P0230.025-008-A2 | M2,5           | 8              | 5              | 1.5            | 0.6            |
| P0230.025-010-A2 | M2,5           | 10             | 5              | 1.5            | 0.6            |
| P0230.025-012-A2 | M2,5           | 12             | 5              | 1.5            | 0.6            |
| P0230.025-016-A2 | M2,5           | 16             | 5              | 1.5            | 0.6            |
| P0230.025-020-A2 | M2,5           | 20             | 5              | 1.5            | 0.6            |
| P0230.025-025-A2 | M2,5           | 25             | 5              | 1.5            | 0.6            |
| P0230.030-003-A2 | M 3            | 3              | 6              | 1.8            | 0.8            |
| P0230.030-004-A2 | M 3            | 4              | 6              | 1.8            | 0.8            |
| P0230.030-005-A2 | M 3            | 5              | 6              | 1.8            | 0.8            |
| P0230.030-006-A2 | M 3            | 6              | 6              | 1.8            | 0.8            |
| P0230.030-008-A2 | M 3            | 8              | 6              | 1.8            | 0.8            |
| P0230.030-010-A2 | M 3            | 10             | 6              | 1.8            | 0.8            |
| P0230.030-012-A2 | M 3            | 12             | 6              | 1.8            | 0.8            |
| P0230.030-014-A2 | M 3            | 14             | 6              | 1.8            | 0.8            |
| P0230.030-016-A2 | M 3            | 16             | 6              | 1.8            | 0.8            |
| P0230.030-018-A2 | M 3            | 18             | 6              | 1.8            | 0.8            |
| P0230.030-020-A2 | M 3            | 20             | 6              | 1.8            | 0.8            |



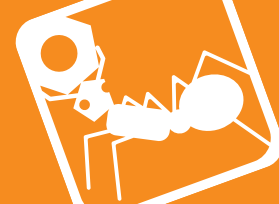

| Order No.        | d <sub>1</sub> | l <sub>1</sub> | d <sub>2</sub> | h <sub>1</sub> | w <sub>1</sub> |
|------------------|----------------|----------------|----------------|----------------|----------------|
| P0230.030-022-A2 | M 3            | 22             | 6              | 1.8            | 0.8            |
| P0230.030-025-A2 | M 3            | 25             | 6              | 1.8            | 0.8            |
| P0230.030-028-A2 | M 3            | 28             | 6              | 1.8            | 0.8            |
| P0230.030-030-A2 | M 3            | 30             | 6              | 1.8            | 0.8            |
| P0230.030-035-A2 | M 3            | 35             | 6              | 1.8            | 0.8            |
| P0230.030-040-A2 | M 3            | 40             | 6              | 1.8            | 0.8            |
| P0230.030-045-A2 | M 3            | 45             | 6              | 1.8            | 0.8            |
| P0230.030-050-A2 | M 3            | 50             | 6              | 1.8            | 0.8            |
| P0230.035-005-A2 | M3,5           | 5              | 7              | 2.1            | 1.0            |
| P0230.035-006-A2 | M3,5           | 6              | 7              | 2.1            | 1.0            |
| P0230.035-008-A2 | M3,5           | 8              | 7              | 2.1            | 1.0            |
| P0230.035-010-A2 | M3,5           | 10             | 7              | 2.1            | 1.0            |
| P0230.035-012-A2 | M3,5           | 12             | 7              | 2.1            | 1.0            |
| P0230.035-016-A2 | M3,5           | 16             | 7              | 2.1            | 1.0            |
| P0230.035-020-A2 | M3,5           | 20             | 7              | 2.1            | 1.0            |
| P0230.035-025-A2 | M3,5           | 25             | 7              | 2.1            | 1.0            |
| P0230.035-030-A2 | M3,5           | 30             | 7              | 2.1            | 1.0            |
| P0230.035-035-A2 | M3,5           | 35             | 7              | 2.1            | 1.0            |
| P0230.035-040-A2 | M3,5           | 40             | 7              | 2.1            | 1.0            |
| P0230.035-050-A2 | M3,5           | 50             | 7              | 2.1            | 1.0            |
| P0230.040-005-A2 | M 4            | 5              | 8              | 2.4            | 1.2            |
| P0230.040-006-A2 | M 4            | 6              | 8              | 2.4            | 1.2            |
| P0230.040-008-A2 | M 4            | 8              | 8              | 2.4            | 1.2            |
| P0230.040-010-A2 | M 4            | 10             | 8              | 2.4            | 1.2            |
| P0230.040-012-A2 | M 4            | 12             | 8              | 2.4            | 1.2            |
| P0230.040-014-A2 | M 4            | 14             | 8              | 2.4            | 1.2            |
| P0230.040-016-A2 | M 4            | 16             | 8              | 2.4            | 1.2            |
| P0230.040-018-A2 | M 4            | 18             | 8              | 2.4            | 1.2            |
| P0230.040-020-A2 | M 4            | 20             | 8              | 2.4            | 1.2            |
| P0230.040-022-A2 | M 4            | 22             | 8              | 2.4            | 1.2            |
| P0230.040-025-A2 | M 4            | 25             | 8              | 2.4            | 1.2            |
| P0230.040-028-A2 | M 4            | 28             | 8              | 2.4            | 1.2            |
| P0230.040-030-A2 | M 4            | 30             | 8              | 2.4            | 1.2            |
| P0230.040-035-A2 | M 4            | 35             | 8              | 2.4            | 1.2            |
| P0230.040-040-A2 | M 4            | 40             | 8              | 2.4            | 1.2            |
| P0230.040-045-A2 | M 4            | 45             | 8              | 2.4            | 1.2            |
| P0230.040-050-A2 | M 4            | 50             | 8              | 2.4            | 1.2            |
| P0230.040-055-A2 | M 4            | 55             | 8              | 2.4            | 1.2            |
| P0230.040-060-A2 | M 4            | 60             | 8              | 2.4            | 1.2            |
| P0230.050-006-A2 | M 5            | 6              | 10             | 3.0            | 1.2            |
| P0230.050-008-A2 | M 5            | 8              | 10             | 3.0            | 1.2            |
| P0230.050-010-A2 | M 5            | 10             | 10             | 3.0            | 1.2            |
| P0230.050-012-A2 | M 5            | 12             | 10             | 3.0            | 1.2            |
| P0230.050-014-A2 | M 5            | 14             | 10             | 3.0            | 1.2            |
| P0230.050-016-A2 | M 5            | 16             | 10             | 3.0            | 1.2            |
| P0230.050-018-A2 | M 5            | 18             | 10             | 3.0            | 1.2            |
| P0230.050-020-A2 | M 5            | 20             | 10             | 3.0            | 1.2            |
| P0230.050-022-A2 | M 5            | 22             | 10             | 3.0            | 1.2            |
| P0230.050-025-A2 | M 5            | 25             | 10             | 3.0            | 1.2            |
| P0230.050-030-A2 | M 5            | 30             | 10             | 3.0            | 1.2            |
| P0230.050-035-A2 | M 5            | 35             | 10             | 3.0            | 1.2            |
| P0230.050-040-A2 | M 5            | 40             | 10             | 3.0            | 1.2            |
| P0230.050-045-A2 | M 5            | 45             | 10             | 3.0            | 1.2            |
| P0230.050-050-A2 | M 5            | 50             | 10             | 3.0            | 1.2            |
| P0230.050-055-A2 | M 5            | 55             | 10             | 3.0            | 1.2            |
| P0230.050-060-A2 | M 5            | 60             | 10             | 3.0            | 1.2            |
| P0230.050-065-A2 | M 5            | 65             | 10             | 3.0            | 1.2            |
| P0230.050-070-A2 | M 5            | 70             | 10             | 3.0            | 1.2            |
| P0230.050-075-A2 | M 5            | 75             | 10             | 3.0            | 1.2            |
| P0230.050-080-A2 | M 5            | 80             | 10             | 3.0            | 1.2            |
| P0230.050-090-A2 | M 5            | 90             | 10             | 3.0            | 1.2            |
| P0230.050-100-A2 | M 5            | 100            | 10             | 3.0            | 1.2            |
| P0230.060-008-A2 | M 6            | 8              | 12             | 3.6            | 1.6            |
| P0230.060-010-A2 | M 6            | 10             | 12             | 3.6            | 1.6            |
| P0230.060-012-A2 | M 6            | 12             | 12             | 3.6            | 1.6            |
| P0230.060-014-A2 | M 6            | 14             | 12             | 3.6            | 1.6            |
| P0230.060-016-A2 | M 6            | 16             | 12             | 3.6            | 1.6            |
| P0230.060-018-A2 | M 6            | 18             | 12             | 3.6            | 1.6            |
| P0230.060-020-A2 | M 6            | 20             | 12             | 3.6            | 1.6            |



# Slot Pan Head Screws

Slot - A2 stainless

Standard Screws



| Order No.        | d <sub>1</sub> | l <sub>1</sub> | d <sub>2</sub> | h <sub>1</sub> | w <sub>1</sub> |
|------------------|----------------|----------------|----------------|----------------|----------------|
| P0230.060-022-A2 | M 6            | 22             | 12             | 3.6            | 1.6            |
| P0230.060-025-A2 | M 6            | 25             | 12             | 3.6            | 1.6            |
| P0230.060-028-A2 | M 6            | 28             | 12             | 3.6            | 1.6            |
| P0230.060-030-A2 | M 6            | 30             | 12             | 3.6            | 1.6            |
| P0230.060-035-A2 | M 6            | 35             | 12             | 3.6            | 1.6            |
| P0230.060-040-A2 | M 6            | 40             | 12             | 3.6            | 1.6            |
| P0230.060-045-A2 | M 6            | 45             | 12             | 3.6            | 1.6            |
| P0230.060-050-A2 | M 6            | 50             | 12             | 3.6            | 1.6            |
| P0230.060-055-A2 | M 6            | 55             | 12             | 3.6            | 1.6            |
| P0230.060-060-A2 | M 6            | 60             | 12             | 3.6            | 1.6            |
| P0230.060-065-A2 | M 6            | 65             | 12             | 3.6            | 1.6            |
| P0230.060-070-A2 | M 6            | 70             | 12             | 3.6            | 1.6            |
| P0230.060-075-A2 | M 6            | 75             | 12             | 3.6            | 1.6            |
| P0230.060-080-A2 | M 6            | 80             | 12             | 3.6            | 1.6            |
| P0230.060-090-A2 | M 6            | 90             | 12             | 3.6            | 1.6            |
| P0230.060-100-A2 | M 6            | 100            | 12             | 3.6            | 1.6            |
| P0230.080-008-A2 | M 8            | 8              | 16             | 4.8            | 2.0            |
| P0230.080-010-A2 | M 8            | 10             | 16             | 4.8            | 2.0            |
| P0230.080-012-A2 | M 8            | 12             | 16             | 4.8            | 2.0            |
| P0230.080-016-A2 | M 8            | 16             | 16             | 4.8            | 2.0            |
| P0230.080-020-A2 | M 8            | 20             | 16             | 4.8            | 2.0            |
| P0230.080-025-A2 | M 8            | 25             | 16             | 4.8            | 2.0            |
| P0230.080-030-A2 | M 8            | 30             | 16             | 4.8            | 2.0            |
| P0230.080-035-A2 | M 8            | 35             | 16             | 4.8            | 2.0            |
| P0230.080-040-A2 | M 8            | 40             | 16             | 4.8            | 2.0            |
| P0230.080-045-A2 | M 8            | 45             | 16             | 4.8            | 2.0            |
| P0230.080-050-A2 | M 8            | 50             | 16             | 4.8            | 2.0            |
| P0230.080-055-A2 | M 8            | 55             | 16             | 4.8            | 2.0            |
| P0230.080-060-A2 | M 8            | 60             | 16             | 4.8            | 2.0            |
| P0230.080-065-A2 | M 8            | 65             | 16             | 4.8            | 2.0            |
| P0230.080-070-A2 | M 8            | 70             | 16             | 4.8            | 2.0            |
| P0230.080-075-A2 | M 8            | 75             | 16             | 4.8            | 2.0            |
| P0230.080-080-A2 | M 8            | 80             | 16             | 4.8            | 2.0            |
| P0230.080-090-A2 | M 8            | 90             | 16             | 4.8            | 2.0            |
| P0230.080-100-A2 | M 8            | 100            | 16             | 4.8            | 2.0            |
| P0230.100-016-A2 | M10            | 16             | 20             | 6              | 2.5            |
| P0230.100-020-A2 | M10            | 20             | 20             | 6              | 2.5            |
| P0230.100-025-A2 | M10            | 25             | 20             | 6              | 2.5            |
| P0230.100-030-A2 | M10            | 30             | 20             | 6              | 2.5            |
| P0230.100-035-A2 | M10            | 35             | 20             | 6              | 2.5            |
| P0230.100-040-A2 | M10            | 40             | 20             | 6              | 2.5            |
| P0230.100-045-A2 | M10            | 45             | 20             | 6              | 2.5            |
| P0230.100-050-A2 | M10            | 50             | 20             | 6              | 2.5            |
| P0230.100-055-A2 | M10            | 55             | 20             | 6              | 2.5            |
| P0230.100-060-A2 | M10            | 60             | 20             | 6              | 2.5            |
| P0230.100-065-A2 | M10            | 65             | 20             | 6              | 2.5            |
| P0230.100-070-A2 | M10            | 70             | 20             | 6              | 2.5            |
| P0230.100-080-A2 | M10            | 80             | 20             | 6              | 2.5            |
| P0230.100-090-A2 | M10            | 90             | 20             | 6              | 2.5            |
| P0230.100-100-A2 | M10            | 100            | 20             | 6              | 2.5            |

STANDARD SCREWS