



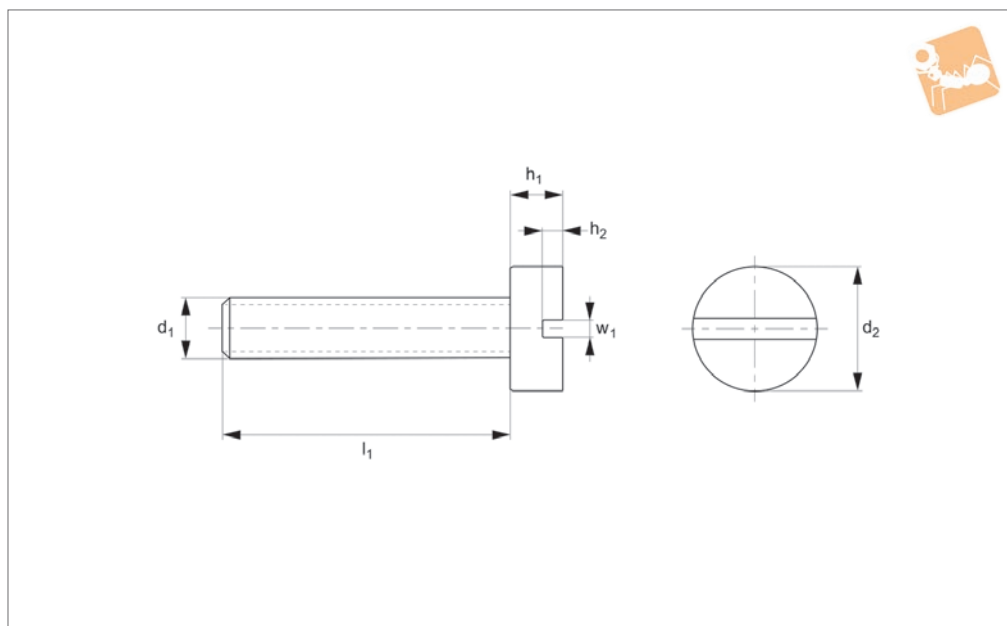

# Slot Cheese Head Screws

## Slot - A2 stainless

Standard Screws

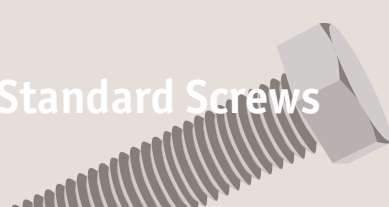

**P0239.A2**

STANDARD SCREWS

### Material

Stainless steel (A2).

See technical page for tightening torques.

### Technical Notes

To DIN 84.


| Order No.        | d <sub>1</sub> | l <sub>1</sub> | w <sub>1</sub> | h <sub>1</sub> | h <sub>2</sub> | d <sub>2</sub> | Material |
|------------------|----------------|----------------|----------------|----------------|----------------|----------------|----------|
| P0239.016-003-A2 | M1,6           | 3              | 0.40           | 1.0            | 0.45           | 3.0            | A2 s/s   |
| P0239.016-004-A2 | M1,6           | 4              | 0.40           | 1.0            | 0.45           | 3.0            | A2 s/s   |
| P0239.016-005-A2 | M1,6           | 5              | 0.40           | 1.0            | 0.45           | 3.0            | A2 s/s   |
| P0239.016-006-A2 | M1,6           | 6              | 0.40           | 1.0            | 0.45           | 3.0            | A2 s/s   |
| P0239.016-008-A2 | M1,6           | 8              | 0.40           | 1.0            | 0.45           | 3.0            | A2 s/s   |
| P0239.016-010-A2 | M1,6           | 10             | 0.40           | 1.0            | 0.45           | 3.0            | A2 s/s   |
| P0239.016-012-A2 | M1,6           | 12             | 0.40           | 1.0            | 0.45           | 3.0            | A2 s/s   |
| P0239.016-014-A2 | M1,6           | 14             | 0.40           | 1.0            | 0.45           | 3.0            | A2 s/s   |
| P0239.016-016-A2 | M1,6           | 16             | 0.40           | 1.0            | 0.45           | 3.0            | A2 s/s   |
| P0239.016-018-A2 | M1,6           | 18             | 0.40           | 1.0            | 0.45           | 3.0            | A2 s/s   |
| P0239.020-003-A2 | M 2            | 3              | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-004-A2 | M 2            | 4              | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-005-A2 | M 2            | 5              | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-006-A2 | M 2            | 6              | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-008-A2 | M 2            | 8              | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-010-A2 | M 2            | 10             | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-012-A2 | M 2            | 12             | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-014-A2 | M 2            | 14             | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-016-A2 | M 2            | 16             | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-018-A2 | M 2            | 18             | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-020-A2 | M 2            | 20             | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-022-A2 | M 2            | 22             | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-025-A2 | M 2            | 25             | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-028-A2 | M 2            | 28             | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.020-030-A2 | M 2            | 30             | 0.50           | 1.3            | 0.60           | 3.8            | A2 s/s   |
| P0239.025-003-A2 | M2,5           | 3              | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-004-A2 | M2,5           | 4              | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-005-A2 | M2,5           | 5              | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-006-A2 | M2,5           | 6              | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-008-A2 | M2,5           | 8              | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-010-A2 | M2,5           | 10             | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-012-A2 | M2,5           | 12             | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-014-A2 | M2,5           | 14             | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-016-A2 | M2,5           | 16             | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |



**Automotion**  
AN ESSENTIA COMPANY

0333 207 4498

[sales@automotioncomponents.co.uk](mailto:sales@automotioncomponents.co.uk)

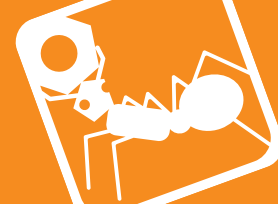

| Order No.        | d <sub>1</sub> | l <sub>1</sub> | w <sub>1</sub> | h <sub>1</sub> | h <sub>2</sub> | d <sub>2</sub> | Material |
|------------------|----------------|----------------|----------------|----------------|----------------|----------------|----------|
| P0239.025-018-A2 | M2,5           | 18             | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-020-A2 | M2,5           | 20             | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-022-A2 | M2,5           | 22             | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-025-A2 | M2,5           | 25             | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-028-A2 | M2,5           | 28             | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.025-030-A2 | M2,5           | 30             | 0.60           | 1.6            | 0.70           | 4.5            | A2 s/s   |
| P0239.030-003-A2 | M 3            | 3              | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-004-A2 | M 3            | 4              | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-005-A2 | M 3            | 5              | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-006-A2 | M 3            | 6              | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-008-A2 | M 3            | 8              | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-010-A2 | M 3            | 10             | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-012-A2 | M 3            | 12             | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-014-A2 | M 3            | 14             | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-016-A2 | M 3            | 16             | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-018-A2 | M 3            | 18             | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-020-A2 | M 3            | 20             | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-022-A2 | M 3            | 22             | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-025-A2 | M 3            | 25             | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-028-A2 | M 3            | 28             | 0.80           | 2.0            | 0.85           | 5.5            | Steel    |
| P0239.030-030-A2 | M 3            | 30             | 0.80           | 2.0            | 0.85           | 5.5            | A2 s/s   |
| P0239.030-035-A2 | M 3            | 35             | 0.80           | 2.0            | 0.85           | 5.5            | A2 s/s   |
| P0239.030-040-A2 | M 3            | 40             | 0.80           | 2.0            | 0.85           | 5.5            | A2 s/s   |
| P0239.030-045-A2 | M 3            | 45             | 0.80           | 2.0            | 0.85           | 5.5            | A2 s/s   |
| P0239.030-050-A2 | M 3            | 50             | 0.80           | 2.0            | 0.85           | 5.5            | A2 s/s   |
| P0239.030-055-A2 | M 3            | 55             | 0.80           | 2.0            | 0.85           | 5.5            | A2 s/s   |
| P0239.030-060-A2 | M 3            | 60             | 0.80           | 2.0            | 0.85           | 5.5            | A2 s/s   |
| P0239.035-004-A2 | M3,5           | 4              | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-005-A2 | M3,5           | 5              | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-006-A2 | M3,5           | 6              | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-008-A2 | M3,5           | 8              | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-010-A2 | M3,5           | 10             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-012-A2 | M3,5           | 12             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-014-A2 | M3,5           | 14             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-016-A2 | M3,5           | 16             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-018-A2 | M3,5           | 18             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-020-A2 | M3,5           | 20             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-022-A2 | M3,5           | 22             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-025-A2 | M3,5           | 25             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-028-A2 | M3,5           | 28             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-030-A2 | M3,5           | 30             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-035-A2 | M3,5           | 35             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-040-A2 | M3,5           | 40             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-045-A2 | M3,5           | 45             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-050-A2 | M3,5           | 50             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-055-A2 | M3,5           | 55             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.035-060-A2 | M3,5           | 60             | 1.00           | 2.4            | 1.00           | 6.0            | A2 s/s   |
| P0239.040-004-A2 | M 4            | 4              | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-005-A2 | M 4            | 5              | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-006-A2 | M 4            | 6              | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-008-A2 | M 4            | 8              | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-010-A2 | M 4            | 10             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-012-A2 | M 4            | 12             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-014-A2 | M 4            | 14             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-016-A2 | M 4            | 16             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-018-A2 | M 4            | 18             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-020-A2 | M 4            | 20             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-022-A2 | M 4            | 22             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-025-A2 | M 4            | 25             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-028-A2 | M 4            | 28             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-030-A2 | M 4            | 30             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-035-A2 | M 4            | 35             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-040-A2 | M 4            | 40             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-045-A2 | M 4            | 45             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-050-A2 | M 4            | 50             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-055-A2 | M 4            | 55             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-060-A2 | M 4            | 60             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-065-A2 | M 4            | 65             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-070-A2 | M 4            | 70             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |



# Slot Cheese Head Screws


## Slot - A2 stainless

Standard Screws



| Order No.        | d <sub>1</sub> | l <sub>1</sub> | w <sub>1</sub> | h <sub>1</sub> | h <sub>2</sub> | d <sub>2</sub> | Material |
|------------------|----------------|----------------|----------------|----------------|----------------|----------------|----------|
| P0239.040-075-A2 | M 4            | 75             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-080-A2 | M 4            | 80             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-085-A2 | M 4            | 85             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-090-A2 | M 4            | 90             | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.040-100-A2 | M 4            | 100            | 1.20           | 2.6            | 1.10           | 7.0            | A2 s/s   |
| P0239.050-006-A2 | M 5            | 6              | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-008-A2 | M 5            | 8              | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-010-A2 | M 5            | 10             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-012-A2 | M 5            | 12             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-014-A2 | M 5            | 14             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-016-A2 | M 5            | 16             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-018-A2 | M 5            | 18             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-020-A2 | M 5            | 20             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-022-A2 | M 5            | 22             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-025-A2 | M 5            | 25             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-028-A2 | M 5            | 28             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-030-A2 | M 5            | 30             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-035-A2 | M 5            | 35             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-040-A2 | M 5            | 40             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-045-A2 | M 5            | 45             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-050-A2 | M 5            | 50             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-055-A2 | M 5            | 55             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-060-A2 | M 5            | 60             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-065-A2 | M 5            | 65             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-070-A2 | M 5            | 70             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-075-A2 | M 5            | 75             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-080-A2 | M 5            | 80             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-085-A2 | M 5            | 85             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-090-A2 | M 5            | 90             | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.050-100-A2 | M 5            | 100            | 1.20           | 3.3            | 1.30           | 8.5            | A2 s/s   |
| P0239.060-006-A2 | M 6            | 6              | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-008-A2 | M 6            | 8              | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-010-A2 | M 6            | 10             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-012-A2 | M 6            | 12             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-014-A2 | M 6            | 14             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-016-A2 | M 6            | 16             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-018-A2 | M 6            | 18             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-020-A2 | M 6            | 20             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-022-A2 | M 6            | 22             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-025-A2 | M 6            | 25             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-028-A2 | M 6            | 28             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-030-A2 | M 6            | 30             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-035-A2 | M 6            | 35             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-040-A2 | M 6            | 40             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-045-A2 | M 6            | 45             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-050-A2 | M 6            | 50             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-055-A2 | M 6            | 55             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-060-A2 | M 6            | 60             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-065-A2 | M 6            | 65             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-070-A2 | M 6            | 70             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-075-A2 | M 6            | 75             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-080-A2 | M 6            | 80             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-085-A2 | M 6            | 85             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-090-A2 | M 6            | 90             | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.060-100-A2 | M 6            | 100            | 1.60           | 3.9            | 1.60           | 10.0           | A2 s/s   |
| P0239.080-010-A2 | M 8            | 10             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-012-A2 | M 8            | 12             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-014-A2 | M 8            | 14             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-016-A2 | M 8            | 16             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-018-A2 | M 8            | 18             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-020-A2 | M 8            | 20             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-022-A2 | M 8            | 22             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-025-A2 | M 8            | 25             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-028-A2 | M 8            | 28             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-030-A2 | M 8            | 30             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-035-A2 | M 8            | 35             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-040-A2 | M 8            | 40             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-045-A2 | M 8            | 45             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-050-A2 | M 8            | 50             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |

STANDARD SCREWS

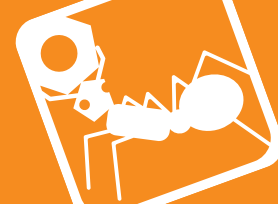

| Order No.        | d <sub>1</sub> | l <sub>1</sub> | w <sub>1</sub> | h <sub>1</sub> | h <sub>2</sub> | d <sub>2</sub> | Material |
|------------------|----------------|----------------|----------------|----------------|----------------|----------------|----------|
| P0239.080-055-A2 | M 8            | 55             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-060-A2 | M 8            | 60             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-065-A2 | M 8            | 65             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-070-A2 | M 8            | 70             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-075-A2 | M 8            | 75             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-080-A2 | M 8            | 80             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-085-A2 | M 8            | 85             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-090-A2 | M 8            | 90             | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.080-100-A2 | M 8            | 100            | 2.00           | 5.0            | 2.00           | 13.0           | A2 s/s   |
| P0239.100-016-A2 | M10            | 16             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-018-A2 | M10            | 18             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-020-A2 | M10            | 20             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-022-A2 | M10            | 22             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-025-A2 | M10            | 25             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-028-A2 | M10            | 28             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-030-A2 | M10            | 30             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-035-A2 | M10            | 35             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-040-A2 | M10            | 40             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-045-A2 | M10            | 45             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-050-A2 | M10            | 50             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-055-A2 | M10            | 55             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-060-A2 | M10            | 60             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-065-A2 | M10            | 65             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-070-A2 | M10            | 70             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-075-A2 | M10            | 75             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-080-A2 | M10            | 80             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-085-A2 | M10            | 85             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-090-A2 | M10            | 90             | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |
| P0239.100-100-A2 | M10            | 100            | 2.50           | 6.0            | 2.40           | 16.0           | A2 s/s   |