



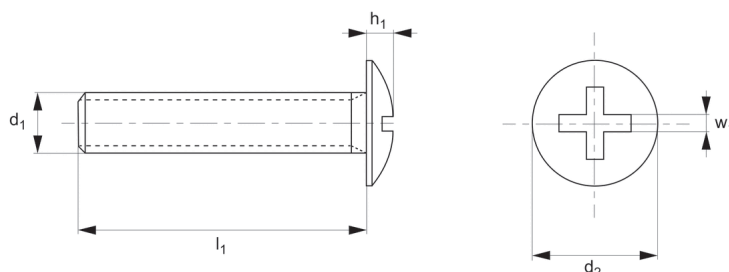

Roofing Bolts

Roofing Bolts - steel, zinc-plated

Standard Screws

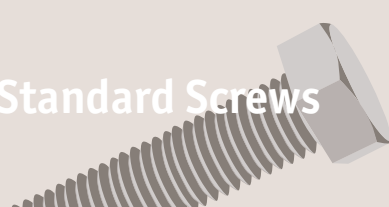

P0269.ZP

STANDARD SCREWS

Material

Steel, zinc-plated.

Order No.	d ₁	l ₁	d ₂ max.	h ₁ max.	w ₁
P0269.040-016-ZP	M 4	16	10.0	2.2	1.2
P0269.040-020-ZP	M 4	20	10.0	2.2	1.2
P0269.040-025-ZP	M 4	25	10.0	2.2	1.2
P0269.040-030-ZP	M 4	30	10.0	2.2	1.2
P0269.050-010-ZP	M 5	10	12.5	2.7	1.2
P0269.050-016-ZP	M 5	16	12.5	2.7	1.2
P0269.050-020-ZP	M 5	20	12.5	2.7	1.2
P0269.050-025-ZP	M 5	25	12.5	2.7	1.2
P0269.050-030-ZP	M 5	30	12.5	2.7	1.2
P0269.060-010-ZP	M 6	10	15.0	3.3	1.6
P0269.060-012-ZP	M 6	12	15.0	3.3	1.6
P0269.060-016-ZP	M 6	16	15.0	3.3	1.6
P0269.060-020-ZP	M 6	20	15.0	3.3	1.6
P0269.060-025-ZP	M 6	25	15.0	3.3	1.6
P0269.060-030-ZP	M 6	30	15.0	3.3	1.6
P0269.060-040-ZP	M 6	40	15.0	3.3	1.6
P0269.060-050-ZP	M 6	50	15.0	3.3	1.6
P0269.060-060-ZP	M 6	60	15.0	3.3	1.6
P0269.060-070-ZP	M 6	70	15.0	3.3	1.6
P0269.060-100-ZP	M 6	100	15.0	3.3	1.6
P0269.080-016-ZP	M 8	16	20.0	4.4	2.0
P0269.080-020-ZP	M 8	20	20.0	4.4	2.0
P0269.080-025-ZP	M 8	25	20.0	4.4	2.0
P0269.080-030-ZP	M 8	30	20.0	4.4	2.0
P0269.080-035-ZP	M 8	35	20.0	4.4	2.0
P0269.080-040-ZP	M 8	40	20.0	4.4	2.0
P0269.080-050-ZP	M 8	50	20.0	4.4	2.0
P0269.100-050-ZP	M10	50	25.0	5.5	2.5
P0269.100-060-ZP	M10	60	25.0	5.5	2.5