




# Slotted Set Screws Cup Point

Cup Point - A4 stainless

Standard Screws

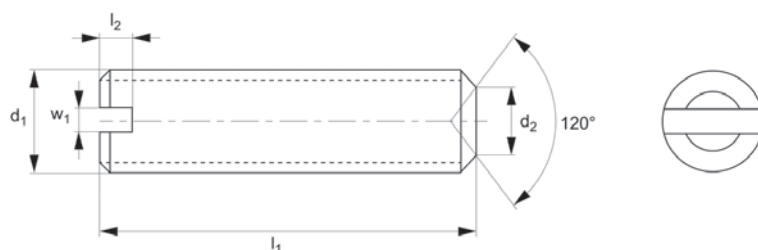

**P0276.A4**

STANDARD SCREWS

## Material

Stainless steel (A4).

See technical page for tightening torques.

## Technical Notes

To DIN 438, cup point.

| Order No.        | d <sub>1</sub> | l <sub>1</sub> | d <sub>2</sub> | l <sub>2</sub><br>min. | w <sub>1</sub> |
|------------------|----------------|----------------|----------------|------------------------|----------------|
| P0276.020-003-A4 | M 2            | 3              | 0.75           | 0.8                    | 0.25           |
| P0276.020-004-A4 | M 2            | 4              | 0.75           | 0.8                    | 0.25           |
| P0276.020-005-A4 | M 2            | 5              | 0.75           | 0.8                    | 0.25           |
| P0276.020-006-A4 | M 2            | 6              | 0.75           | 0.8                    | 0.25           |
| P0276.020-008-A4 | M 2            | 8              | 0.75           | 0.8                    | 0.25           |
| P0276.020-010-A4 | M 2            | 10             | 0.75           | 0.8                    | 0.25           |
| P0276.020-012-A4 | M 2            | 12             | 0.75           | 0.8                    | 0.25           |
| P0276.020-016-A4 | M 2            | 16             | 0.75           | 0.8                    | 0.25           |
| P0276.025-003-A4 | M2,5           | 3              | 0.95           | 1.2                    | 0.4            |
| P0276.025-004-A4 | M2,5           | 4              | 0.95           | 1.2                    | 0.4            |
| P0276.025-005-A4 | M2,5           | 5              | 0.95           | 1.2                    | 0.4            |
| P0276.025-006-A4 | M2,5           | 6              | 0.95           | 1.2                    | 0.4            |
| P0276.025-008-A4 | M2,5           | 8              | 0.95           | 1.2                    | 0.4            |
| P0276.025-010-A4 | M2,5           | 10             | 0.95           | 1.2                    | 0.4            |
| P0276.025-012-A4 | M2,5           | 12             | 0.95           | 1.2                    | 0.4            |
| P0276.025-016-A4 | M2,5           | 16             | 0.95           | 1.2                    | 0.4            |
| P0276.030-003-A4 | M 3            | 3              | 1.15           | 1.2                    | 0.4            |
| P0276.030-004-A4 | M 3            | 4              | 1.15           | 1.2                    | 0.4            |
| P0276.030-005-A4 | M 3            | 5              | 1.15           | 1.2                    | 0.4            |
| P0276.030-006-A4 | M 3            | 6              | 1.15           | 1.2                    | 0.4            |
| P0276.030-008-A4 | M 3            | 8              | 1.15           | 1.2                    | 0.4            |
| P0276.030-010-A4 | M 3            | 10             | 1.15           | 1.2                    | 0.4            |
| P0276.030-012-A4 | M 3            | 12             | 1.15           | 1.2                    | 0.4            |
| P0276.030-014-A4 | M 3            | 14             | 1.15           | 1.2                    | 0.4            |
| P0276.030-016-A4 | M 3            | 16             | 1.15           | 1.2                    | 0.4            |
| P0276.030-020-A4 | M 3            | 20             | 1.15           | 1.2                    | 0.4            |
| P0276.030-025-A4 | M 3            | 25             | 1.15           | 1.2                    | 0.4            |
| P0276.030-030-A4 | M 3            | 30             | 1.15           | 1.2                    | 0.4            |
| P0276.040-003-A4 | M 4            | 3              | 1.75           | 1.5                    | 0.6            |
| P0276.040-004-A4 | M 4            | 4              | 1.75           | 1.5                    | 0.6            |
| P0276.040-005-A4 | M 4            | 5              | 1.75           | 1.5                    | 0.6            |
| P0276.040-006-A4 | M 4            | 6              | 1.75           | 1.5                    | 0.6            |
| P0276.040-008-A4 | M 4            | 8              | 1.75           | 1.5                    | 0.6            |
| P0276.040-010-A4 | M 4            | 10             | 1.75           | 1.5                    | 0.6            |



**Automotion**  
AN ESSENTIA COMPANY

0333 207 4498

[sales@automotioncomponents.co.uk](mailto:sales@automotioncomponents.co.uk)



| Order No.        | d <sub>1</sub> | l <sub>1</sub> | d <sub>2</sub> | l <sub>2</sub><br>min. | w <sub>1</sub> |
|------------------|----------------|----------------|----------------|------------------------|----------------|
| P0276.040-012-A4 | M 4            | 12             | 1.75           | 1.5                    | 0.6            |
| P0276.040-014-A4 | M 4            | 14             | 1.75           | 1.5                    | 0.6            |
| P0276.040-016-A4 | M 4            | 16             | 1.75           | 1.5                    | 0.6            |
| P0276.040-020-A4 | M 4            | 20             | 1.75           | 1.5                    | 0.6            |
| P0276.040-025-A4 | M 4            | 25             | 1.75           | 1.5                    | 0.6            |
| P0276.040-030-A4 | M 4            | 30             | 1.75           | 1.5                    | 0.6            |
| P0276.040-035-A4 | M 4            | 35             | 1.75           | 1.5                    | 0.6            |
| P0276.040-040-A4 | M 4            | 40             | 1.75           | 1.5                    | 0.6            |
| P0276.050-004-A4 | M 5            | 4              | 2.25           | 2.0                    | 0.8            |
| P0276.050-005-A4 | M 5            | 5              | 2.25           | 2.0                    | 0.8            |
| P0276.050-006-A4 | M 5            | 6              | 2.25           | 2.0                    | 0.8            |
| P0276.050-008-A4 | M 5            | 8              | 2.25           | 2.0                    | 0.8            |
| P0276.050-010-A4 | M 5            | 10             | 2.25           | 2.0                    | 0.8            |
| P0276.050-012-A4 | M 5            | 12             | 2.25           | 2.0                    | 0.8            |
| P0276.050-014-A4 | M 5            | 14             | 2.25           | 2.0                    | 0.8            |
| P0276.050-016-A4 | M 5            | 16             | 2.25           | 2.0                    | 0.8            |
| P0276.050-020-A4 | M 5            | 20             | 2.25           | 2.0                    | 0.8            |
| P0276.050-025-A4 | M 5            | 25             | 2.25           | 2.0                    | 0.8            |
| P0276.050-030-A4 | M 5            | 30             | 2.25           | 2.0                    | 0.8            |
| P0276.050-035-A4 | M 5            | 35             | 2.25           | 2.0                    | 0.8            |
| P0276.050-040-A4 | M 5            | 40             | 2.25           | 2.0                    | 0.8            |
| P0276.060-005-A4 | M 6            | 5              | 2.75           | 2.0                    | 1.0            |
| P0276.060-006-A4 | M 6            | 6              | 2.75           | 2.0                    | 1.0            |
| P0276.060-008-A4 | M 6            | 8              | 2.75           | 2.0                    | 1.0            |
| P0276.060-010-A4 | M 6            | 10             | 2.75           | 2.0                    | 1.0            |
| P0276.060-012-A4 | M 6            | 12             | 2.75           | 2.0                    | 1.0            |
| P0276.060-014-A4 | M 6            | 14             | 2.75           | 2.0                    | 1.0            |
| P0276.060-016-A4 | M 6            | 16             | 2.75           | 2.0                    | 1.0            |
| P0276.060-018-A4 | M 6            | 18             | 2.75           | 2.0                    | 1.0            |
| P0276.060-020-A4 | M 6            | 20             | 2.75           | 2.0                    | 1.0            |
| P0276.060-025-A4 | M 6            | 25             | 2.75           | 2.0                    | 1.0            |
| P0276.060-030-A4 | M 6            | 30             | 2.75           | 2.0                    | 1.0            |
| P0276.060-035-A4 | M 6            | 35             | 2.75           | 2.0                    | 1.0            |
| P0276.060-040-A4 | M 6            | 40             | 2.75           | 2.0                    | 1.0            |
| P0276.060-045-A4 | M 6            | 45             | 2.75           | 2.0                    | 1.0            |
| P0276.060-050-A4 | M 6            | 50             | 2.75           | 2.0                    | 1.0            |
| P0276.060-055-A4 | M 6            | 55             | 2.75           | 2.0                    | 1.0            |
| P0276.060-060-A4 | M 6            | 60             | 2.75           | 2.0                    | 1.0            |
| P0276.080-006-A4 | M 8            | 6              | 4.70           | 3.0                    | 1.2            |
| P0276.080-008-A4 | M 8            | 8              | 4.70           | 3.0                    | 1.2            |
| P0276.080-010-A4 | M 8            | 10             | 4.70           | 3.0                    | 1.2            |
| P0276.080-012-A4 | M 8            | 12             | 4.70           | 3.0                    | 1.2            |
| P0276.080-014-A4 | M 8            | 14             | 4.70           | 3.0                    | 1.2            |
| P0276.080-016-A4 | M 8            | 16             | 4.70           | 3.0                    | 1.2            |
| P0276.080-018-A4 | M 8            | 18             | 4.70           | 3.0                    | 1.2            |
| P0276.080-020-A4 | M 8            | 20             | 4.70           | 3.0                    | 1.2            |
| P0276.080-025-A4 | M 8            | 25             | 4.70           | 3.0                    | 1.2            |
| P0276.080-030-A4 | M 8            | 30             | 4.70           | 3.0                    | 1.2            |
| P0276.080-035-A4 | M 8            | 35             | 4.70           | 3.0                    | 1.2            |
| P0276.080-040-A4 | M 8            | 40             | 4.70           | 3.0                    | 1.2            |
| P0276.080-050-A4 | M 8            | 50             | 4.70           | 3.0                    | 1.2            |
| P0276.080-060-A4 | M 8            | 60             | 4.70           | 3.0                    | 1.2            |
| P0276.080-070-A4 | M 8            | 70             | 4.70           | 3.0                    | 1.2            |
| P0276.080-080-A4 | M 8            | 80             | 4.70           | 3.0                    | 1.2            |
| P0276.100-010-A4 | M10            | 10             | 5.70           | 4.0                    | 1.6            |
| P0276.100-012-A4 | M10            | 12             | 5.70           | 4.0                    | 1.6            |
| P0276.100-016-A4 | M10            | 16             | 5.70           | 4.0                    | 1.6            |
| P0276.100-020-A4 | M10            | 20             | 5.70           | 4.0                    | 1.6            |
| P0276.100-025-A4 | M10            | 25             | 5.70           | 4.0                    | 1.6            |
| P0276.100-030-A4 | M10            | 30             | 5.70           | 4.0                    | 1.6            |
| P0276.100-035-A4 | M10            | 35             | 5.70           | 4.0                    | 1.6            |
| P0276.100-040-A4 | M10            | 40             | 5.70           | 4.0                    | 1.6            |
| P0276.100-045-A4 | M10            | 45             | 5.70           | 4.0                    | 1.6            |
| P0276.100-050-A4 | M10            | 50             | 5.70           | 4.0                    | 1.6            |
| P0276.100-055-A4 | M10            | 55             | 5.70           | 4.0                    | 1.6            |
| P0276.100-060-A4 | M10            | 60             | 5.70           | 4.0                    | 1.6            |
| P0276.100-070-A4 | M10            | 70             | 5.70           | 4.0                    | 1.6            |
| P0276.100-080-A4 | M10            | 80             | 5.70           | 4.0                    | 1.6            |



# Slotted Set Screws Cup Point

Cup Point - A4 stainless

Standard Screws



| Order No.        | d <sub>1</sub> | l <sub>1</sub> | d <sub>2</sub> | l <sub>2</sub><br>min. | w <sub>1</sub> |
|------------------|----------------|----------------|----------------|------------------------|----------------|
| P0276.120-010-A4 | M12            | 10             | 7.64           | 4.8                    | 2.0            |
| P0276.120-012-A4 | M12            | 12             | 7.64           | 4.8                    | 2.0            |
| P0276.120-016-A4 | M12            | 16             | 7.64           | 4.8                    | 2.0            |
| P0276.120-020-A4 | M12            | 20             | 7.64           | 4.8                    | 2.0            |
| P0276.120-025-A4 | M12            | 25             | 7.64           | 4.8                    | 2.0            |
| P0276.120-030-A4 | M12            | 30             | 7.64           | 4.8                    | 2.0            |
| P0276.120-035-A4 | M12            | 35             | 7.64           | 4.8                    | 2.0            |
| P0276.120-040-A4 | M12            | 40             | 7.64           | 4.8                    | 2.0            |
| P0276.120-045-A4 | M12            | 45             | 7.64           | 4.8                    | 2.0            |
| P0276.120-050-A4 | M12            | 50             | 7.64           | 4.8                    | 2.0            |
| P0276.120-055-A4 | M12            | 55             | 7.64           | 4.8                    | 2.0            |
| P0276.120-060-A4 | M12            | 60             | 7.64           | 4.8                    | 2.0            |
| P0276.120-070-A4 | M12            | 70             | 7.64           | 4.8                    | 2.0            |
| P0276.120-080-A4 | M12            | 80             | 7.64           | 4.8                    | 2.0            |
| P0276.120-090-A4 | M12            | 90             | 7.64           | 4.8                    | 2.0            |
| P0276.120-100-A4 | M12            | 100            | 7.64           | 4.8                    | 2.0            |
| P0276.160-016-A4 | M16            | 16             | 9.64           | 6.4                    | 2.2            |
| P0276.160-020-A4 | M16            | 20             | 9.64           | 6.4                    | 2.2            |
| P0276.160-025-A4 | M16            | 25             | 9.64           | 6.4                    | 2.2            |
| P0276.160-030-A4 | M16            | 30             | 9.64           | 6.4                    | 2.2            |
| P0276.160-035-A4 | M16            | 35             | 9.64           | 6.4                    | 2.2            |
| P0276.160-040-A4 | M16            | 40             | 9.64           | 6.4                    | 2.2            |
| P0276.160-045-A4 | M16            | 45             | 9.64           | 6.4                    | 2.2            |
| P0276.160-050-A4 | M16            | 50             | 9.64           | 6.4                    | 2.2            |
| P0276.160-055-A4 | M16            | 55             | 9.64           | 6.4                    | 2.2            |
| P0276.160-060-A4 | M16            | 60             | 9.64           | 6.4                    | 2.2            |
| P0276.160-070-A4 | M16            | 70             | 9.64           | 6.4                    | 2.2            |
| P0276.160-080-A4 | M16            | 80             | 9.64           | 6.4                    | 2.2            |
| P0276.160-090-A4 | M16            | 90             | 9.64           | 6.4                    | 2.2            |
| P0276.160-100-A4 | M16            | 100            | 9.64           | 6.4                    | 2.2            |
| P0276.200-020-A4 | M20            | 20             | 13.57          | 8.0                    | 2.6            |
| P0276.200-025-A4 | M20            | 25             | 13.57          | 8.0                    | 2.6            |
| P0276.200-030-A4 | M20            | 30             | 13.57          | 8.0                    | 2.6            |
| P0276.200-035-A4 | M20            | 35             | 13.57          | 8.0                    | 2.6            |
| P0276.200-040-A4 | M20            | 40             | 13.57          | 8.0                    | 2.6            |
| P0276.200-045-A4 | M20            | 45             | 13.57          | 8.0                    | 2.6            |
| P0276.200-050-A4 | M20            | 50             | 13.57          | 8.0                    | 2.6            |
| P0276.200-055-A4 | M20            | 55             | 13.57          | 8.0                    | 2.6            |
| P0276.200-060-A4 | M20            | 60             | 13.57          | 8.0                    | 2.6            |
| P0276.200-070-A4 | M20            | 70             | 13.57          | 8.0                    | 2.6            |
| P0276.200-080-A4 | M20            | 80             | 13.57          | 8.0                    | 2.6            |
| P0276.200-090-A4 | M20            | 90             | 13.57          | 8.0                    | 2.6            |
| P0276.200-100-A4 | M20            | 100            | 13.57          | 8.0                    | 2.6            |

STANDARD SCREWS