



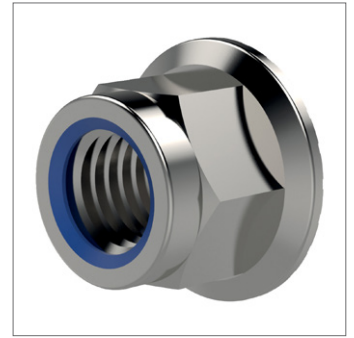

Nylon Insert Serrated Flanged Nuts

Serrated - A2 stainless nylon insert

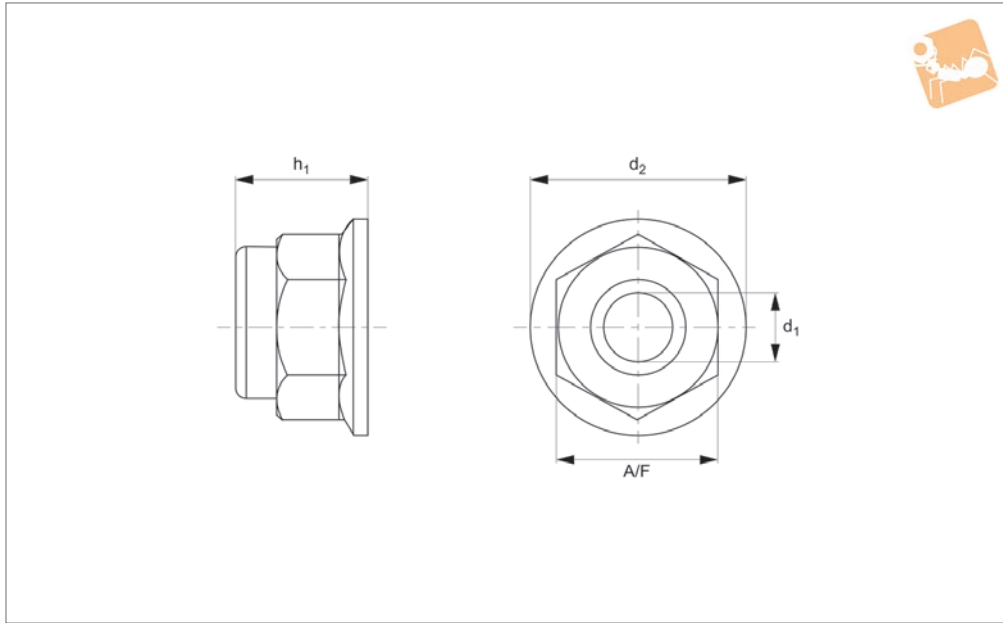

P0310.A2

NUTS

Material
Stainless steel (A2).

Technical Notes
To DIN 6926, serrated.

Order No.	d ₁	d ₂ max.	h ₁	A/F	Material
P0310.040-A2	M 4	10	6,10 - 5,74	7	A2 stainless steel
P0310.050-A2	M 5	11.8	7,10 - 6,74	8	A2 stainless steel
P0310.060-A2	M 6	14.2	9,10 - 8,74	10	A2 stainless steel
P0310.080-A2	M 8	17.9	11,10 - 10,67	13	A2 stainless steel
P0310.100-A2	M10	21.8	13,50 - 13,07	15	A2 stainless steel
P0310.120-A2	M12	26.0	16,10 - 15,67	18	A2 stainless steel