



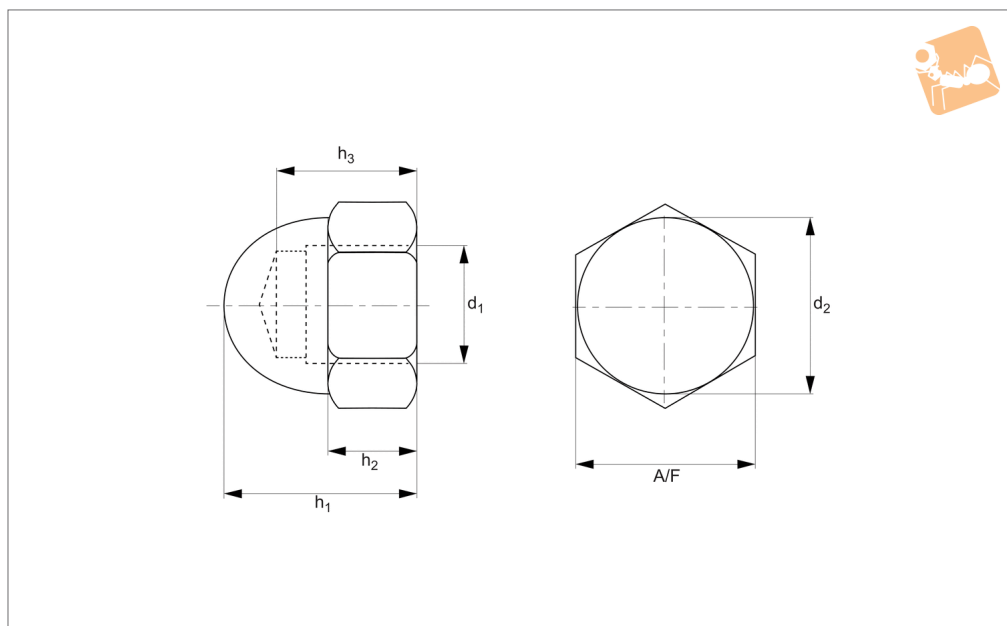

Hexagon Domed Cap Nuts

Hexagon Domed, DIN 1587

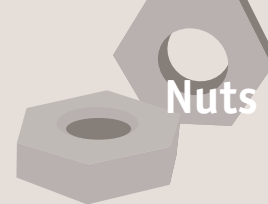

P0318.NL

Material

Nylon.

Technical Notes

To DIN 1587. Nylon Hexagon Domenuts.

Screw into place with tool.

Light and rustproof. Good wear resistance and low coefficient of friction Good resistance to shocks.

Order No.	d ₁	d ₂	h ₁	h ₂ max.	h ₃	A/F	Material	Grade	Colour	To standard
P0318.030-NL	M 3	5.5	6.3	2.5	5.0	5.5	Nylon	Std	natural	DIN 1587
P0318.040-NL	M 4	6.5	8.0	3.2	5.5	7.0	Nylon	Std	natural	DIN 1587
P0318.050-NL	M 5	7.5	10.0	4.0	7.5	8.0	Nylon	Std	natural	DIN 1587
P0318.060-NL	M 6	9.5	12.0	8.0	8.0	10.0	Nylon	Std	natural	DIN 1587
P0318.080-NL	M 8	12.5	15.0	6.5	11.0	13.0	Nylon	Std	natural	DIN 1587
P0318.100-NL	M 10	16.0	18.0	8.0	13.0	17.0	Nylon	Std	natural	DIN 1587