



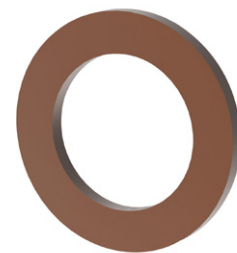

Sealing Rings copper

Flat Washers

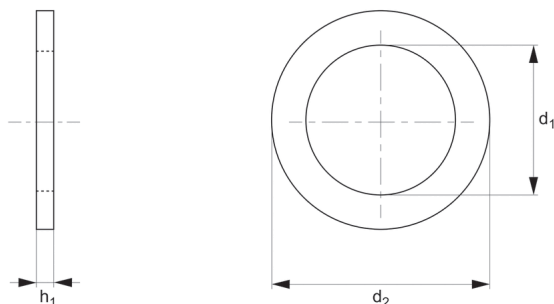

P0334.CU

FLAT WASHERS

Material
Copper.

Technical Notes

To DIN 7603 A. Used as sealing ring for pipe connections and blanking plugs.

Order No.	d ₁	d ₂	h ₁	Suitable for DIN 908 thread	Suitable for pipe thread
P0334.05-10-010	5	10	1.0	-	-
P0334.06-10-010	6	10	1.0	-	-
P0334.07-10-010	7	10	1.0	-	-
P0334.08-12-010	8	12	1.0	M 8 x 1,0	-
P0334.09-14-010	9	14	1.0	-	-
P0334.10-14-010	10	14	1.0	M10 x 1,0	G1/8"
P0334.10-15-010	10	15	1.0	M10 x 1,0	-
P0334.10-16-010	10	16	1.0	M10 x 1,0	-
P0334.12-16-010	12	16	1.0	M12 x 1,5	-
P0334.14-18-010	14	18	1.0	M14 x 1,5	G1/4"
P0334.14-20-010	14	20	1.0	-	-
P0334.15-20-010	15	20	1.0	-	-
P0334.06-10-015	6	10	1.5	-	-
P0334.08-14-015	8	14	1.5	M 8 x 1,0	-
P0334.09-14-015	9	14	1.5	M10 x 1,0	-
P0334.10-14-015	10	14	1.5	M10 x 1,0	G1/8"
P0334.10-16-015	10	16	1.5	M10 x 1,0	-
P0334.10-20-015	10	20	1.5	-	-
P0334.11-17-015	11	17	1.5	-	-
P0334.12-16-015	12	16	1.5	M12 x 1,5	-
P0334.12-17-015	12	17	1.5	-	-
P0334.12-18-015	12	18	1.5	-	-
P0334.12-20-015	12	20	1.5	-	-
P0334.13-18-015	13	18	1.5	-	-
P0334.14-18-015	14	18	1.5	M14 x 1,5	G1/4"
P0334.14-20-015	14	20	1.5	-	-
P0334.14-22-015	14	22	1.5	-	-
P0334.15-20-015	15	20	1.5	-	-
P0334.16-20-015	16	20	1.5	M16 x 1,5	-
P0334.16-22-015	16	22	1.5	-	-
P0334.17-21-015	17	21	1.5	-	G3/8"
P0334.17-22-015	17	22	1.5	-	-
P0334.18-24-015	18	24	1.5	M18 x 1,5	-
P0334.20-24-015	20	24	1.5	M20 x 1,5	-
P0334.20-26-015	20	26	1.5	-	-



Order No.	d ₁	d ₂	h ₁	Suitable for DIN 908 thread	Suitable for pipe thread
P0334.21-26-015	21	26	1.5	-	G1/2"
P0334.21-28-015	21	28	1.5	-	-
P0334.22-27-015	22	27	1.5	M22 x 1,5	-
P0334.22-29-015	22	29	1.5	-	-
P0334.10-19-020	10	19	2.0	-	-
P0334.13-18-020	13	18	2.0	-	-
P0334.14-18-020	14	18	2.0	M14 x 1,5	G1/4"
P0334.14-20-020	14	20	2.0	-	-
P0334.15-20-020	15	20	2.0	-	-
P0334.16-20-020	16	20	2.0	M16 x 1,5	-
P0334.16-21-020	16	21	2.0	-	-
P0334.16-22-020	16	22	2.0	-	-
P0334.17-24-020	17	24	2.0	-	-
P0334.18-24-020	18	24	2.0	M18 x 1,5	-
P0334.19-26-020	19	26	2.0	-	-
P0334.20-24-020	20	24	2.0	M20 x 1,5	-
P0334.21-26-020	21	26	2.0	-	G1/2"
P0334.21-28-020	21	28	2.0	-	-
P0334.22-26-020	22	26	2.0	M22 x 1,5	-
P0334.22-29-020	22	29	2.0	-	-
P0334.24-30-020	24	30	2.0	M24 x 1,5	-
P0334.24-32-020	24	32	2.0	-	-
P0334.26-32-020	26	32	2.0	M26 x 1,5	G3/4"
P0334.26-33-020	26	33	2.0	-	-
P0334.26-34-020	26	34	2.0	-	-
P0334.28-34-020	28	34	2.0	-	-
P0334.30-36-020	30	36	2.0	M30 x 1,5	G7/8"
P0334.30-38-020	30	38	2.0	-	-
P0334.32-38-020	32	38	2.0	-	-
P0334.32-40-020	32	40	2.0	-	-
P0334.33-39-020	33	39	2.0	-	G1"
P0334.35-45-020	35	45	2.0	-	-
P0334.36-42-020	36	42	2.0	M36 x 2,0	G1-1/8"
P0334.38-44-020	38	44	2.0	M38 x 2,0	-
P0334.40-47-020	40	47	2.0	-	-
P0334.42-49-020	42	49	2.0	M42 x 2	G1-1/4"
P0334.45-52-020	45	52	2.0	-	-
P0334.48-55-020	48	55	2.0	M48 x 2	G1-1/2"
P0334.50-57-020	50	57	2.0	-	-