




Flat Washer

A4 stainless



Flat Washers

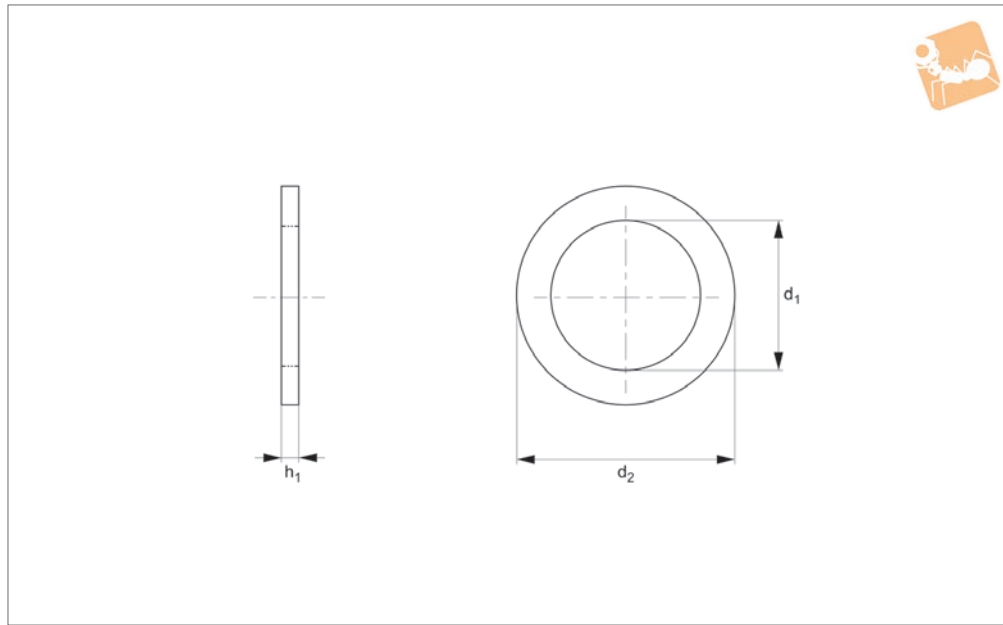

P0335.A4

FLAT WASHERS

Material

Stainless steel (A4, AISI 316).

Technical Notes

To DIN 433.

Order No.	d ₁	d ₂	For thread	h ₁	Material
P0335.014-A4	1.5	3	M1,4	0.3	A4 s/s
P0335.016-A4	1.7	3.5	M1,6	0.3	A4 s/s
P0335.020-A4	2.2	4.5	M 2	0.3	A4 s/s
P0335.025-A4	2.7	5	M2,5	0.5	A4 s/s
P0335.030-A4	3.2	6	M 3	0.5	A4 s/s
P0335.035-A4	3.7	7	M3,5	0.5	A4 s/s
P0335.040-A4	4.3	8	M 4	0.5	A4 s/s
P0335.050-A4	5.3	9	M 5	1.0	A4 s/s
P0335.060-A4	6.4	11	M 6	1.6	A4 s/s
P0335.080-A4	8.4	15	M 8	1.6	A4 s/s
P0335.100-A4	10.5	18	M10	1.6	A4 s/s
P0335.120-A4	13	20	M12	2.0	A4 s/s
P0335.140-A4	15	24	M14	2.5	A4 s/s
P0335.160-A4	17	28	M16	2.5	A4 s/s
P0335.180-A4	19	30	M18	2.5	A4 s/s
P0335.200-A4	21	34	M20	3.0	A4 s/s