


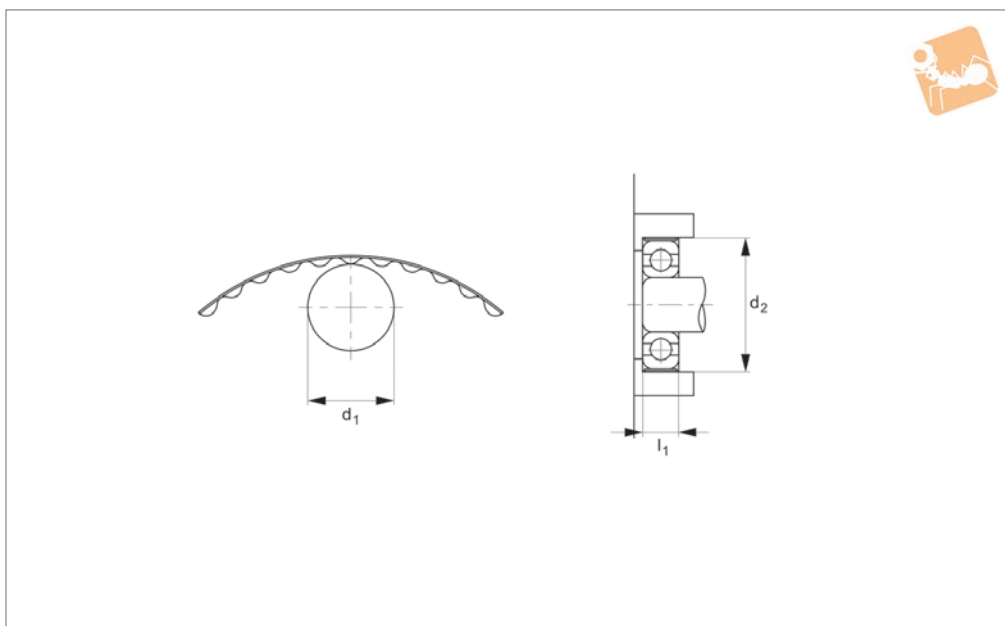

P0397

TOLERANCE RINGS

Material

Stainless steel (type 304, DIN 1.4301).

Technical Notes

The waves are on the inside, the ring sits

on the housing bore with the waves being compressed by the shaft diameter. Used as a bearing mount where the bearings are required to float axially.

Order No.	d ₁	l ₁	Bearing dia. & no.	d ₂	Radial load N max.
P0397.HVL013-005	13	5	13 (~624)	13,60 to 13,65	125
P0397.HVL016-005	16	5	16 (~625)	16,60 to 16,65	150
P0397.HVL019-006	19	6	19 (~626)	19,60 to 19,65	220
P0397.HVL022-007	22	7	22 (~608)	22,60 to 22,65	300
P0397.HVL024-007	24	7	24 (~609)	24,60 to 24,65	330
P0397.HVL026-008	26	8	26 (~629)	26,60 to 26,65	400
P0397.HVL028-008	28	8	28 (~6001)	28,60 to 28,65	440
P0397.HVL030-009	30	9	30 (~6200)	30,60 to 30,65	520
P0397.HVL032-008	32	8	32 (~16002)	32,60 to 32,65	500
P0397.HVL032-009	32	9	32 (~6002)	32,60 to 32,65	560
P0397.HVL032-010	32	10	32 (~6201)	32,60 to 32,65	620
P0397.HVL035-010	35	10	35 (~6003)	35,60 to 35,65	750
P0397.HVL035-015	35	15	35 (~6202)	35,60 to 35,65	1050
P0397.HVL052-015	52	15	52 (~6205)	52,60 to 52,65	1600