




# Knurled Thumb Screws

plastic - stainless steel grub screw

Thumb Screws

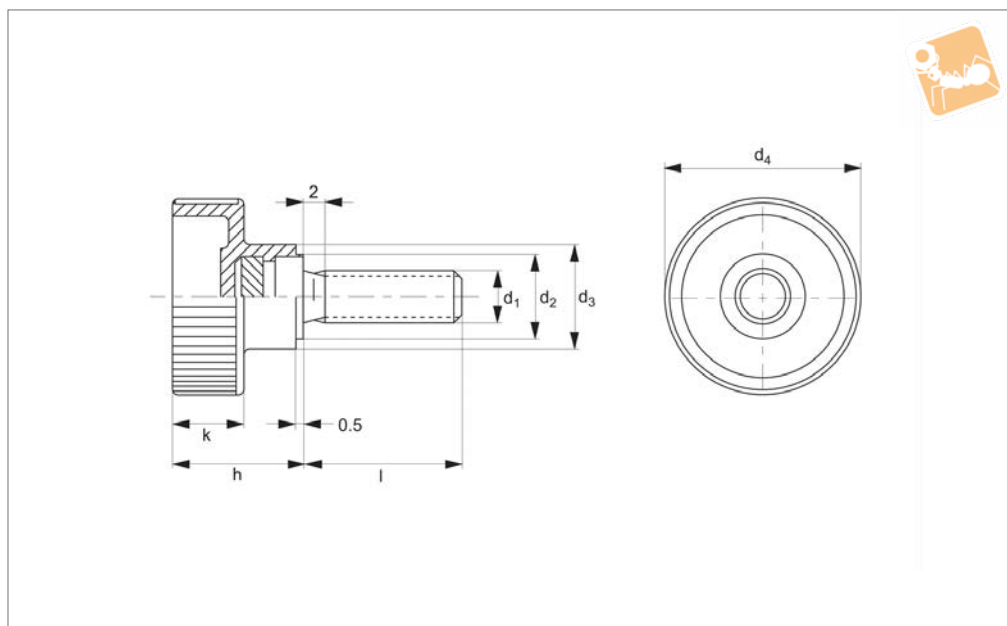

**P0440.A2**

THUMB SCREWS

## Material

Handle: thermoplastic PA, black.

Screw: stainless steel 1.4567. (AISI 304)

## Technical Notes

Temperature range from -30°C up to +80°C.

| Order No.        | d <sub>1</sub> | d <sub>2</sub> | d <sub>3</sub> | d <sub>4</sub> | h    | k    | l  | Weight<br>g |
|------------------|----------------|----------------|----------------|----------------|------|------|----|-------------|
| P0440.050-010-A2 | M 5            | 9              | 12             | 19             | 14.0 | 8.0  | 10 | 4.3         |
| P0440.050-025-A2 | M 5            | 9              | 12             | 19             | 14.0 | 8.0  | 25 | 6.0         |
| P0440.060-016-A2 | M 6            | 12             | 14             | 24             | 16.5 | 9.5  | 16 | 8.0         |
| P0440.060-020-A2 | M 6            | 12             | 14             | 24             | 16.5 | 9.5  | 20 | 9.0         |
| P0440.060-030-A2 | M 6            | 12             | 14             | 24             | 16.5 | 9.5  | 30 | 10.0        |
| P0440.080-025-A2 | M 8            | 14             | 16             | 30             | 19.5 | 11.0 | 25 | 17.0        |
| P0440.080-030-A2 | M 8            | 14             | 16             | 30             | 19.5 | 11.0 | 30 | 19.0        |