




Reduced C'snk Head Insert Nuts

Reduced - A4 stainless

Insert Nuts

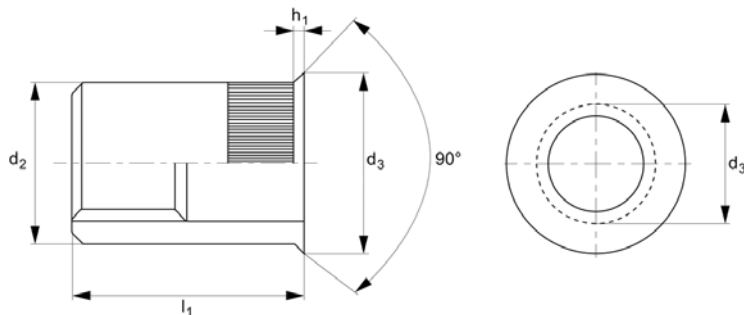

P0824.A4

INSERT NUTS

Material

Stainless steel (A4, AISI 316).

Technical Notes

Plain body type.

Provides near flush installation in thin

materials.

Tips

Also known as blind rivet nuts or grip nuts.

Important Notes

Reduced height head.

M3-M8: $0 < 0.7$

M10: $0.7 < 0.9$

Order No.	d_1	Grip range	d_2 $+0 -0.2$	d_3	h_1	l_1
P0824.040-020-A4	M 4	0,5-2,0	6.0	6.5	0.5	11.0
P0824.050-030-A4	M 5	0,5-3,0	7.0	7.5	0.5	12.0
P0824.060-030-A4	M 6	0,5-3,0	9.0	9.50	0.5	14.5
P0824.080-030-A4	M 8	0,5-3,0	11.0	11.5	0.5	16.0