



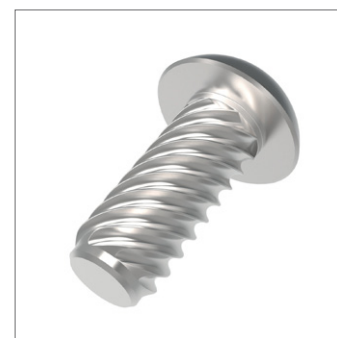

# Hammer Drive Pins

steel

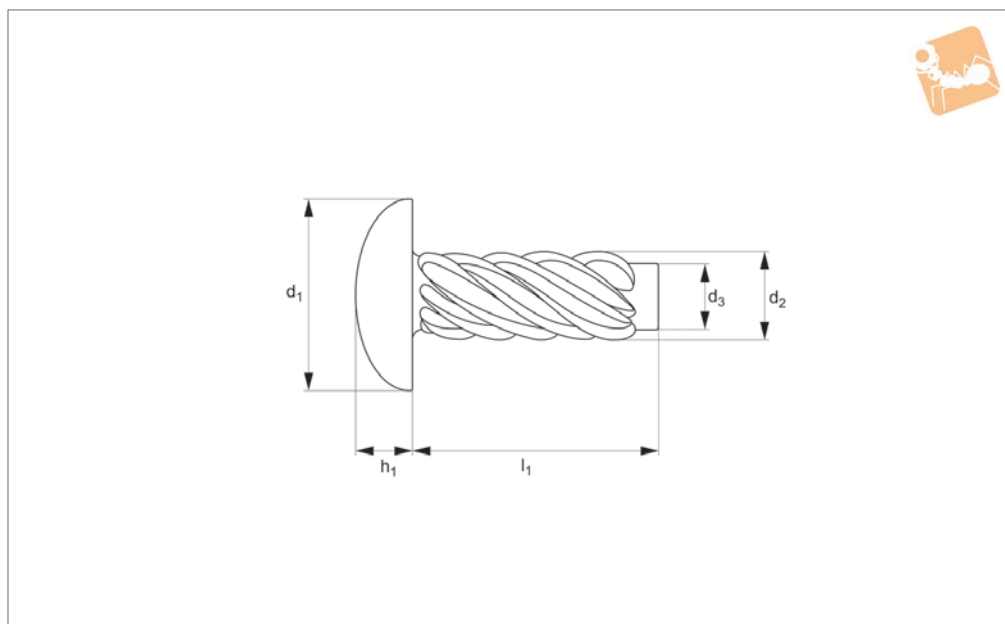

**P1245**

OTHER PINS

## Material

Steel (nickel-plated or self-colour).

| Order No.        | d <sub>1</sub> | d <sub>2</sub> | d <sub>3</sub> | l <sub>1</sub> | h <sub>1</sub> | Recc. hole |
|------------------|----------------|----------------|----------------|----------------|----------------|------------|
| P1245.014-005-SC | 2.60           | 1.63           | 1.40           | 5.0            | 0.90           | 1.40       |
| P1245.014-060-SC | 2.60           | 1.63           | 1.40           | 6.0            | 0.90           | 1.40       |
| P1245.014-800-SC | 2.60           | 1.63           | 1.40           | 8.0            | 0.90           | 1.40       |
| P1245.016-050-SC | 3.00           | 1.83           | 1.60           | 5.0            | 1.10           | 1.60       |
| P1245.016-060-SC | 3.00           | 1.83           | 1.60           | 6.0            | 1.10           | 1.60       |
| P1245.016-080-SC | 3.00           | 1.83           | 1.60           | 8.0            | 1.10           | 1.60       |
| P1245.020-060-SC | 3.70           | 2.30           | 2.00           | 6.0            | 1.30           | 2.00       |
| P1245.020-080-SC | 3.70           | 2.30           | 2.00           | 8.0            | 1.30           | 2.00       |
| P1245.020-100-SC | 3.70           | 2.30           | 2.00           | 10.0           | 1.30           | 2.00       |
| P1245.025-060-SC | 4.60           | 2.80           | 2.50           | 6.0            | 1.60           | 2.55       |
| P1245.025-080-SC | 4.60           | 2.80           | 2.50           | 8.0            | 1.60           | 2.55       |
| P1245.025-100-SC | 4.60           | 2.80           | 2.50           | 10.0           | 1.60           | 2.55       |
| P1245.030-080-SC | 5.45           | 3.35           | 3.00           | 8.0            | 1.95           | 3.00       |
| P1245.030-100-SC | 5.45           | 3.35           | 3.00           | 10.0           | 1.95           | 3.00       |
| P1245.030-120-SC | 5.45           | 3.35           | 3.00           | 12.0           | 1.95           | 3.00       |
| P1245.040-100-SC | 7.25           | 4.35           | 4.00           | 10.0           | 2.55           | 4.00       |
| P1245.040-120-SC | 7.25           | 4.35           | 4.00           | 12.0           | 2.55           | 4.00       |
| P1245.040-160-SC | 7.25           | 4.35           | 4.00           | 16.0           | 2.55           | 4.00       |
| P1245.050-120-SC | 9.10           | 5.35           | 5.00           | 12.0           | 3.15           | 5.00       |
| P1245.050-160-SC | 9.10           | 5.35           | 5.00           | 16.0           | 3.15           | 5.00       |
| P1245.050-200-SC | 9.10           | 5.35           | 5.00           | 20.0           | 3.15           | 5.00       |
| P1245.060-160-SC | 10.80          | 6.35           | 6.00           | 16.0           | 3.75           | 6.00       |
| P1245.060-200-SC | 10.80          | 6.35           | 6.00           | 20.0           | 3.75           | 6.00       |
| P1245.035-095-NP | 6.60           | 3.50           | 2.94           | 9.5            | 2.61           | 3.05       |
| P1245.035-065-NP | 6.60           | 3.50           | 2.94           | 6.4            | 2.61           | 3.05       |