


P1316

SPRINGS

Material

Stainless steel (EN10270-3, DIN 1.4310).

Order No.	d ₁	d ₂	l ±0.25	For spring
P1316.10-12-10	10	12	10	P1315.10-A
P1316.12-16-10	12	16	10	P1315.10-B
P1316.15-17-15	15	17	15	P1315.15-A
P1316.20-23-15	20	23	15	P1315.15-B
P1316.15-17-20	15	17	20	P1315.15-C
P1316.20-23-20	20	23	20	P1315.15-D
P1316.30-34-15	30	34	15	P1315.20-B
P1316.30-34-20	30	34	20	P1315.20-D
P1316.20-23-25	20	23	25	P1315.20-E
P1316.30-34-25	30	34	25	P1315.20-F
P1316.25-28-15	25	28	15	P1315.25-A
P1316.35-39-15	35	39	15	P1315.25-B
P1316.25-28-20	25	28	20	P1315.25-C
P1316.35-39-20	35	39	20	P1315.25-D
P1316.25-28-25	25	28	25	P1315.25-E
P1316.35-39-25	35	39	25	P1315.25-F
P1316.32-36-20	32	36	20	P1315.30-A
P1316.45-50-20	45	50	20	P1315.30-B
P1316.32-34-25	30	34	25	P1315.30-C
P1316.45-50-25	45	50	25	P1315.30-D
P1316.32-36-30	32	36	30	P1315.30-E
P1316.45-50-30	45	50	30	P1315.30-F
P1316.40-44-25	40	44	25	P1315.40-A
P1316.60-65-25	60	65	25	P1315.40-B
P1316.40-44-30	40	44	30	P1315.40-C
P1316.60-65-30	60	65	30	P1315.40-D
P1316.40-44-40	40	44	40	P1315.40-E
P1316.60-65-40	60	65	40	P1315.40-F
P1316.50-55-30	50	55	30	P1315.50-A
P1316.75-80-30	75	80	30	P1315.50-B
P1316.50-55-40	50	55	40	P1315.50-C
P1316.75-80-40	75	80	40	P1315.50-D
P1316.50-55-50	50	55	50	P1315.50-E
P1316.75-80-50	75	80	50	P1315.50-F

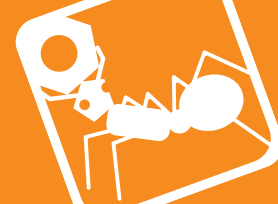

Order No.	d ₁	d ₂	l ±0.25	For spring
P1316.100-105-40	100	105	40	P1315.60-B
P1316.60-65-50	60	65	50	P1315.60-C
P1316.100-105-50	100	105	50	P1315.60-D
P1316.60-65-60	60	65	60	P1315.60-E
P1316.100-105-60	100	105	60	P1315.60-F