



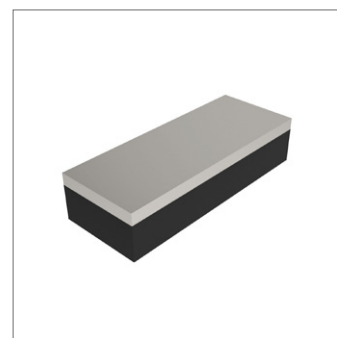

Anti-vibration Impact Plates

metal-rubber

Anti-Vibration Components

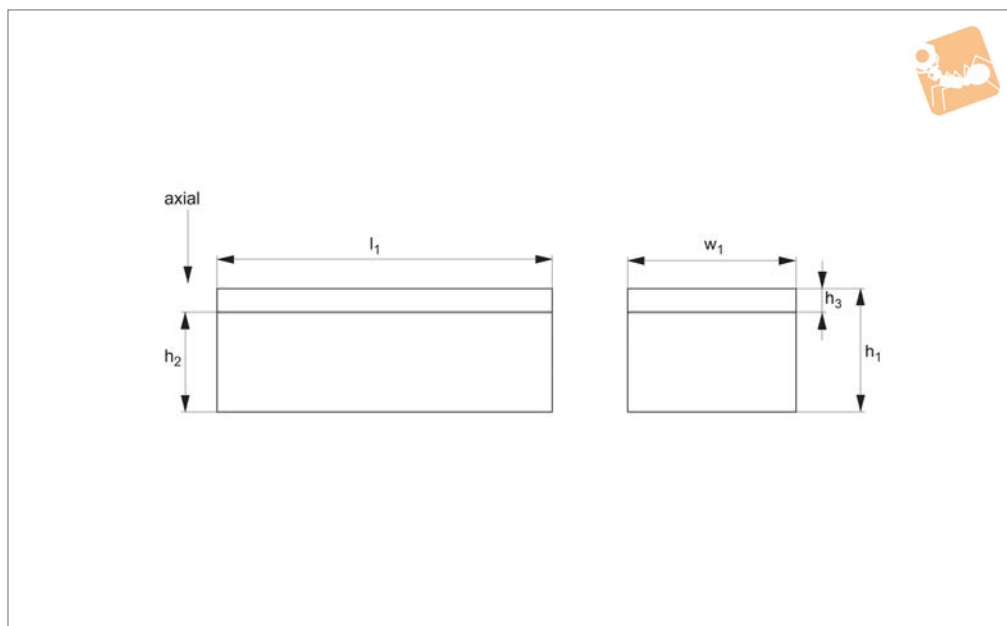

P2060

ANTI-VIBRATION COMPONENTS

Material

Rubber on silver zinc plated steel (rubber hardness - 60 Shore A).

be drilled to suit the number of threads, thread sizes and the pitch you require.

request.

Technical Notes

The metal plate is provided blank so it can

Part no. P2060.0500-125 has a ribbed base. Other sizes can be supplied on

Order No.	l_1	w_1	h_1	h_2	h_3	Axial load kgf max.	Compression max.
P2060.1250-035	1250	35	40	30	10	2500	2.0
P2060.0180-070	180	70	40	30	10	1000	2.8
P2060.0245-070	245	70	40	30	10	1300	3.7
P2060.0285-070	285	70	40	30	10	2000	3.6
P2060.0320-070	320	70	40	30	10	2700	3.5
P2060.0250-120	250	120	40	28	12	5000	3.3
P2060.0500-125	500	125	30	15	15	10000	4.0