


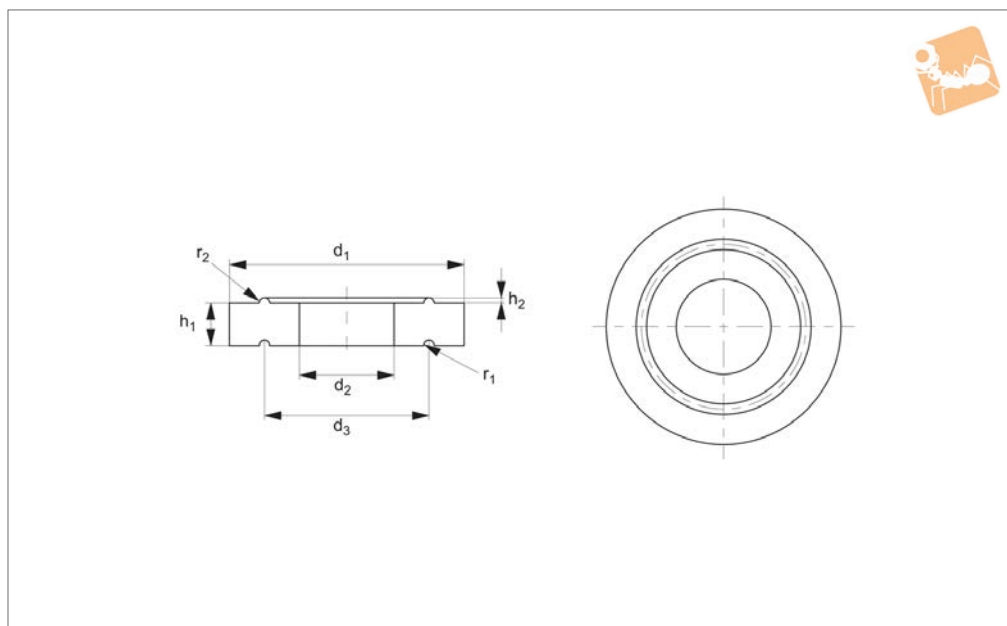

P2083

ANTI-VIBRATION COMPONENTS

Material

Rubber (hardness 70 Shore A).

Order No.	d ₁	d ₂	d ₃	h ₁	h ₂	r ₁	r ₂	Compression max.	Axial load kgf max.
P2083.070	70	30	50	14	2	7	4	2	200
P2083.072	72	32	52	23	2	2	2	7	400
P2083.073	72	32	52	23	2	2	2	8.5	900
P2083.076	76	37	58	12.5	3.5	2.5	2.5	2	550
P2083.114	114	66	90	15	3	3	3	3.2	500
P2083.115	114	66	90	15	3	3	3	5	1500
P2083.116	116	52	84	23.5	2.5	3.5	2.5	3.5	800
P2083.117	116	52	84	23.5	2.5	3.5	2.5	3.5	1000
P2083.120	120	50	85	27.5	2.5	2.5	2.5	3.5	1000
P2083.174	174	126	150	15	3	3	3	2	2000
P2083.192	192	55	122	31	3	4	3	3.1	4340
P2083.207	207	108	160	28	2	4	4	2.5	3000